


# ASSEMBLY AND INSTALLATION INSTRUCTIONS

P0454 / P0455

**WARNING:** TO AVOID RISK OF ELECTRICAL SHOCK, BE SURE TO SHUT OFF POWER WHILE INSTALLING OR SERVICING THIS FIXTURE.

**NOTES:** 1. Before installing, consult local electrical codes for wiring and grounding requirements.  
2. Read and save these instructions.

## Hardware Package (included):

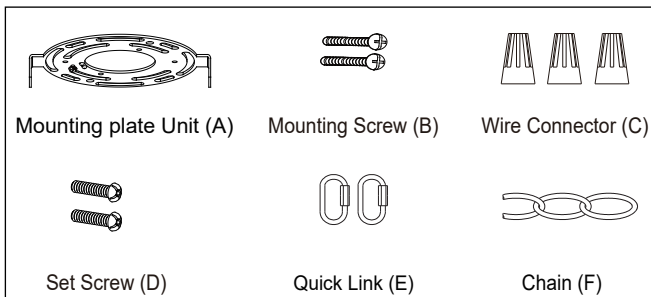


## Installation Steps

Turn off the power at fuse or circuit box.


1. Unscrew the two set screws (D), remove the canopy kit from the mounting plate unit (A).
2. Attach the mounting plate unit (A) to outlet box by using two mounting screws (B).
3. Choose the length of the chain (F) you need, then weave the fixture wire and the fixture ground wire through the chain (F) and canopy kit.
4. Connect the chain (F) to the canopy kit and loop with two quick links (E).
5. Pull out the source wires from the outlet box. Make wire connections using wire connectors (C) as follows:
  - Connect the smooth-coated wire (marked) from the fixture to the black wire from the power source.
  - Connect the ribbed-coated wire (unmarked) from the fixture to the white wire from the power source.
  - Attach the fixture ground wire to the mounting plate unit (A) with the green ground screw, then connect it to the house ground wire with a wire connector (C).Carefully put the wires back into the outlet box.
6. Attach the canopy kit to the mounting plate unit (A) by using two set screws (D).
7. Install 1 x 60W max. medium base bulb (not included). See relamping label at socket area or packaging for maximum allowed wattage.
8. Rotate the glass shade onto the glass holder until they are locked in place. (Do not over tighten the glass shade).

Turn on the power at fuse or circuit box.

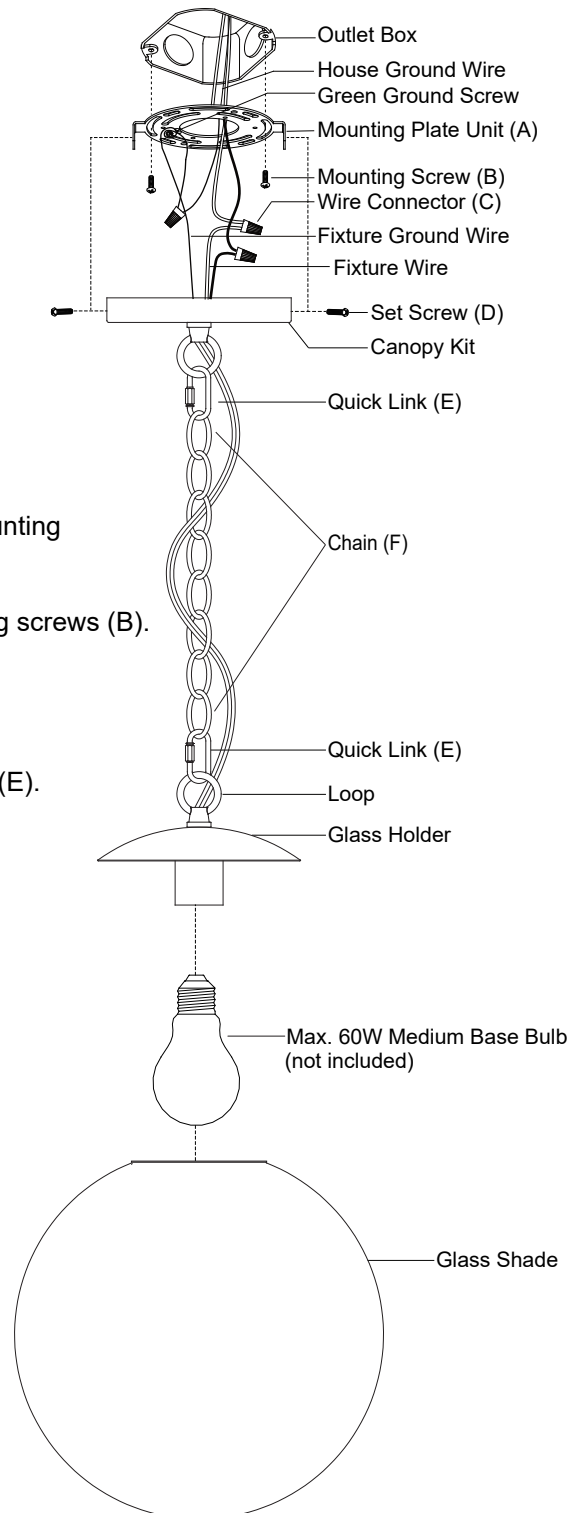


The following parts are available for reorder if damaged or missing.


### Spare Parts List:

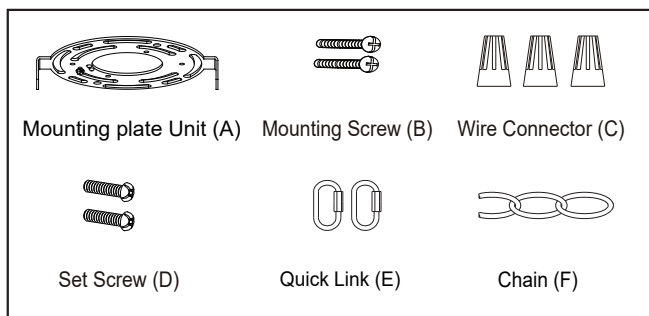

Assembly Kit  
7178MM (1 SET) for P0454  
7179MM (1 SET) for P0455

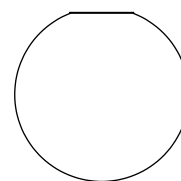

Glass Shade  
10590FO

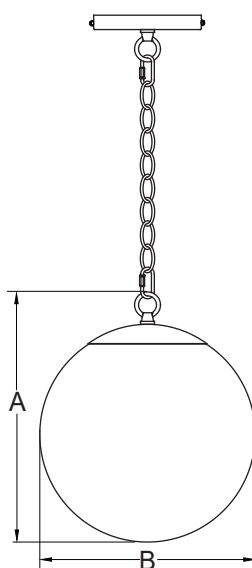

### 1 Year Warranty

Vaxcel warrants all of our products against defects in workmanship and finishes for one year following the date of shipment.

*Exclusions: This warranty does not include the failure of products from extreme acts of nature; environmental conditions not suited for the products intended use; operation in temperatures outside of the range specified in the instruction manual; usage with improper power supply, power surges or dips. For coastal locations, some corrosion is considered normal for the environment.*

*Vaxcel reserves the right to repair, replace or issue a credit for any properly installed product, provided it is returned per RMA instruction. This warranty is limited to the cost of the product only and does not extend to transportation, installation or replacement costs.*

How can warranty service be obtained?

[info@vaxcel.com](mailto:info@vaxcel.com)

1-800-482-9235