



Ultra compact LED flood with a variety of NEMA distributions for lighting applications such as safety/security, accent, flag pole, columns, facade, area, or signs

- NEMA distributions include: - N (3x3), M (4x4), RM (5x4) and W (6x6)
- 7 high powered LED's (Stock)
- 10 high powered LED's (MTO)
- MTO Versions: 3000K CCT nominal with 80 CRI, 4000K and 5000K CCT nominal with 70 CRI
- Stock Versions: 4000K and 5000K CCT
- High impact UV stabilized acrylic outer lens protects LEDs and allows for cleaning and debris removal

- Rugged die-cast aluminum housing with dark bronze finish
- Traditional 1/2" x 14 NPS threaded adjustable knuckle mounting
- Visor and vandal lens available
- 0-10V dimming driver standard, order CD option to have dimming leads extended
- IP 66, Listed to UL1598 for use in wet locations
- DesignLights Consortium (DLC) qualified Consult DLC website for more details: <http://www.designlights.org/QPL>

STOCK

ORDERING INFORMATION

Catalog Number	Mount	Max Candle Power	Beam Pattern	Wattage	Drive Current	Voltage	Color Temperature	Lumens	LPW	Weight lbs. (kg)	Finish
FSL-25	1/2" thread	1814	Wide	25	700mA	120-277V	5000K	2664	106.5	6 (2.7)	Bronze
FSL-25-PCU	1/2" thread	1814	Wide	25	700mA	120-277V	5000K	2664	106.5	6 (2.7)	
FSL-25-4K	1/2" thread	1794	Wide	26	1050mA	120-277V	4000K	2406	92.5	6 (2.7)	
FSL-25-4K-PCU	1/2" thread	1668	Wide	26	700mA	120-277V	4000K	2463	98.5	6 (2.7)	

MADE-TO-ORDER

ORDERING INFORMATION

FSL	-	10L	-	25	-		-		-	K	-		-		-	F
-----	---	-----	---	----	---	--	---	--	---	---	---	--	---	--	---	---

FAMILY	# LEDS	WATTS	CCT	DISTRIBUTION	VOLTAGE	MOUNTING	FINISH	CONTROL OPTION	OPTIONS
FSL FACTOR Flood Small	10L 10 LED	25 25W	3K 3000K 4K 4000K 5K 5000K	N 3x3 M 4x4 RM 5x4 W 6x6	U 120V-277V 1 120V 2 208V 3 240V 4 277V	K Knuckle	DB Bronze BL Black WH White GR Gray PS Platinum silver CC Custom Color	PC ¹ Photocontrol (voltage specified and determined by voltage field) CD Continuous dimming	F ¹ Fusing 120 or 277V only (determined by voltage field)

1 - PC - photocell and F - Fusing options cannot be combined, only available as separate options

STOCK

ACCESSORIES/REPLACEMENT PARTS - ORDER SEPARATELY

Catalog Number	Description
FSL-SPC	Vandal resistant polycarbonate lens (Replaces existing acrylic fixture lens)
FSL-VISOR-XX ¹	Top/Bottom visor (Tap holes in lens frame for field installation)
93047942AC	Acrylic lens w/ gasket
93047957	FSL7, 25w, 120-277V Dimming driver, 1050mA
93043808	FSL10, 25w, 120-277V Dimming driver, 700mA
20750110264	Knuckle mount Dark Bronze finish. Contact factory for additional finishes
S-302	Slipfits 1 1/2" or 2" pipe (1.9" OD or 2 3/8" OD) with 1/2" N.P.S.M. hub; Gray
S-302-M51	Slipfits 1 1/2" or 2" pipe (1.9" OD or 2 3/8" OD) with 1/2" N.P.S.M. hub; Bronze
S-302-M52	Slipfits 1 1/2" or 2" pipe (1.9" OD or 2 3/8" OD) with 1/2" N.P.S.M. hub; White
TRN-XX ¹	Trunnion adaptor for 1/2" threaded knuckle mount

1 Specify finish color to match fixture, e.g. DB - Bronze.

EQUIVALENCY INFORMATION


Equivalency			Energy Savings
MH	HPS	CFL	
100w	100w	42w	79%



TRN-XX

ADDITIONAL ACCESSORIES ON PG. 214-217

DIMENSIONS

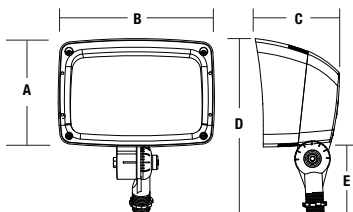

A	B	C	D	E	Weight
5.125"	7.5"	4"	8.625"	3.5"	6 lbs.
130 mm	190 mm	102 mm	219 mm	89 mm	2.7 kg