
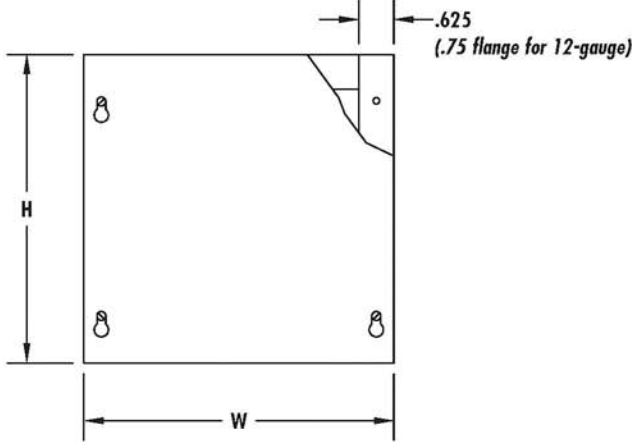


# GALVANIZED AND PAINTED TYPE 1 BOXES

Screw Cover, Screw Cover w/KO's, Hinge Cover, Hinge Cover w/KO's


TYPE 1

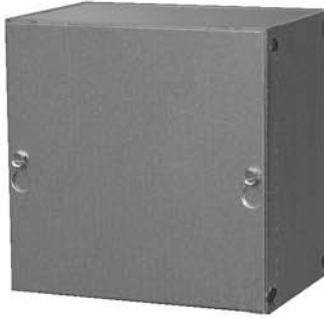

**TYPE 1 SCREW COVER**

.50-.75 CONCENTRIC KNOCKOUT

\* THE 1.00-1.25 CONCENTRIC KNOCKOUT IS USED WHEN H OR W = 12.00 INCHES OR MORE.\*

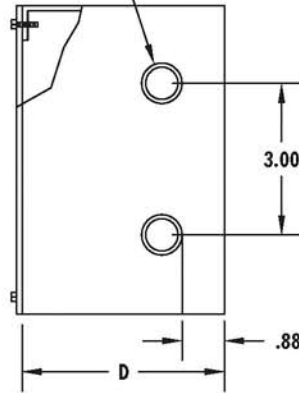

**TYPE 1 SCREW COVER WITH KNOCKOUTS**




**CONSTRUCTION:**


- CODE GAUGE G-90U GALVANIZED STEEL
- REMOVABLE COVER FASTENED WITH PLATED STEEL SCREWS
- KEYHOLE SCREW SLOTS IN THE COVER PERMIT THE REMOVAL OF THE COVER WITHOUT EXTRACTING THE SCREWS

**FINISH:**

- E-BOX TYPE 1 SCREW COVER BOXES ARE PROVIDED IN GALVANIZED G-90U OR ANSI 61 GRAY POLYESTER POWDER COATING INSIDE AND OUT OVER PAINT GRIP GALVANIZED STEEL

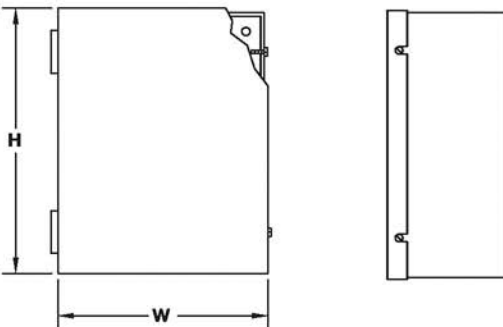

**TYPE 1 HINGE SCREW COVER**

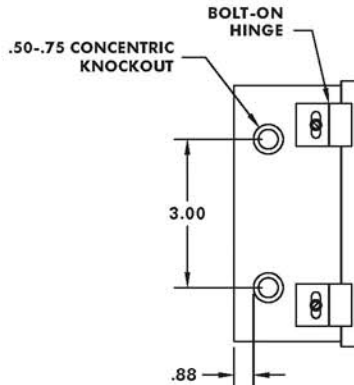

\* THE 1.00-1.25 CONCENTRIC KNOCKOUT IS USED WHEN H OR W = 12.00 INCHES OR MORE. \*



**CONSTRUCTION:**

- CODE GAUGE G-90U GRADE GALVANIZED STEEL
- HINGE COVERS ARE FASTENED WITH STEEL PLATED SCREWS
- BOLT-ON HINGE COVERS HAVE A FORMED STEEL ON SMALLER BOXES AND A BUTT HINGE ON LARGER HINGE BOXES

**FINISH:**

- E-BOX TYPE 1 SCREW COVER BOXES ARE PROVIDED IN GALVANIZED G-90U OR ANSI 61 GRAY POLYESTER POWDER COATING INSIDE AND OUT OVER PAINT GRIP GALVANIZED STEEL

# GALVANIZED AND PAINTED TYPE 1 BOXES

Screw Cover, Screw Cover w/KO's, Hinge Cover, Hinge Cover w/KO's



TYPE  
I

## GALVANIZED

**SC Suffix** = Galvanized Screw Cover

**NOTE:** Replace "SC" suffix with:

**SCKO** ..... Galvanized Screw cover w/KO's

**HC** ..... Galvanized Hinge cover

**HCKO** ..... Galvanized Hinge cover w/KO's

## PAINTED

**SC Suffix** = Galvanized Screw Cover

**NOTE:** Replace "SC" suffix with:

**SCP** ..... Painted Screw Cover

**SCPKO** ..... Painted Screw cover w/KO's

**HCP** ..... Painted Hinge cover

**HCPKO** ..... Painted Hinge cover w/KO's

Enclosure Size HxWxD	Catalog Number	Weight
4x4x4	444SC	2
6x4x4	644SC	2
6x6x4	664SC	3
8x6x4	864SC	4
8x8x4	884SC	5
10x6x4	1064SC	5
10x8x4	1084SC	5
10x10x4	10104SC	7
12x6x4	1264SC	6
12x8x4	1284SC	6
12x10x4	12104SC	7
12x12x4	12124SC	9
15x12x4	15124SC	11
15x15x4	15154SC	14
16x16x4	16164SC	16
18x12x4	18124SC	13
18x15x4	18154SC	16
18x18x4	18184SC	17
24x12x4	24124SC	15
24x18x4	24184SC	23
24x24x4	24244SC	35
30x24x4	30244SC	43
36x24x4	36244SC	51
6x6x6	666SC	4
8x6x6	866SC	5
8x8x6	886SC	6
10x8x6	1086SC	7
10x10x6	10106SC	9
12x8x6	1286SC	9
12x10x6	12106SC	10
12x12x6	12126SC	11
15x12x6	15126SC	13
15x15x6	15156SC	16
16x16x6	16166SC	18
18x12x6	18126SC	16
18x15x6	18156SC	17
18x18x6	18186SC	20
24x12x6	24126SC	21
24x18x6	24186SC	26
24x24x6	24246SC	39
30x24x6	30246SC	48
30x30x6	30306SC	56
36x24x6	36246SC	81
36x30x6	36306SC	94
* 36x36x6	36366SC	110
* 48x24x6	48246SC	101
* 48x36x6	48366SC	128
* 48x48x6	48486SC	234

**NOTE:** \* Size **not** available with KO'S

**FOR LARGE QUANTITIES CALL FACTORY**

*Continue on next Page*