

Product Code: HM204VKLQM4ISLT

Flow Designation: Scheme 0

Actuation: ISLT Oval Handle

Working Pressure: Max. 300 psi (2 MPa)

Body Size: 1/4"

Inlet Connection: Male Face Seal

Outlet Connection: Male Face Seal

Connection Size: 1/4"

Body Material: Bar Stock SS 316L Vim/Var

Temperature Range: -10°C to 60°C

Leak Rate - Inboard: $\leq 3 \cdot 10^{-11}$ atm · cc/sec (He)



Leak Rate - Across Seat: $\leq 1 \cdot 10^{-9}$ atm · cc/sec (He)

CV: 0.3

Seat Material: PCTFE

Actuator Type: ISLT Oval Handle

Limit Switch: No Limit Switch

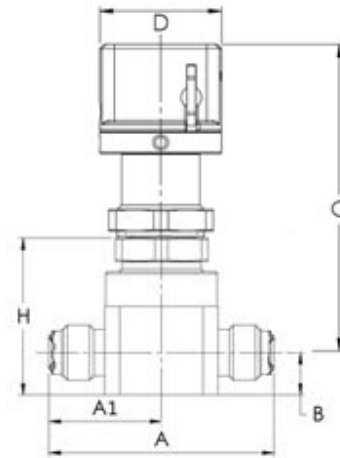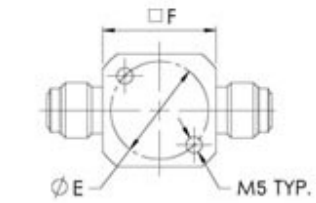

Param	inch	mm
A	2.30	58.4
A1	1.15	29.2
B	0.43	11
C	3	76
D	1.1	28
E	1	25.4
F	1.16	29.4
H	1.57	40

THIS DRAWING AND INFORMATION INCLUDED, ARE CONFIDENTIAL PROPERTY OF HAM-LET LTD AND ARE LOANED TO YOU FOR A LIMITED PURPOSE. NEITHER TO BE COPIED EXHIBITED OR FURNISHED TO OTHERS IN ANY FORM WITHOUT THE WRITTEN CONSENT OF HAM-LET LTD.

HAM-LET GROUP LTD
hl-info@uct.com

Part No. HM204VKLQM4ISLT

Catalog Number N/A

HM Series, Low Pressure UHP Manual Valve, Male Face Seal 1/4"