

**30W** | **USB-C**

**X30**

**X30B**



**X30W**



## COMPACT AND PORTABLE. XGRID USB-C CHARGER.

### 1 PORT

#### SINGLE-PORT DESIGN.

Experience efficient charging with 30 watts of dedicated power, delivering a fast and reliable charge for your device.

### USB-C

#### FAST CHARGING.

Experience the latest fast charging technologies - Power Delivery (PD), Quick Charge (QC), and Programmable Power Supply (PPS) - to charge up all your USB-C devices faster than ever.

### POWER SHARING

#### DYNAMIC POWER SHARING.

Seamlessly adjusts power distribution across the port, delivering the most efficient and safe charge to your device exactly when needed.



**NOCO**

30339 Diamond Parkway, #102  
Glenwillow, OH 44139 | USA  
1.800.456.6626

**no.co**

# CHARGE EVERYTHING.

## MEET THE XGRID X30.

A sleek, 1-port charger that delivers fast charging to all devices with intelligent power sharing, ensuring a safe and reliable charging experience - your all-in-one charging solution.

## CHARGE IN 4 EASY STEPS.



1. Unfold Prongs



2. Plug into Outlet



3. Plug Cord into Charger



4. Plug into Device



## INTELLIGENT SAFEGUARDS.



An advanced charger that continuously monitors and adjusts, ensuring precise charging while protecting your devices from overcharging or overheating.



## ALL-IN-ONE CHARGING SOLUTION.

Designed to charge any USB-powered device - from smartphones and tablets to laptops, cameras, headphones, earpods, drones, and more.

## WHAT'S IN THE BOX

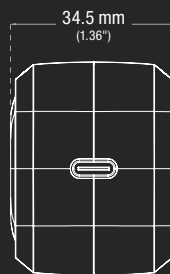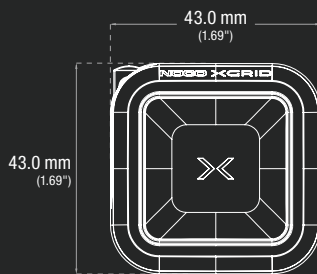

\*Manuals not to scale with X30



Quick Start Guide



Safety and Warranty Information

## TECHNICAL SPECIFICATIONS

|                                |                                                                                                                                                                                                                                                                                                                                                                       |
|--------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| OPERATING INPUT VOLTAGE RANGE: | 100-240VAC                                                                                                                                                                                                                                                                                                                                                            |
| AC LINE FREQUENCY:             | 50-60HZ                                                                                                                                                                                                                                                                                                                                                               |
| USB-C VERSION:                 | USB-C PD 3.0                                                                                                                                                                                                                                                                                                                                                          |
| USB-C WATTAGE:                 | 30W                                                                                                                                                                                                                                                                                                                                                                   |
| IP RATING:                     | IP20                                                                                                                                                                                                                                                                                                                                                                  |
| OPERATING TEMPERATURE:         | 32° to 104°F (0° to 40°C)                                                                                                                                                                                                                                                                                                                                             |
| STORAGE TEMPERATURE:           | -4° to 176°F (-20° to 80°C)                                                                                                                                                                                                                                                                                                                                           |
| WEIGHT:                        | 0.15 lbs (0.07 kg)                                                                                                                                                                                                                                                                                                                                                    |
| VOLUMETRICS:                   | <div> <b>Retail Packaging:</b><br/> Dimensions: 3.72" x 3.68" x 1.63"<br/> Weight: 0.35 lbs<br/> UPC: 0-46221-24001-6 </div> <div> <b>Master Carton:</b><br/> Dimensions: 8.27" x 6.50" x 4.65"<br/> Weight: 2.66 lbs<br/> Quantity: 6<br/> UCC: 10046221240013 </div> <div> <b>Inner Carton:</b><br/> Dimensions: 3.84" x 1.91" x 3.98"<br/> Weight: 0.39 lbs </div> |

NOCO

30339 Diamond Parkway, #102  
Glenwillow, OH 44139 | USA  
1.800.456.6626

no.co



CONFORMS TO UL STD. 62368-1  
CERTIFIED TO CSA STD. C22.2 No. 62368-1