


KA31U2N, AL Set Screw Connector, 1-Conductor, 2-Hole

By Burndy
Catalog # [KA31U2N](#)

Accommodates: #6 Str-350 kcmil, 2-Hole, 1/2" Stud, 1.75" Spacing, Dual Rated

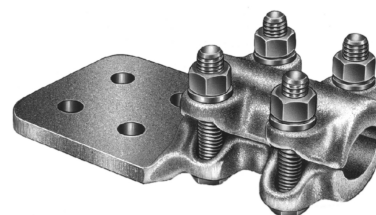

Features

- Dual rated panelboard lugs constructed from high strength extruded aluminum alloy , electro tin-plated to provide low contact resistance

Specifications

Certification - ETL	No
Certification - UL Recognized	No
Standards - Industry Standards Met	UL 486A-486B
Standards - RoHS Compliance Status	CM
Certification - cULus	No
Industry Standard(s)	UL 486A-486B
UL Listed	Yes
Certification - CSA Approved	Yes

Conductor

Conductor Size	6 AWG-350 KCMIL
Number Of Conductors	1
Conductor - AL Str Size Range	6 Str. - 350Kcmil
Conductor Type	- CU C Str-Size - AL C Str-Size
Conductor - Copper Str Size Range	6 Str. - 350Kcmil

Configuration

Physical Attribute - Number of Screws	1
Physical Attribute - Number of Holes	2
Connector Type	Terminal

Dimensions

Package Height	0.000 in
----------------	----------

Dimension - Height mm	0 mm
Dimension - Bolt Size fraction	1/2
Dimension - Height inch	1.38 in
Package Weight	0.000 lb.
Dimension - Width inch	1.25 in
Package Length	0.000 in
Dimension - E Spacing between Holes fraction	1-3/8 in
Package Width	0.000 in
Dimension - L Length Overall mm	114 mm
Dimension - Hole Size mm	14 mm
Dimension - Hole Size inch	0.56 in
Dimension - Length Overall inch	4.50 in

General

Physical Attribute - Screw Type	Allen
Plated	Y
UPC	781810125069
Type	Bolted Lugs & Terminals
Material	Aluminum
Plating Type	Tin
UPC 14 Digit GTIN	00781810125069

Logistics

Minimum Pack Quantity	50
Pallet Quantity	1
Carton Quantity	50

Operational

Temperature Rating	194
--------------------	-----

Product Assets

[Catalog \[English\]](#)