



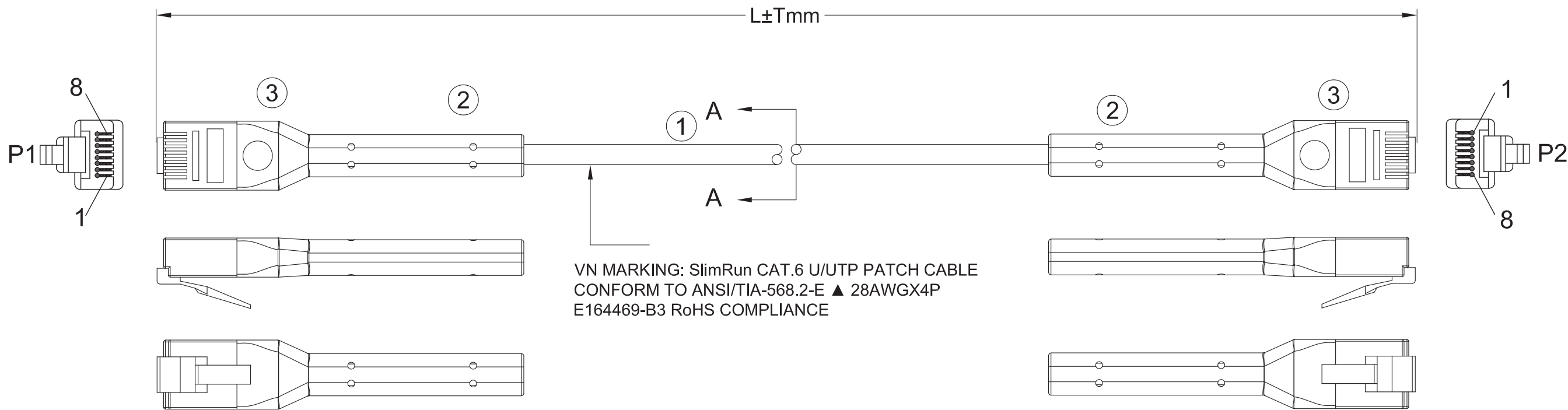

orange 2 white/orange	green 3 white/green
blue 1 white/blue	brown 4 white/brown

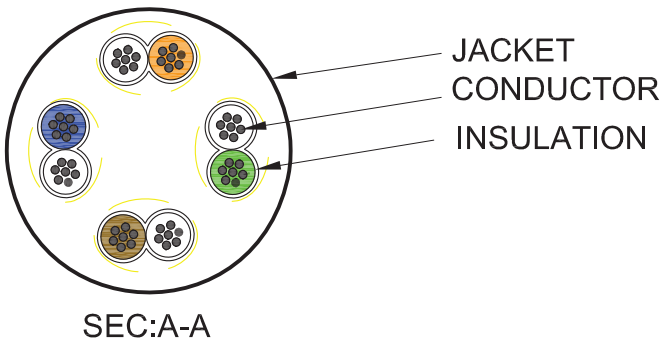

NOTE:
1.ELECTRICAL TEST:
<1> 100% OPEN SHORT & MISS WIRE TEST.
<2> FLUKE CHANNEL LEVEL 1DB↑
<3> CONDUCTOR RESISTANCE: L≤10M 10ΩMAX
10<L≤20M 15ΩMAX
20<L≤40M 25ΩMAX

Conductor		Bare Copper 28AWG (7/0.12±0.008mmBC)*4P
INSULATION		Thickness:MIN at any point:0.2mm MAX AVG:0.3mm Diameter:0.60±0.06mm
Jacket	PVC	Thickness:MIN at any point:0.50mm MAX AVG:0.60mm Diameter:3.6±0.2MM

3	RJ45 PLUG	RJ45 PLUG: 8P8C 50U" GOLD PLATED TWO-PIECE PLUG.		
2	MOLDED	PVC MOLDED BOOT.		
1	CABLE	CAT6 UTP 4P/28AWG(7/0.12±0.008MM BC) OD=3.6±0.20MM CM PVC JACKET		
NO.	PART NAME	SPECIFICATION DESCRIPTION	QTY	UNIT

PA/R	PINOUT		
	P1(T568B)	WIRE	P2(T568B)
2	1	WHT/ORG	1
	2	ORG	2
3	3	WHT/GRN	3
	6	GRN	6
1	4	BLU	4
	5	WHT/BLU	5
4	7	WHT/BRN	7
	8	BRN	8



DESCRIPTION :
Monoprice™ Cat6 Ethernet Patch Cable - Bendable UTP 28AWG

PID # : 49037 - 49076

DATE :	UNIT : FT / IN / MM	FILE NAME:
--------	---------------------	------------

RoHS COMPLIANT					REVISION INFORMATION		
					Rev.	Rev. Date	Brief Description

PID	Length	Color
49037	0.5ft(6")	GRAY
49038	1ft(12")	GRAY
49039	2ft(24")	GRAY
49040	3ft(36")	GRAY
49041	5ft(60")	GRAY
49042	0.5ft(6")	GREEN
49043	1ft(12")	GREEN
49044	2ft(24")	GREEN
49045	3ft(36")	GREEN
49046	5ft(60")	GREEN
49047	0.5ft(6")	ORANGE
49048	1ft(12")	ORANGE
49049	2ft(24")	ORANGE

49050	3ft(36")	ORANGE
49051	5ft(60")	ORANGE
49052	0.5ft(6")	RED
49053	1ft(12")	RED
49054	2ft(24")	RED
49055	3ft(36")	RED
49056	5ft(60")	RED
49057	0.5ft(6")	YELLOW
49058	1ft(12")	YELLOW
49059	2ft(24")	YELLOW
49060	3ft(36")	YELLOW
49061	5ft(60")	YELLOW
49062	0.5ft(6")	BLACK
49063	1ft(12")	BLUE

49064	2ft(24")	BLACK
49065	3ft(36")	BLACK
49066	5ft(60")	BLACK
49067	0.5ft(6")	BLUE
49068	1ft(12")	BLUE
49069	2ft(24")	BLUE
49070	3ft(36")	BLUE
49071	5ft(60")	BLUE
49072	0.5ft(6")	WHITE
49073	1ft(12")	WHITE
49074	2ft(24")	WHITE
49075	3ft(36")	WHITE
49076	5ft(60")	WHITE

NO.	PART NAME	SPECIFICATION DESCRIPTION	QTY	UNIT

 MONOPRICE

DESCRIPTION :
Monoprice™ Cat6 Ethernet Patch Cable - Bendable UTP 28AWG

PID # :
49037 - 49076

DATE :UNIT :FILE NAME:

FT / IN / MM