



# Vista Pivot™ II

Framed pivot shower door  
1500D-36

## Features

- Framed, 1/8" (3 mm) thick tempered glass.
- Out-of-plumb adjustability.
- Tempered glass ensures maximum safety and durability.
- Anodized aluminum prevents rusting and corrosion.
- 7" (178 mm) inline panel 5/32" (4 mm) thick.

## Installation

- Not for use in hospitality.
- For residential use only.

## Recommended Products/Accessories

K-23723 Faucet cleaner

## Included Components

Additional Components:  
Hardware kit



## Codes/Standards

ANSI Z97.1  
CPSC 16CFR 1201


## STERLING® Warranty - Bath and Shower Doors

See website for detailed warranty information.

## Available Colors/Finishes

*Color tiles intended for reference only.*

Color	Code	Description
-------	------	-------------

	S	Silver
--	---	--------

## Available Glass Options

Code	Description
------	-------------

	Pebbled
--	---------

---


1-800-STERLING (1-800-783-7546)

Kohler Co. reserves the right to make revisions without notice to product specifications.

For the most current Specification Sheet, go to [www.sterlingplumbing.com](http://www.sterlingplumbing.com).

3-22-2020 05:32 - US/CA

**Vista Pivot™ II**  
Framed pivot shower door  
**1500D-36**

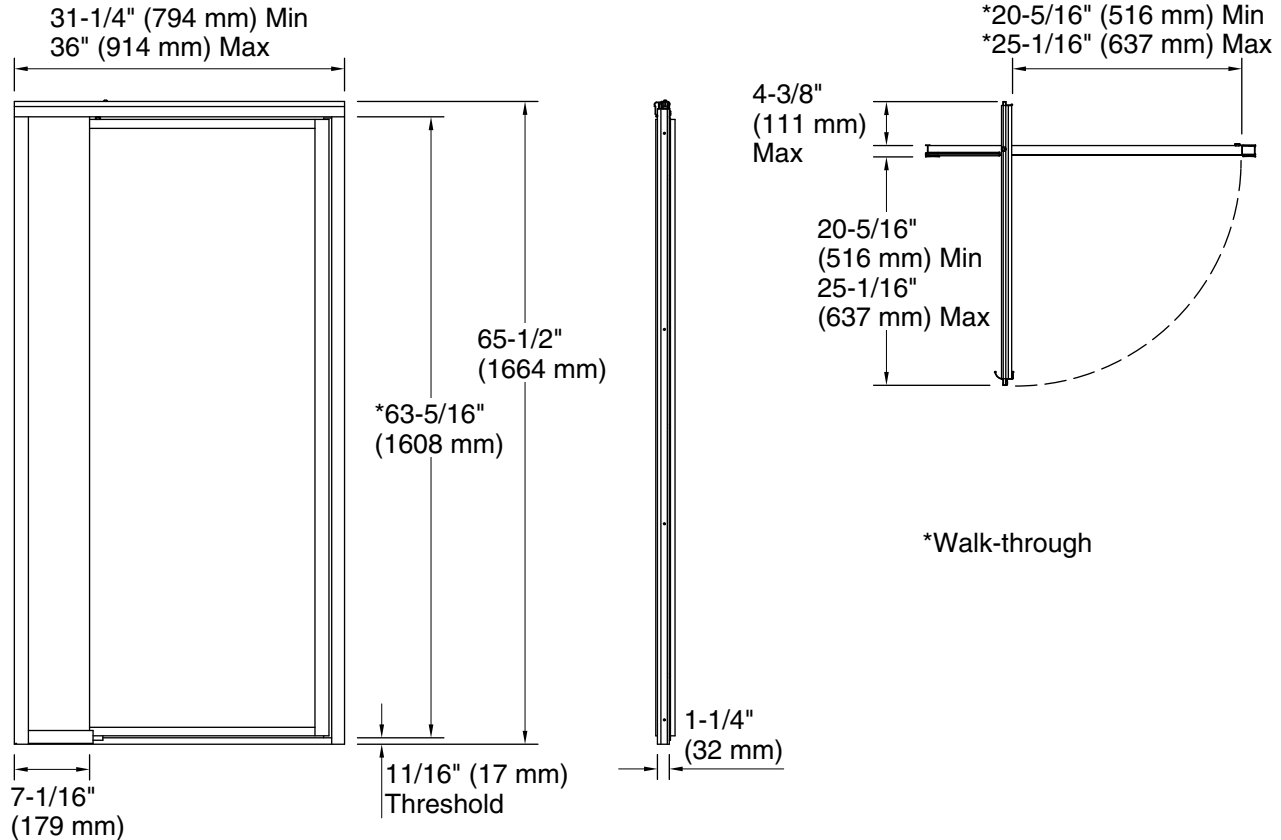

\*Walk-through

**Technical Information**

All product dimensions are nominal.

Installation type: For shower base installation

Opening Width - Min: 31-1/4" (794 mm)

Opening Width - Max: 36" (914 mm)

Walk-through - Min: 20-5/16" (516 mm)

Walk-through - Max: 25-1/16" (637 mm)

Base-To-Wall Radius 3/8" (10 mm)

– Max:

Glass thickness: 1/8" (3 mm)

**Notes**

Install this product according to the installation guide.

The vertical opening should be a minimum of 67" (1702 mm) to allow for installation clearance.