



GAR1529, Mech Grounding Connector, Cable to Rod or Pipe

By Burndy
Catalog # [GAR1529](#)

Mechanical Grounding Connector, Cable to Rod or Pipe, 2/0 AWG (Sol) -250 kcmil, 1" Pipe, 1-1/8"-1-1/4" Rod, #9-#10 Rebar

Features

- Parallel or 90° Copper Cable Connection
- One-wrench installation
- Rated for Direct Burial in earth or concrete

Application


For Joining A Range Of Cable, Parallel Or At Right Angles To Rod Or Tube, Direct Burial Cable, Fence Post

Specifications

Certification - UL Recognized	No
Buy American Compliant	No
Certification - cULus	No
EU RoHS Indicator	Yes
Industry Standard(s)	UL467
Certification - ETL	No
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
Certification - UL Listed Direct Burial	Yes
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Rebar Size	9-10
Conductor - Pipe or Round Tube Size Range	1 in
Conductor - Rebar Size Range	9-10
Conductor - Rod Size Range	1 1/8 in-1 1/4 in
Conductor - Copper Str Size	250 Kcmil
Conductor - Rod Size	1.120-1.31 in
Conductor - Copper Solid Size	2/0 AWG
Conductor - Copper Solid Size Range	2/0 AWG-4/0 AWG
Conductor Type	• CU C Solid-Size • CU C Str-Size • CU Tube Std-Size • Rod-Size
Conductor - Copper Str Size Range	1/0 AWG - 250 kcmil
Conductor - Copper Tube Std Size Range	1 IPS IPS

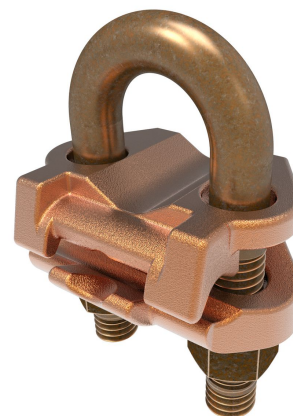

Conductor - Copper Tube Std Size 1 IPS IPS

Dimensions

Package Height	0.000 in
Dimension - Height mm	85.9 mm
Dimension - Height inch	3.38 in
Dimension - Height fraction	3-3/8 in
Package Weight	0.000 lb.
Package Length	0.000 in
Package Width	0.000 in
Dimension - L Length Overall mm	46 mm
Dimension - Outside Diameter inch	1.31 in
Dimension - Width fraction	2-5/8 in
Dimension - Width mm	67 mm
Dimension - Width inch	2.62 in
Dimension - B Length inch	1.75 in
Dimension - Length Overall inch	1.81 in

Force Related

Installation Torque Recommended in-lb	240 LBS/in
Installation Torque Recommended Run in-lb	240 Lb in

General

Material - Hardware Plated	DURIUM™ Silicon Bronze N
Sub Brand	MECHANICAL CONNECTOR
UPC	781810232804
Type	GAR
U Bolt Type	244
Material	Copper
Plating Type	Bright Dipped
UPC 12 Digit	781810232804
UPC 14 Digit GTIN	00781810232804

Logistics

Minimum Pack Quantity	1
Pallet Quantity	1275
Carton Quantity	25



A Hubbell brand