



# YONAH™

## 3rd Gen



Beyond LED Yonah 3rd Gen Linkable T8 LED Integrated Lamps perform efficiently in conditions where low voltage, halogen, or fluorescent luminaires have traditionally been used. Our LED tubes incorporate integral drivers, are self-supporting and can be surface mounted. Individual units can be plugged together for continuous lengths up to 200W. Our Yonah 3rd Gen Lamps connect directly to line voltage and can be used in any interior space.

### Product Features

- Efficacy up to 140 Lumens per watt
- 6 Wattages Adjustable 18W/20W/22W/25W/28W/30W
- 6 CCT Adjustable 3K/3500K/4K/5K/6K/6500K
- Operates directly from line voltage
- Usable as a stand alone fixture
- Linkable up to 200W at AC120V
- Aluminum and PC housing
- Input Voltage 100-277Vac 50-60Hz
- ETL Listed
- 5 Year warranty

# YONAH™

## 3rd Gen



SKU #	Model #	Wattage Adjustable	Lumens	CCT Adjustable	Size	Lens	Input Voltage	Certifications
156779	BLT-T8-30P4FT-INT2-MM	18W/20W/22W/25W/28W/30W	Max 4200Lm	3K/3500K/4K/5K/6K/6500K	4FT	Frosted	100-277Vac	ETL
156829	BLT-T8-30P4FT-INT2-CM	18W/20W/22W/25W/28W/30W	Max 4200Lm	3K/3500K/4K/5K/6K/6500K	4FT	Clear	100-277Vac	ETL
156830	BLT-T8-30P4FT-INT2-SM	18W/20W/22W/25W/28W/30W	Max 4200Lm	3K/3500K/4K/5K/6K/6500K	4FT	Strip	100-277Vac	ETL
156780	BLT-T8-60P8FT-INT2-MM	40W/45W/48W/52W/56W/60W	Max 8400Lm	3K/3500K/4K/5K/6K/6500K	8FT	Frosted	100-277Vac	ETL
156831	BLT-T8-60P8FT-INT2-CM	40W/45W/48W/52W/56W/60W	Max 8400Lm	3K/3500K/4K/5K/6K/6500K	8FT	Clear	100-277Vac	ETL

### Size: 4FT

### Specifications

Parameter	Description	Value
General Performance	Wattage Adjustable	18W/20W/22W/25W/28W/30W
	Lumen	4200Lm
	Lumen Efficacy	Up to 140LM/W
	Color Temperature	3K/3500K/4K/5K/6K/6500K
	CRI (Ra)	>80
	Beam Angle	180° Degree
Electrical	Diffuser Type	Frosted / Clear / Strip
	Input Voltage	100-277Vac
	Frequency	50/60Hz
	Power Factor	≥0.95
Physical	Operating Temperature	N/A
	Operating Humidity	N/A
	Storage Temperature	N/A
	LED Type	N/A
Qualification	Housing Material	Aluminium + PC
	Housing Color	N/A
	IP Rating	N/A
	Warranty	5 Year



# YONAH™

## 3rd Gen

Size: 8FT

### Specifications

Parameter	Description	Value
General Performance	Wattage Adjustable	40W/45W/48W/52W/56W/60W
	Lumen	7800Lm
	Lumen Efficacy	Up to 140LM/W
	Color Temperature	3K/3500K/4K/5K/6K/6500K
	CRI (Ra)	>80
	Beam Angle	180° Degree
Electrical	Diffuser Type	Frosted / Clear
	Input Voltage	100-277Vac
	Frequency	50/60Hz
	Power Factor	≥0.95
Physical	Operating Temperature	N/A
	Operating Humidity	N/A
	Storage Temperature	N/A
	LED Type	N/A
Qualification	Housing Material	Aluminium + PC
	Housing Color	N/A
	IP Rating	N/A
	Warranty	5 Year

### Optional Accessories (Cable)

SKU: 156846  
(1FT)



SKU: 156847  
(2FT)



# YONAH™

## 3rd Gen



### Accessories

Linkable Options




Mounting Clips



Linkable Options Mounting Clips



### Installation, Hanging

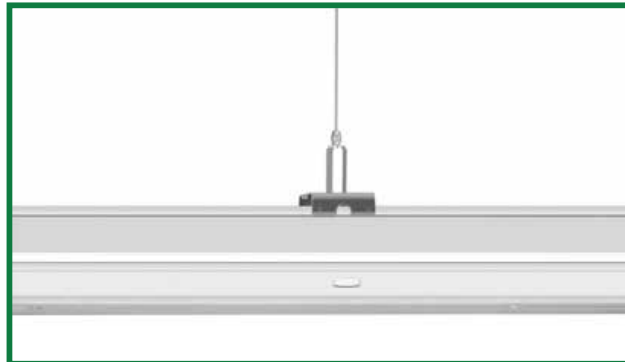


LED LINKABLE FIXTURES





# YONAH™

## 3rd Gen

### Correlated Color Temperature (CCT)

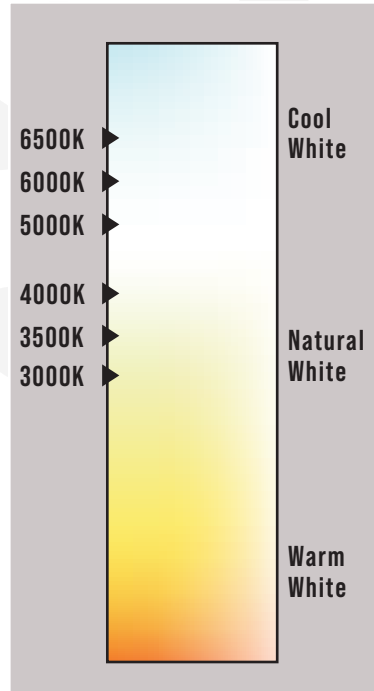

### Dimension

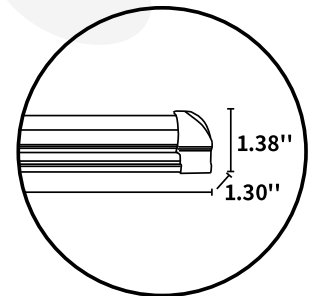 

LED LINKABLE FIXTURES





# YONAH™

## 3rd Gen



Size: 4FT

Photometric Data

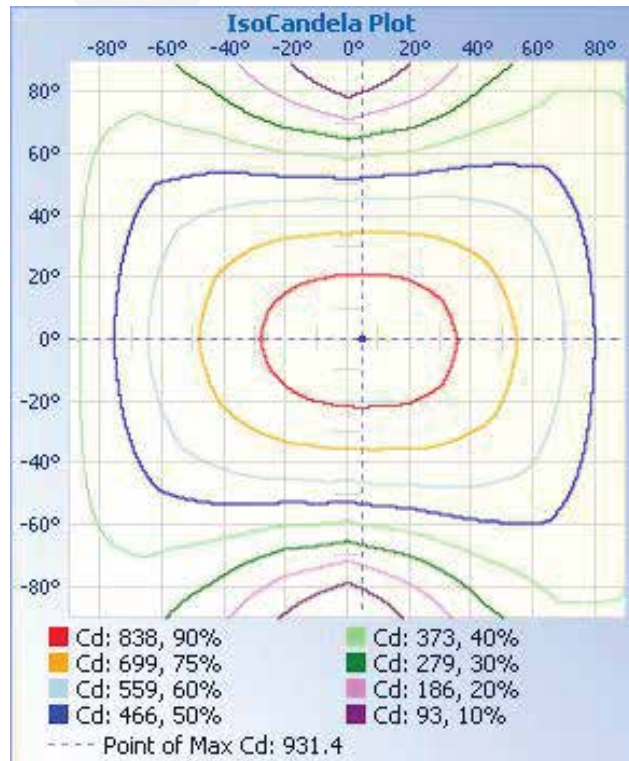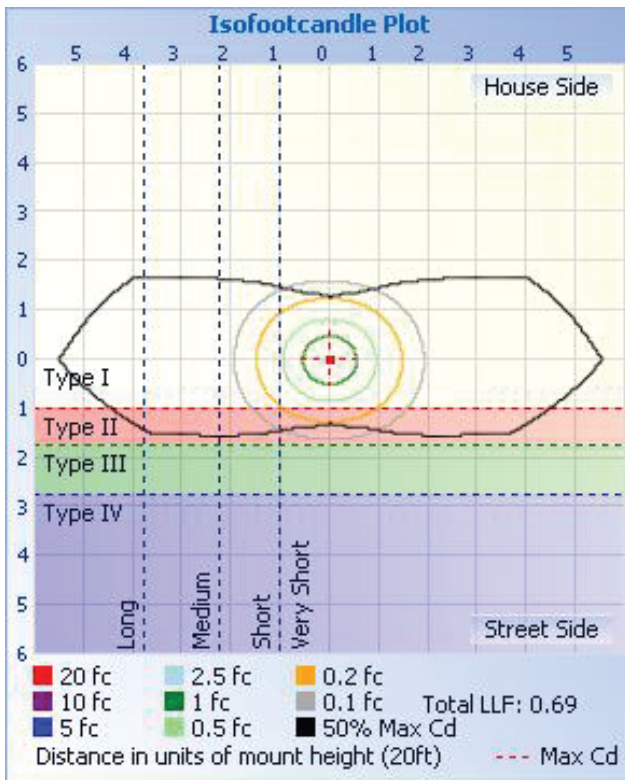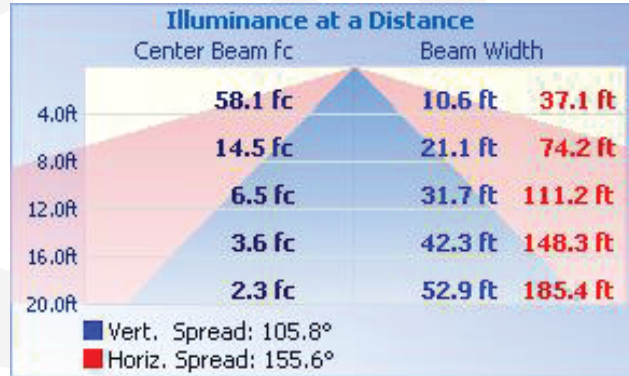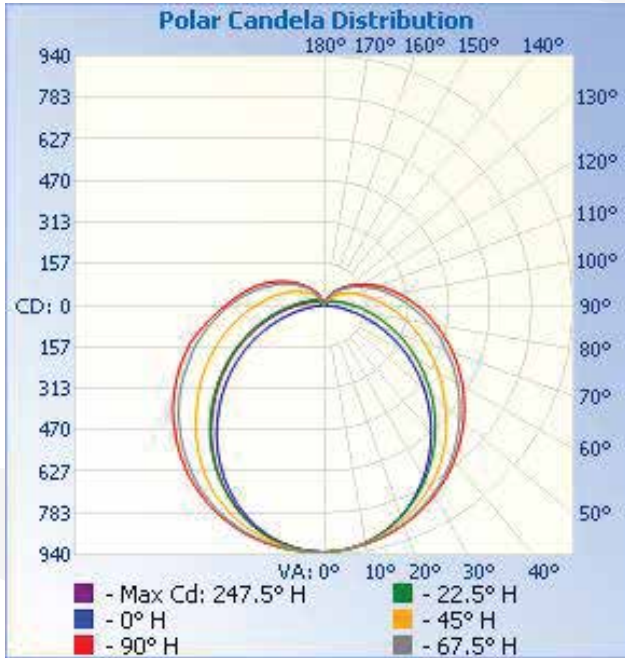

LED LINKABLE FIXTURES



# YONAH™


## 3rd Gen

### Installation


#### Installation Guide for Surface Mounted LED Tube Integrated T8

This is LED surface mounted light. Please take the time to read this quick installation guide. The guide contains important information and notes regarding installation and operation.

#### 1. Accessories bag includes:

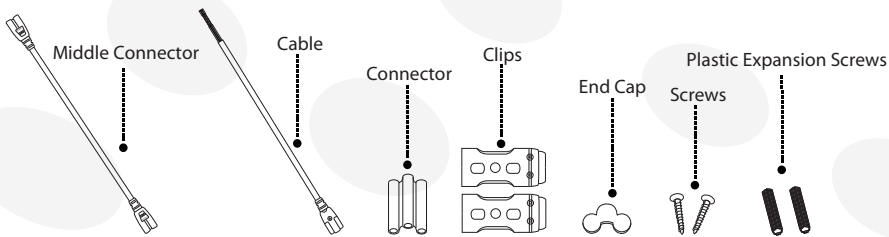


#### 2. Cable connection instruction


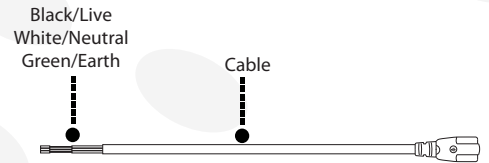


#### 3. Installation Instructions

1. Confirm the buckle's position on the wall

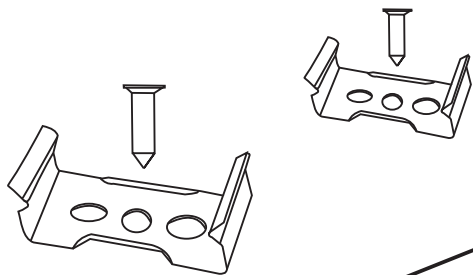

2. Screw the buckles on the wall

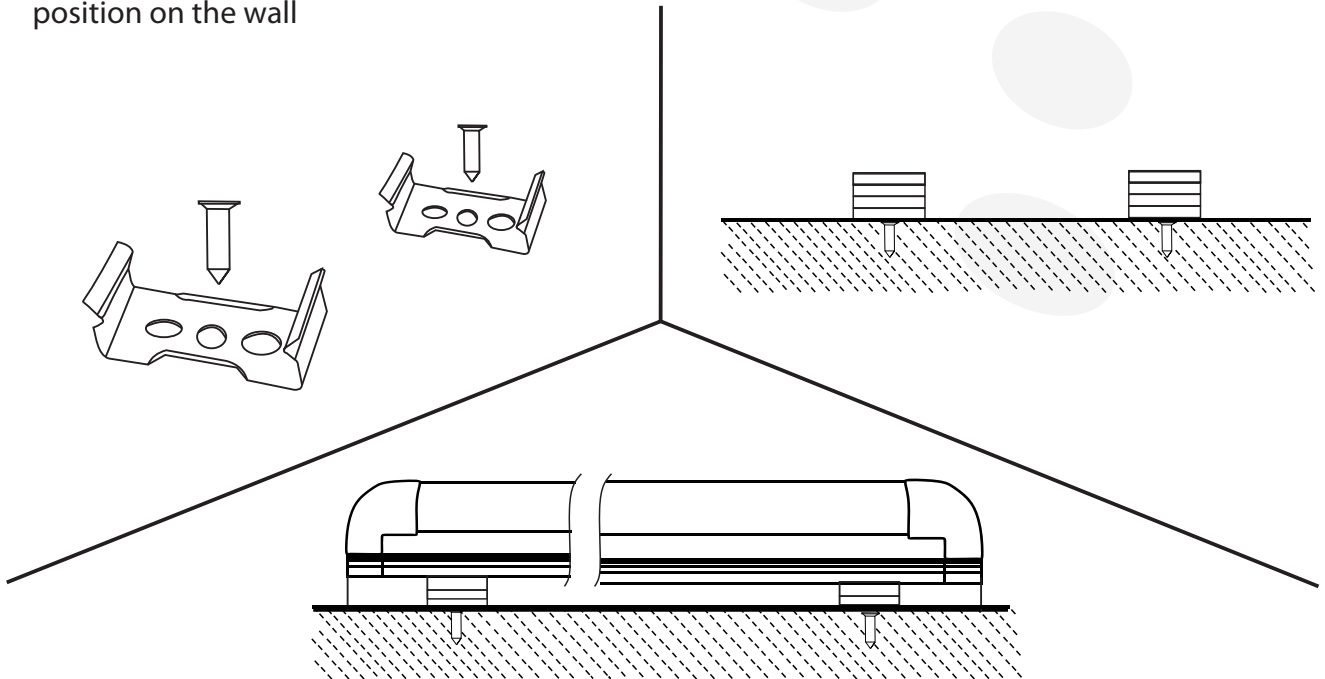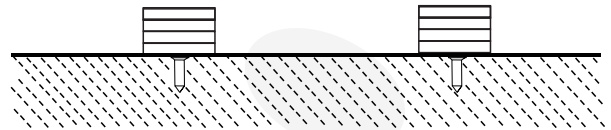


# YONAH™

## 3rd Gen




### Installation

#### Connection Installation

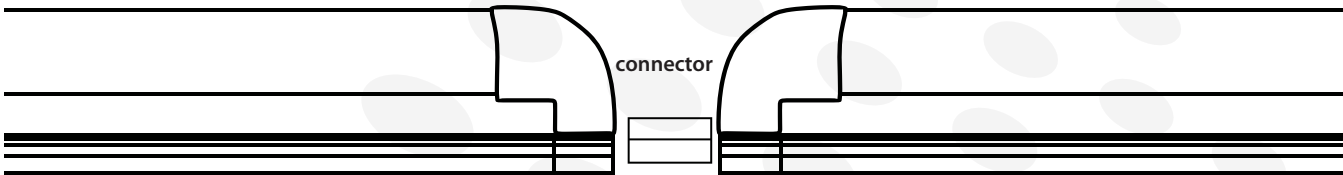

1. Please find the connector in the accessories bag

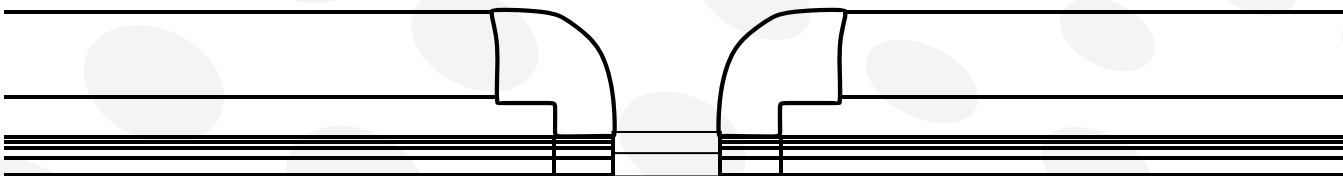

2. Plug the connector into the tube

#### Notes:

For safety standard, in a row please do not connect more than 300w (add up) at 120VAC, do not connect more than 600w (add up) at 220-277VAC.

#### Warnings

End cap: Please insert the END CAP at the end of last connection lamp as isolation protection. This product must be installed in accordance with the applicable installation code by a person familiar with the construction and operation of the product and hazards involved. Risk of fire or electric shock. LED tube installation requires knowledge of luminaries' electrical systems. If not qualified, do not attempt installation. Contact a qualified electrician.

Do not use with dimmers.

Small noises when shaking does not affect the quality.

3. Fix the light into the buckles



# YONAH™

## 3rd Gen

### Packaging

SKU#	Size	Dimension (Inches)	Qty	Net Weight	Gross Weight
156779	4FT	49.21x 8.66 x 7.87	20 Pcs/Box	14.53 LBS	17.86 LBS
156829	4FT	49.21x 8.66 x 7.87	20 Pcs/Box	14.53 LBS	17.86 LBS
156830	4FT	49.21x 8.66 x 7.87	20 Pcs/Box	14.53 LBS	17.86 LBS
156780	8FT	95.28 x 8.27 x 7.48	20 Pcs/Box	28.66 LBS	33.40 LBS
156831	8FT	95.28 x 8.27 x 7.48	20 Pcs/Box	28.66 LBS	33.40 LBS




# YONAH™

## 3rd Gen



### Application Picture

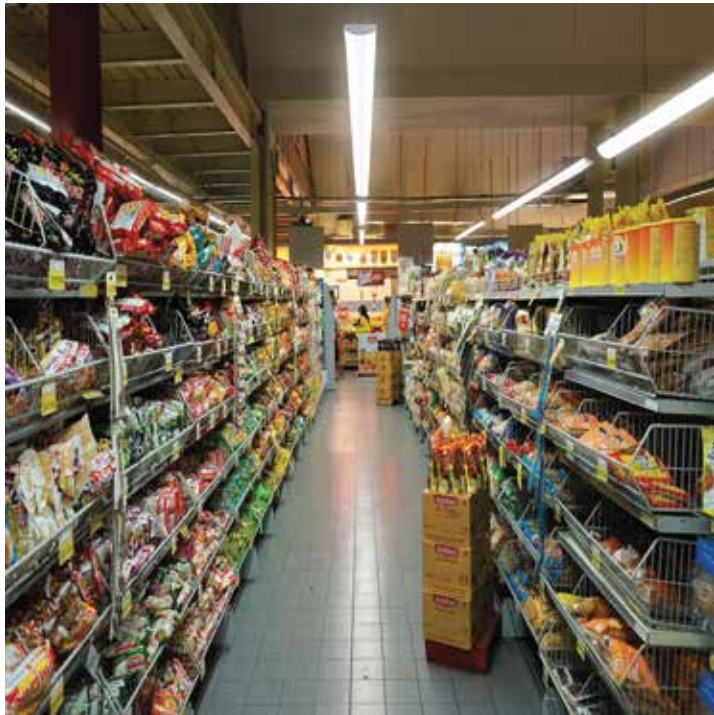

### Warranty

5 Year Warranty

LED LINKABLE FIXTURES