



Nuvo Lighting's Laguna two-tier, nine light chandelier in Aged Bronze with white glass. Nuvo item number 60-5929. [www.nuvolighting.com](http://www.nuvolighting.com)

## Enduring solutions.


Incandescent lamps represent the original lighting technology, remaining virtually unchanged since their invention in the mid-19th century, and the lighting technology Satco was founded upon. This is the technology most everyone has become familiar with and the baseline comparison for all other lighting technologies. As the incandescent bulb becomes more and more regulated, Satco remains on the cutting edge of new lighting technologies. Still, we remain well-stocked with incandescent lamps in a multitude of wattages, base sizes, and shapes for every application.

### Incandescent lamp features:

- High lumen output
- Up to 5,000 hour life
- Virtually every size and style imaginable
- Wattages from 3 to 500 Watts
- Durable vibration and rough service products
- Colored and special application types



Nuvo Lighting's Neval five light chandelier in Brushed Nickel with Satin White Glass. Nuvo item number 60-5485. See the [www.nuvolighting.com](http://www.nuvolighting.com) website.

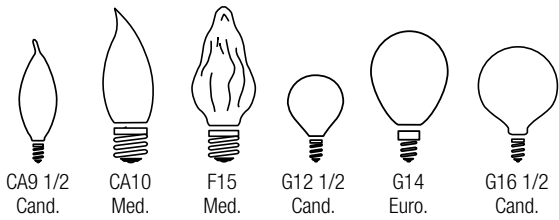

Watts	Bulb Type	Base	Satco Prod. #	Lamp Code	Volts	Finish	M.O.L. Inches	Filament	Initial Lumens	Avg. Rated Hours	Pkg. Type	Master/Inner Carton	Notes	
40	CA9 1/2	Cand.	S3275	40CA9 1/2	120	Clear	3 7/8	CC-2V	370	1500	Box	500/25		
			S3775	40CA9 1/2	120	Clear	3 7/8	CC-2V	370	1500	CD/2	120/10		
			S4466	KR40CA9 1/2	120	Clear	3 15/16	CC-2V	380	2500	Box	500/25	1	
			A3675	40CA9 1/2	130	Clear	3 15/16	CC-2V	370	2500	Box	500/25		
			S3279	40CA9 1/2/F	120	Frost	3 15/16	CC-2V	384	1500	Box	500/25		
			S3779	40CA9 1/2/F	120	Frost	3 15/16	CC-2V	384	1500	CD/2	120/10		
	CA10	Med.	A3679	40CA9 1/2/F	130	Frost	3 15/16	CC-2V	350	2500	Box	500/25		
			S3265	40CA10	120	Clear	4 ¼	CC-2V	370	1500	Box	500/25		
			S3765†	40CA10	120	Clear	4 ¼	CC-2V	370	1500	CD/2	120/10		
			A3665	40CA10	130	Clear	4 ¼	CC-2V	360	2500	Box	500/25		
			S3268	40CA10/F	120	Frost	4 ¼	CC-2V	360	1500	Box	500/25		
			S3768	40CA10/F	120	Frost	4 ¼	CC-2V	360	1500	CD/2	120/10		
	F15	Med.	A3668	40CA10/F	130	Frost	4 ¼	CC-2V	360	2500	Box	500/25		
			S3367	40F15	120	Clear	4 ½	CC-9	350	1500	Box	300/25		
			S2767	40F15	120	Clear	4 ½	CC-9	350	1500	CD/2	120/12		
			S2768	40F15/W	120	White	4 ½	CC-9	320	1500	CD/2	120/12		
			S3368	40F15/W	120	White	4 ½	CC-9	320	1500	Box	300/25		
			S3369	40F15/AU	120	Aurora	4 ½	CC-9	335	1500	Box	300/25		
	G12 1/2	Cand.	S2769	40F15/AU	120	Aurora	4 ½	CC-9	335	1500	CD/2	120/12		
			S3370	40F15/A	120	Amber	4 ½	CC-9	–	1500	Box	300/25		
			S2770	40F15/A	120	Amber	4 ½	CC-9	–	1500	CD/2	120/12		
S3847			40G12 1/2	120	Clear	2 3/8	C-7A	370	1500	Box	500/25			
G14			Euro.	S3397	40G14	130	Clear	3 1/8	CC-9	370	1500	Box	500/25	
				S4707	40G14	130	Clear	3 1/8	CC-9	370	1500	CD/2	120/10	
	S3398	40G14/W		130	Gloss White	3 1/8	CC-9	330	1500	Box	500/25			
	S4708	40G14/W		130	Gloss White	3 1/8	CC-9	330	1500	CD/2	120/10			
G16 1/2	Cand.	S3823	40G16 1/2	120	Clear	3	CC-2V	384	1500	Box	500/25			
		S3728	40G16 1/2	120	Clear	3	CC-2V	384	1500	CD/2	120/10			
		A3923	40G16 1/2	130	Clear	3	CC-2V	360	2500	Box	500/25			
		S3754	40G16 1/2/W	120	Satin White	3	CC-2V	348	1500	CD/2	120/10			
		S3826	40G16 1/2/W	120	Satin White	3	CC-2V	348	1500	Box	500/25			
		A3926	40G16 1/2/W	130	Satin White	3	CC-2V	325	2500	Box	500/25			
		S3261	40G16 1/2/W	120	Gloss White	3	CC-2V	348	1500	Box	500/25			
		S2974 ■	40G16 1/2/VLX	120	Full Spectrum	3	CC-2V	370	2000	CD/1	50/10	3		
S3245	40G16 1/2/SL	120	Silver Crown	3	CC-2V	384	1500	Box	500/25					

NOTE: When using a 130 Volt lamp on a 120 Volt line, life is extended approximately 2.5 times and lumens are reduced approximately 20%.