

## Popular for good reason.

Halogen lamps come in more sizes, shapes, and base variations than most other technologies, and with good reason – brilliant white light, great color temperature, and color rendering properties, long life, and superior lumen maintenance combine to make them very popular. Satco stocks virtually every variation there is. Our wide inventory allows you to get the types you need, whether a specialty size or an incandescent A19 replacement, that meets government regulations. When it comes to Halogen lamps, we can confidently say “Yes, we have that.”

### Halogen lamp features:


- Available from 5 to 1500 Watts
- From 6 to 240 Volt variations
- All industry standard sizes and bases
- Fully dimmable
- Environmentally friendly – Mercury free
- Energy efficient
- Our Halogen Excel line saves up to 30% in energy costs over traditional incandescent lamps
- Halogen/Xenon technology for enhanced performance in our Halogen Excel™ line
- Excellent color rendering
- High lumen output



Nuvo Lighting's Lynne five light vanity in Polished Nickel with Frosted Glass. Nuvo item number 60-5178. See the [www.nuvolighting.com](http://www.nuvolighting.com) website.



HALOGEN

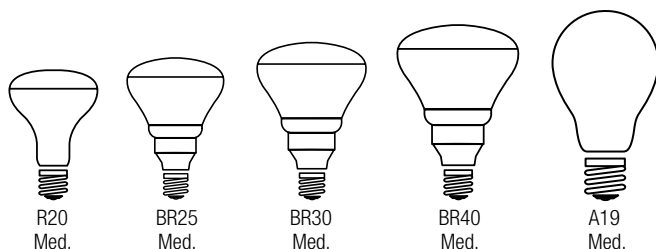

## R20, BR25, BR30 & R40 Reflector 120 & 130 Volt – Halogen

| Watts     | Bulb Type | Base | Satco Prod. # | Lamp Code          | Beam Pattern | Volts | Finish | M.O.L. Inches | Initial Lumens | Avg. Rated Hours | Pkg. Type | Carton |
|-----------|-----------|------|---------------|--------------------|--------------|-------|--------|---------------|----------------|------------------|-----------|--------|
| <b>45</b> | R20       | Med. | <b>S4514</b>  | 45R20/FL/HAL       | FL 70        | 120   | Frost  | 4             | 560            | 2000             | Sleeve    | 48/6   |
|           |           |      | <b>S4414</b>  | 45R20/FL/HAL/130V  | FL 70        | 130   | Frost  | 4             | 540            | 2000             | Sleeve    | 48/6   |
|           | BR25      |      | <b>S2451</b>  | 45BR25/FL/HAL/120V | FL 70        | 120   | Frost  | 4 ¾           | 560            | 2000             | Box       | 24/12  |
| <b>65</b> | BR30      | Med. | <b>S4515</b>  | 65BR30/FL/HAL      | FL 80        | 120   | Frost  | 5 3/8         | 920            | 2000             | Sleeve    | 48/6   |
|           |           |      | <b>S4415</b>  | 65BR30/FL/HAL/130V | FL 80        | 130   | Frost  | 6 ½           | 900            | 2000             | Sleeve    | 48/6   |
|           | BR40      | Med. | <b>S4516</b>  | 65BR40/FL/HAL      | FL 90        | 120   | Frost  | 6 ½           | 920            | 2000             | Sleeve    | 24/6   |
|           |           |      | <b>S4416</b>  | 65BR40/FL/HAL/130V | FL 90        | 130   | Frost  | 6 ½           | 900            | 2000             | Sleeve    | 24/6   |

## Halogen A19

### Halogen/Excel A19 Replacements

| Watts     | Bulb Type | Base | Satco Prod. # | Incand. Equiv. | Lamp Code                | Volts | Finish | M.O.L. Inches | Initial Lumens | Avg. Rated Hours | Pkg. Type | Master/ Inner Carton |
|-----------|-----------|------|---------------|----------------|--------------------------|-------|--------|---------------|----------------|------------------|-----------|----------------------|
| <b>29</b> | A19       | Med. | <b>S2401</b>  | 40W            | 29A19/HAL/ES/CL/120V/2PK | 120   | Clear  | 4 ½           | 430            | 1000             | Box       | 12/2                 |
|           |           |      | <b>S2405</b>  | 40W            | 29A19/HAL/ES/SW/120V/2PK | 120   | White  | 4 ½           | 430            | 1000             | Box       | 12/2                 |
| <b>43</b> | A19       | Med. | <b>S2402</b>  | 60W            | 43A19/HAL/ES/CL/120V/2PK | 120   | Clear  | 4 ½           | 750            | 1000             | Box       | 12/2                 |
|           |           |      | <b>S2406</b>  | 60W            | 43A19/HAL/ES/SW/120V/2PK | 120   | White  | 4 ½           | 750            | 1000             | Box       | 12/2                 |
|           |           |      | <b>S2448</b>  | 60W            | 43A19/HAL/ES/SW/120V/4PK | 120   | White  | 4 ½           | 750            | 1000             | Box       | 12/4                 |
| <b>53</b> | A19       | Med. | <b>S2403</b>  | 75W            | 53A19/HAL/ES/CL/120V/2PK | 120   | Clear  | 4 ½           | 1050           | 1000             | Box       | 12/2                 |
|           |           |      | <b>S2407</b>  | 75W            | 53A19/HAL/ES/SW/120V/2PK | 120   | White  | 4 ½           | 1050           | 1000             | Box       | 12/2                 |
|           |           |      | <b>S2449</b>  | 75W            | 53A19/HAL/ES/SW/120V/4PK | 120   | White  | 4 ½           | 1050           | 1000             | Box       | 12/4                 |
| <b>72</b> | A19       | Med. | <b>S2404</b>  | 100W           | 72A19/HAL/ES/CL/120V/2PK | 120   | Clear  | 4 ½           | 1490           | 1000             | Box       | 12/2                 |
|           |           |      | <b>S2408</b>  | 100W           | 72A19/HAL/ES/SW/120V/2PK | 120   | White  | 4 ½           | 1490           | 1000             | Box       | 12/2                 |
|           |           |      | <b>S2450</b>  | 100W           | 72A19/HAL/ES/SW/120V/4PK | 120   | White  | 4 ½           | 1490           | 1000             | Box       | 12/4                 |