




GLOWEN™

Up & Down Wall Sconce

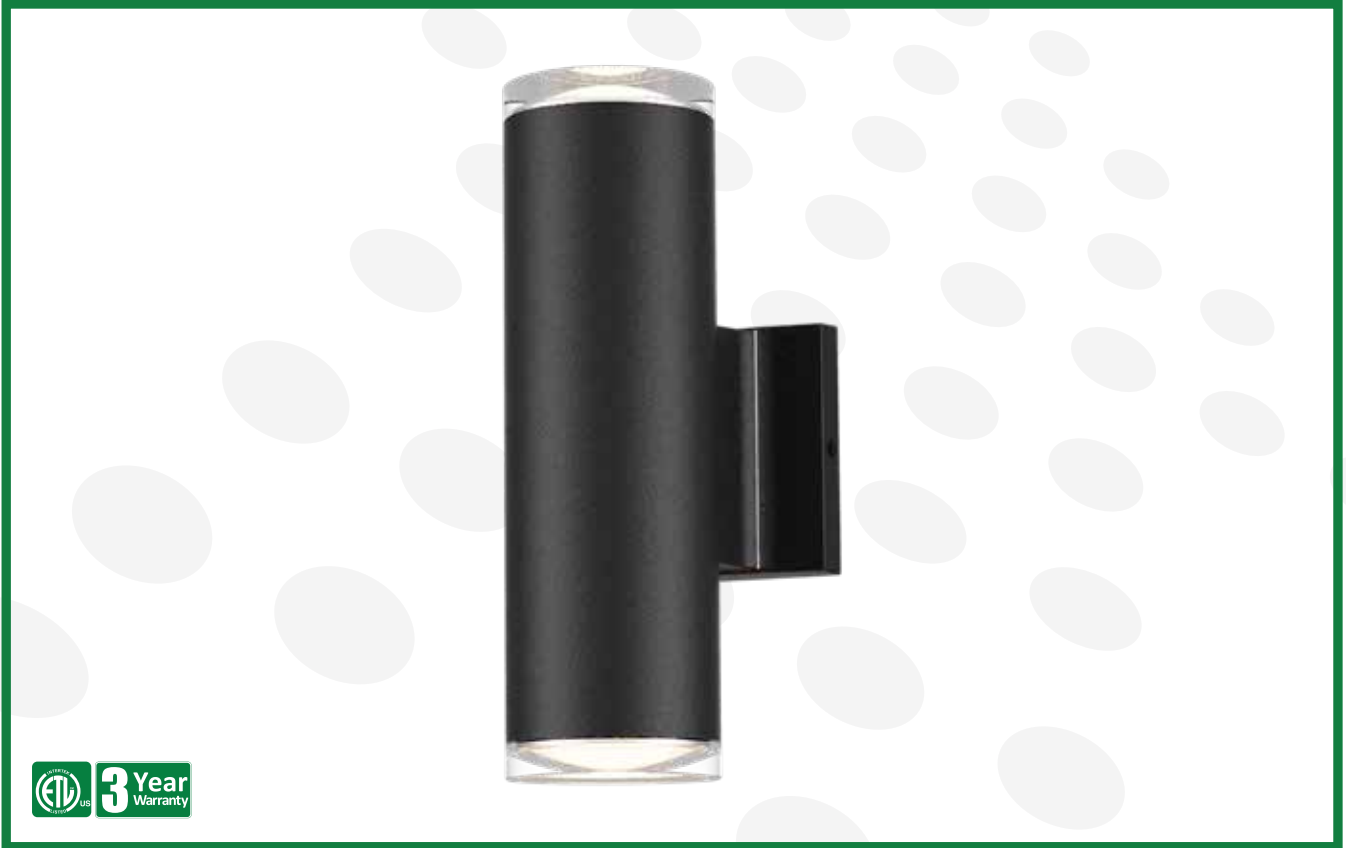

SKU	Model #
157027	JXL-BD90-YK18W-5CCT

Beyond LED Technology's GLOWEN Up & Down LED Wall Sconce combines modern design with functional lighting, offering 18W of energy-efficient illumination with customizable 5CCT color temperatures (2700K, 3000K, 3500K, 4000K, 5000K). The GLOWEN provides versatile lighting options, allowing you to adjust the color temperature to suit your needs, whether you're enhancing entryways, outdoor spaces, pathways, or commercial exteriors. Equipped with a built-in photocell & IP65 rating, this fixture is dustproof and water-resistant, making it suitable for use in wet locations. The acrylic diffuser ensures uniform light distribution, while the aluminum + steel housing with a sleek matte black finish provides durability and modern appeal. The GLOWEN Up & Down Wall Sconce offers smart automation, energy savings, and durability, making it an ideal choice for industrial and commercial lighting applications.

Product Features

- Up to 88 lm/W
- 18 Watt
- Adj. CCT 2700K/3K/3500K/4K/5K
- Triac Dimmable
- Built-in Photocell & Acrylic
- Black housing
- Input Voltage 100-277VAC
- ETL Listed
- 3-year warranty

GLOWEN™

Up & Down Wall Sconce



SKU	WATT	MAX LUMENS	ADJ. CCT	INPUT VOLTAGE	CRI	SIZE	LIGHT SPREAD	CONSTRUCTION	IP RATING	CERTIFICATIONS
157027	18W	1600	2700K/3K/ 3500K/4K/5K	100-277V	>70	12.87"	60°	Aluminum+ Arcylic	IP65	ETL

SKU: 157027

Specifications

Parameter	Description	Value
General Performance	Model #	JXL-BD90-YK18W-5CCT
	Watt	18W
	Max Lumens	1600
	Lumen Efficacy	Up to 88LM/W
	Color Temperature	2700K / 3000K / 3500K / 4000K / 5000K
	CRI (Ra)	>80
	Light Spread	65°
	Diffuser Type	Acrylic
Electrical	Input Voltage	100-277Vac
	Frequency	50/60Hz
	Dimming	Triac Dimmable
	Power Factor	≥0.9
	Driver Surge Protection	<1000V
	Flicker Percent	<30%
Physical	Operating Temperature	-20°C to 40°C
	Operating Humidity	10% ~ 40%
	Storage Temperature	-20°C to +60°C
	Storage Humidity	10%-90%RH
	LED Brand	Sanan
	LED Type	SMD
	LED QTY	40 Pcs
Construction	Aluminum+Steel	
Qualification	Housing Color	Matt Black
	IP Rating	IP65
	Warranty	3 Years


UP & DOWN WALL SCONCE




GLOWEN™

Up & Down Wall Sconce

Correlated Color Temperature (CCT)

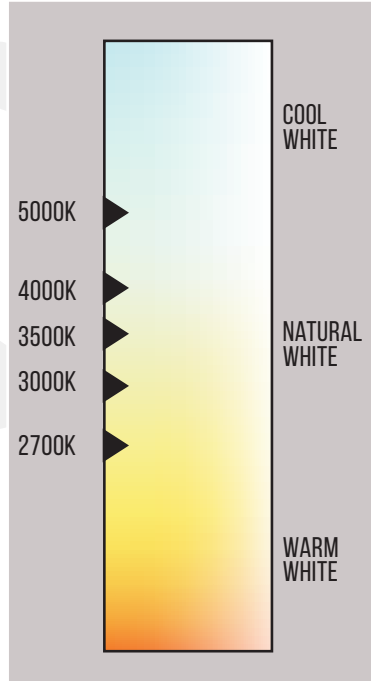

Dimensions

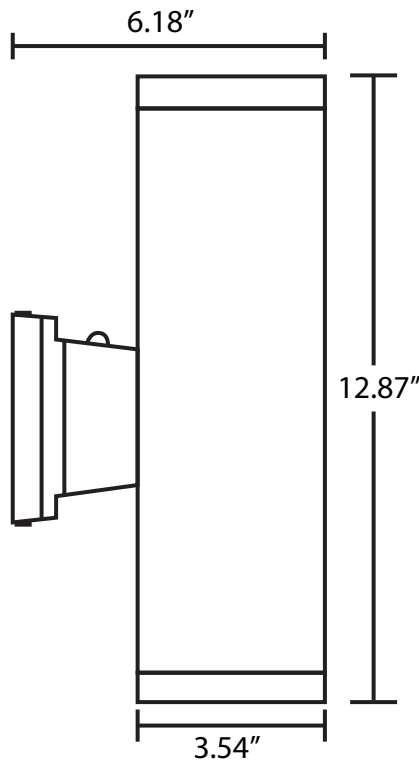


UP & DOWN WALL SCONCE

GLOWEN™

Up & Down Wall Sconce



Product Appearance

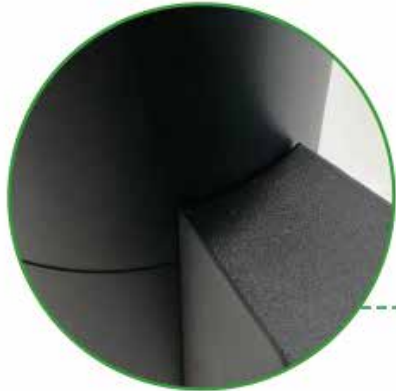

Aluminium Lamp Body
Durable for outdoor



High Brightness LEDs
Up to 2000 Lumens



5CCT Switch
2700k/3000k/3500k/
4000k/5000k tuable




Optical Lens
Bright and even light effects

UP & DOWN WALL SCONCE



Installation

IMPORTANT: Read all instructions in order to ensure safety and proper installation
DO NOT operate this product under any conditions other than those for which it is specified. Failure to observe these precautions can lead to electrical shock, product failure, or other problems.

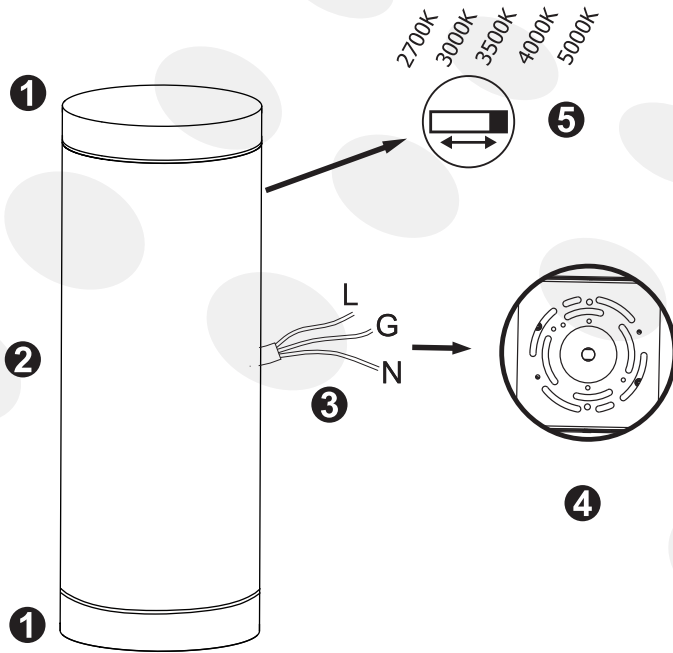

PARTS LIST

- ① LED Chip
- ② LED Fixture
- ③ Wire
- ④ Mounting Plate
- ⑤ CCT adjustable switch

Specification	Watt	Voltage	Length	Width	Height	Equivalent to
12-Inch Up & Down Wall Lamp	18W	100-277V AC	9.44"	3.54"	6.14"	180W

MAINTENANCE

READ ALL INSTRUCTIONS IN ORDER TO ENSURE SAFETY AND PROPER INSTALLATION.

1. DO NOT operate this product under ANY conditions other than those specified for it. Failure to observe these precautions can lead to electrical shock, product failure or other problems
2. TURN OFF THE POWER at the electrical panel before installation or maintenance
3. DO NOT modify this fixture. ANY modifications may render the product unsafe and void the warranty
4. This product is rated for outdoor use

GLOWEN™

Up & Down Wall Sconce



Installation

Limited Warranty

The warranty applies to the product from the original date of purchase for three (3) years against manufacturing defects. The owner must provide a copy of the original proof of purchase. The manufacturer's obligation under this warranty is limited to repairing or replacing the component. It is not related in any way to the cost of the connection, the

Package Content

- 12-Inch Up and Down Wall Lamp x 1
- Wire Connectors x 3
- Screws x 4
- Mounting plate x 1

WARNING

Turn power OFF from electrical panel before installation or maintenance.


1. Take off the mounting bracket from the light fixture
2. Attached the mounting bracket to the J-box
3. Adjust the switch to select the color temperature 2700K / 3000K / 3500K / 4000K / 5000K
4. Use push in wire connectors to connect the wires
5. Fix the light fixture to the mounting bracket by 2 screws on the side
6. Installation is done



GLOWEN™

Up & Down Wall Sconce

Installation

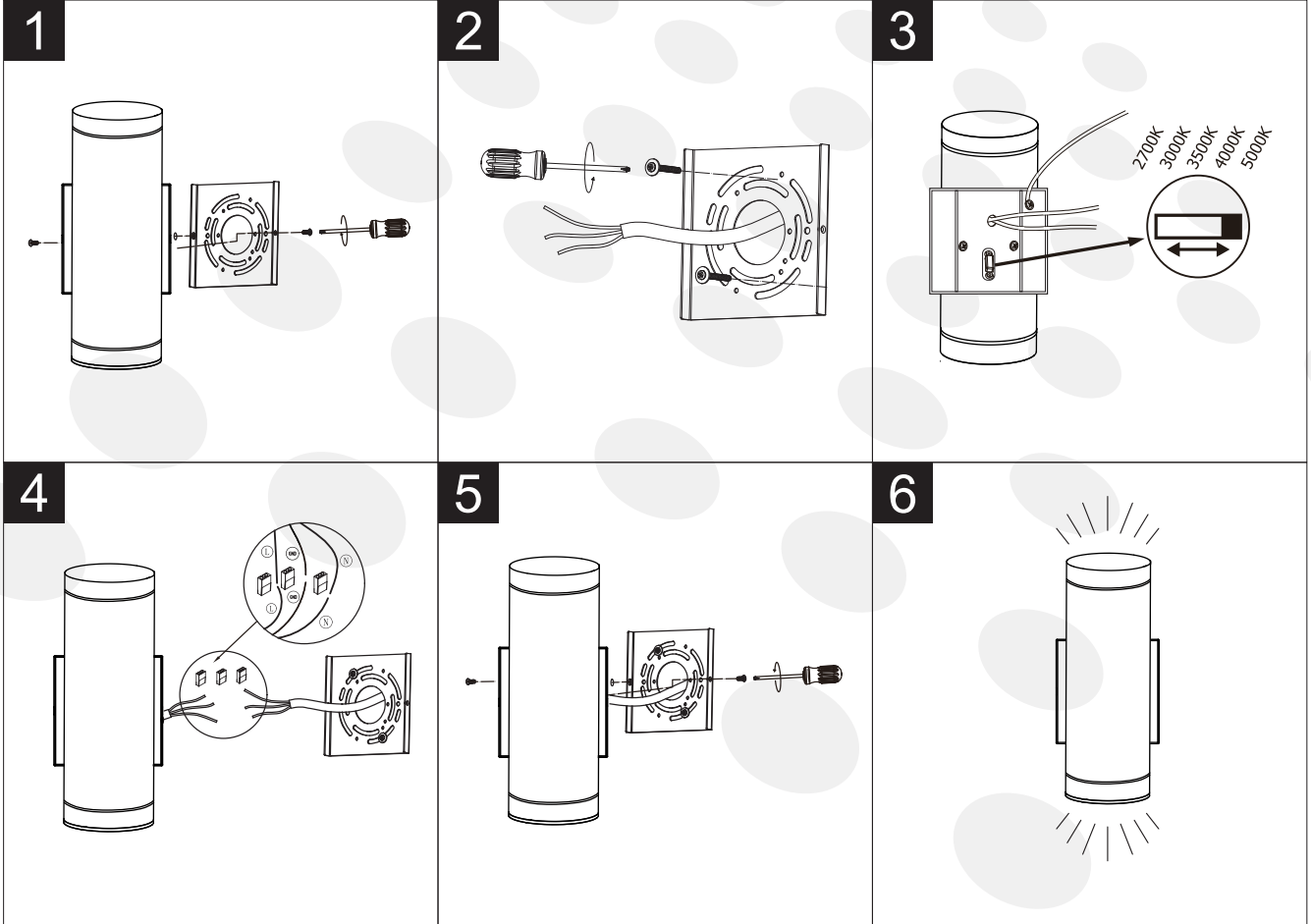

Packaging

SKU	Box Dimension	Qty	Net Weight	Gross Weight
157027	20.66" x 19.09" x 13.70"	12 Pcs/Box		

GLOWEN™

Up & Down Wall Sconce



Application Picture



UP & DOWN WALL SCONCE

Warranty

This product is covered under a 3-year warranty. For complete warranty details, [Click Here.](#)