



Post Office Box 97
Benton Harbor, Michigan
Ph: 616/926-6171
Fax: 616/925-8288

PART NUMBER:

LTD122

REV.

B



Product Specifications

Model Number	MAX. VAC.		RPM	HP	KW	Net Wt.	
	mbar	In. Hg				lbs.	kg
3040-V115A	500	15"	1325	2.0	1,5	70	31,82
3040-V115A	350	20"	1060	1.5	1,1	70	31,82
* 3040-V158	500	15"	1325	2.0	1,5	70	31,82

SOUND LEVEL 91 dB(A) MAX.
 NORMAL AMBIENT 1 ± C. - 40 ± C.
 RELATIVE HUMIDITY 8% - 100% NON CONDENSING
 ENVIRONMENT CLEAN DUST FREE

NOTES:
 1. TECHNICAL DATA SUBJECT TO CHANGE WITHOUT NOTICE.
 2. DIMENSIONS: METRIC (mm), U.S. IMPERIAL (inches).
 3. * DENOTES INACTIVE MODEL.

Product Performance

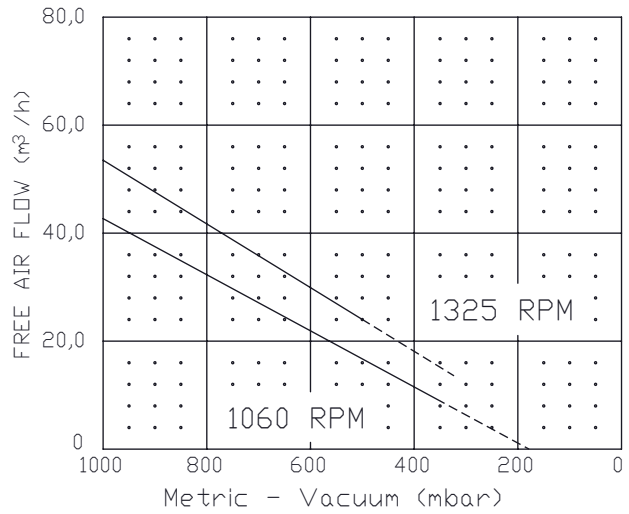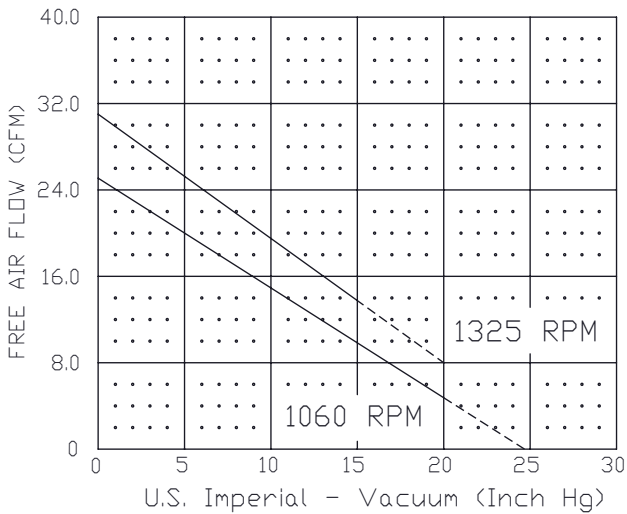

DASHED LINE INDICATES INTERMITTENT PERFORMANCE ONLY.

