


KS26, Split Bolt Connector, Run/Tap: #2 AWG-2/0 AWG Str

By Burndy
Catalog # [KS26](#)

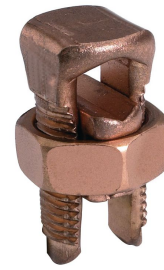

Copper Split Bolt, Cu: 2 AWG-2/0 AWG (Str) (Run & Tap)

Features

- UL467 Listed for Direct Burial applications in earth or concrete
- Compact, high-strength, copper alloy with free-running threads and easy to grip wrench flats
- Highly resistant to cracking and corrosion

Application

For Direct Burial Applications In Earth Or Concrete, Copper

Specifications

Certification - UL Recognized	No
Buy American Compliant	Yes
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	<ul style="list-style-type: none"> • Buy America Compliant (All status valid till December 2026) • Buy American Act Compliant (All status valid till December 2026) • BABA Compliant (All status valid till December 2026)
Industry Standard(s)	<ul style="list-style-type: none"> • UL 486A • UL486B
Certification - ETL	No
Standards - Industry Standards Met	<ul style="list-style-type: none"> • UL 486A • UL486B
Standards - RoHS Compliance Status	CM
Certification - UL Listed Direct Burial	Yes
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Rebar Size	3
Conductor - Rebar Size Range	3
Conductor - Copper Str Run Range	2 STR - 2/0 STR
Conductor - Copper Str Run	<ul style="list-style-type: none"> • 2 AWG • 1 AWG • 1/0 • 2/0 AWG

Conductor - Copper Solid Run Range	2 AWG-2/0 AWG
Conductor - Copper Solid Run	3/0 AWG
Conductor - Copper Solid Tap Range	14 AWG-2/0 AWG
Conductor - Copper Solid Tap	3/0 AWG
Conductor - CopperWeld Solid Tap Range	3/0
Conductor - CopperWeld Solid Tap	3/0
Conductor - CopperWeld Solid Run Range	3/0
Conductor - CopperWeld Solid Run	3/0
Conductor - CopperWeld Str Tap Range	7 #7
Conductor - CopperWeld Str Tap	7 #7
Conductor - CopperWeld Str Run Range	7 #7
Conductor - CopperWeld Str Run	7 #7
Conductor Type	<ul style="list-style-type: none"> • CU C Solid-Run • CU C Str-Run • CU Weld C Solid-Run • CU Weld C Str-Run • CU C Str-Tap • CU Weld C Solid-Tap • CU Weld C Str-Tap • CU C Solid-Tap
Conductor - Copper Str Tap Range	2 STR - 2/0 STR
Conductor - Copper Str Tap	<ul style="list-style-type: none"> • 14 AWG • 12 AWG • 10 AWG • 9 AWG • 8 AWG • 7 AWG • 6 AWG • 5 AWG • 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0 • 2/0 AWG

Configuration

Connector Type Split Bolt

Dimensions

Package Height 0.000 in
Package Weight 0.000 lb.
Package Length 0.000 in
Package Width 0.000 in
Dimension - L Length Overall
mm 49 mm
Width 0.82 in
Dimension - Width fraction 41/50 in
Dimension - B Length fraction 9/10 in
Dimension - Width mm 21 mm
Dimension - Width inch 0.82 in
Dimension - B Length inch .90 in
Dimension - Cross Flats inch 1.05 in
Dimension - Length Overall
inch 1.94

Force Related



A Hubbell brand

Installation Torque
Recommended in-lb

385 in

General

Trade Name SERVIT®
Plated N
Sub Brand SERVIT
UPC 781810013281
Type KS, Compact
Material Copper
Plating Type Unplated
UPC 12 Digit 781810013281
UPC 14 Digit GTIN 00781810013281

Logistics

Minimum Pack Quantity 1
Pallet Quantity 8700
Carton Quantity 25

Product Assets

[Catalog \[English\]](#)