

PRODUCT SPECIFICATIONS

MODEL NO.	MOTOR	RPM		RUNNING AMPS DIRECT CURRENT	HP	Watts	NET WT.	
		60HZ	N/A				lbs.	kg
87R637-101-BL480X	24v BLDC	1725	N/A	22	1/2	511	17.5	7.94

SOUND LEVEL: LESS THAN 65dB(A)

NORMAL AMBIENT: +5 °C TO +40 °C


RELATIVE HUMIDITY: 20% TO 80%

ENVIRONMENT: CLEAN, DUST FREE


**PRODUCT PERFORMANCE:
 (PERFORMANCE CURVES BASED ON 24VDC)**

NOTES:

1. TECHNICAL DATA SUBJECT TO CHANGE WITHOUT NOTICE.
2. THIS PUMP MUST BE INSTALLED IN AN ENCLOSURE.
3. ALL DIMENSIONS ARE FOR REFERENCE ONLY.
4. KIT P/N: K964.
5. REDUCED BEARING LIFE FOR 50 PSI OR GREATER CONTINUOUS OPERATION

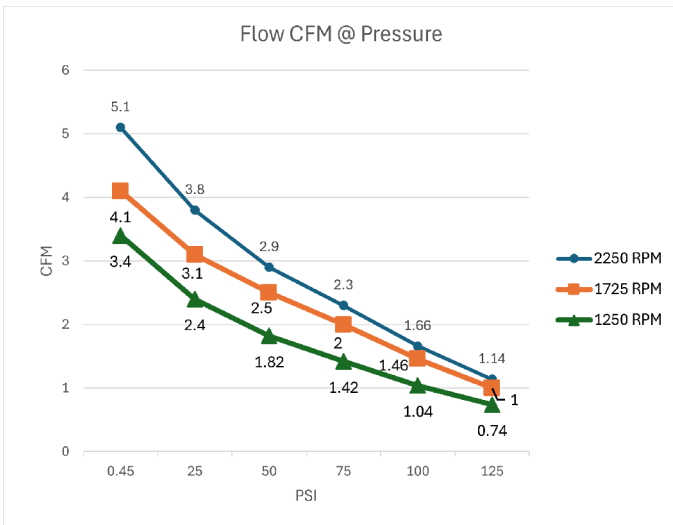

PRODUCT DIMENSIONS:

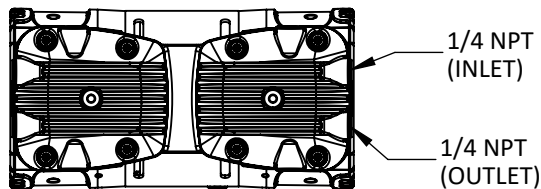

Connection Diagram of motor and driver

