

Quartzliter® Series – Industrial Grade



- Die-cast aluminum housing and door, deep fin system maintains rated lamp life
- High temperature lens, silicone gasket, tool-free stainless latch entry
- Large 1/2" swivel knuckle provides versatile aiming
- QL produces a wide uniform beam with true color rendering
- QL505 suitable for 300-500w lamps, QL1505 suitable for 900-1500w lamps
- Models available with or without lamp, consult listings
- Gray finish is available
- Listed to UL1598 for use in wet locations

ORDERING INFORMATION

Catalog Number	Max. Watts	Housing Finish	NEMA Beam Spread H° x V°	Weight lbs. (kg)	EPA ft² (m²)
Lamp Not Included					
QL-1505¹	1000/1500	Gray	6(115°) x 5(78°)	6 (2.7)	.9 (0.1)
QL-505	300/500	Gray	5(88°) x 5(82°)	4 (1.8)	.5 (0.1)

1 Do not aim at ±10° from horizontal or higher

2 Fixture voltage is controlled by lamp voltage rating

Note: Do not operate on voltage higher than lamp voltage rating, shortens lamp life and increases heat stress within the fixture



 
REPLACEMENT PARTS

Catalog Number	Description
26401849803	Glass lens QL505
26401839805	Glass lens QL1505
20750110214	Knuckle, gray
80021660108	Replacement socket QL505
705327	Replacement socket QL1505

ACCESSORIES - Order Separately

Catalog Number	Description	Weight lbs. (kg)
QL-505 Series		
QL-5G	Wire guard (2 inch square grid)	1 (0.5)
QL-VS	Top/side visor (max use two - at 180°)	.5 (0.2)
26100119905	500w 120V Quartz lamp	-
QL-1505 Series		
QL-15G	Wire guard (2 inch square grid)	1.3 (0.6)
QL-15V	Top visor / bottom visor	1.3 (0.6)
QL-VS	Side visor (will not work with QL-15V on same fixture)	.5 (0.2)
26100149902	1500w 240V Quartz lamp	-
QL-500 / QL-1500		
S-302	Pole top slipfitter for 1/2" swivel knuckle; slipfits 2 3/8" OD pipe; gray finish	.8 (0.4)
S-302-M51	Pole-top slipfitter for 1/2" knuckle, slipfits 2 3/8" OD pipe; bronze finish	.8 (0.4)
TRN-XX¹	Trunnion adaptor for 1/2" threaded knuckle mount	.5 (0.2)

1 Specify color, eg. DB - Dark Bronze

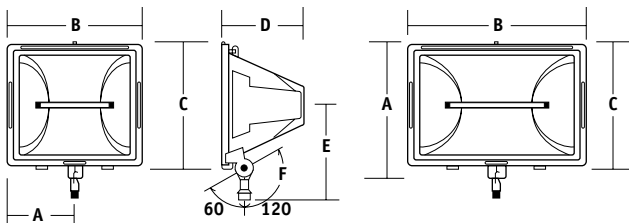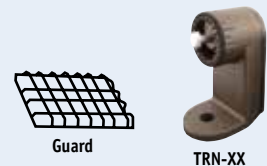

	A	B	C	D	E	F
QL-505	4 5/16"	8 5/8"	8 1/2"	5 1/4"	7"	2 1/2"
	110 mm	219 mm	216 mm	133 mm	178 mm	64 mm
QL-1505	4 1/2"	14"	8 1/2"	5 1/4"	7"	2 1/2"
	292 mm	356 mm	216 mm	133 mm	178 mm	64 mm



HUBBELL
Outdoor Lighting