

NEPHELE

473-11-VPB

Echoing the artistry of bespoke installations and the graceful allure of fine jewelry, Nephele floats elegantly in space, resembling a string of luminous pearls suspended in perfect harmony. Each softly glowing cloud glass orb is held in place by intricately detailed Vintage Polished Brass links, creating a striking interplay of light and form.

Available in 8, 12, or 16-light LED-lit chandeliers, as well as a 1-light wall sconce, Nephele captivates the senses with its fluid silhouette and exquisite craftsmanship. This artful statement piece offers a refined elegance that elevates interiors with its sculptural presence.

FINISHES

VINTAGE POLISHED BRASS

Coastal Suitable Finish (EPM): No

DIMENSIONS

Height: 59.5"
Width/Diameter: 10"
Length: 177.5"
Minimum Height: 59.5"
Maximum Height: 84"
Canopy/Backplate: 7.75"
Hanging Type: 72" Chain
Product Weight: 62.3lb
Canopy/Backplate Shape: Round
Sloped Ceiling Compatible: No
Living Finish: No
Uplight Only: No

Shade

Shade 1: Glass
Shade 1 Finish: Cloud
Shade 1 Top Width: 10"
Shade 1 Height: 6.25"

ELECTRICAL




Bulb 1

Bulb Included: N/A
Socket: Integrated LED
Max Wattage: 95
Bulb Quantity: 16
Bulb Included: Yes
Wire Length: 120"
Cord Type: SPT-1 SILVER W/ TINNED GROUND WIRE
Dimmer Type: ELV, TRIAC, 0-10 VOLT
Gem Box Required (2"x3"): No
Dark Sky: No
CRI: 90
Color Temp.: 2700k
Lumens: 2875
Title 24: No
Field Serviceable: No

SHIPPING

Carton 1: 36" x 36" x 22"
Carton 1 Weight: 76lb
Shipping Method: Truck Only
Country of Origin: VN

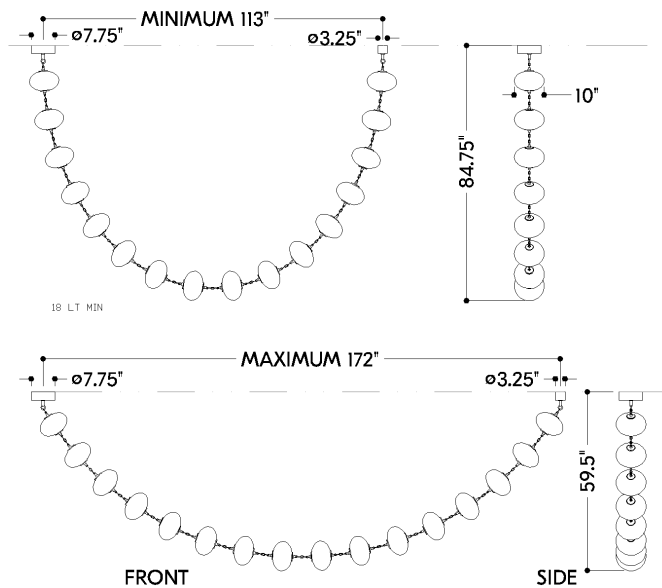

HUDSON VALLEY
LIGHTING GROUP

| hvlgroup.com | 1.800.814.3993

REVISED 3.11.2022