

## Square Boxes and Accessories


### 4" Square Boxes (continued)

CAT. NO.	DEPTH (IN.)	CU. IN. CAPACITY	CLAMPS	BRKTS.	KNOCKOUTS (IN.)				STD. CONDUIT CTN.
					EA. SIDE	EA. END	BOTTOM	STD.	
<b>With Armored Cable/Metal-Clad Clamps</b>									
52151 X	1¼	21.0	C-3	—	2-½, 1-½, ¾E	2	1-½	50	
52151XP	1¼	21.0	C-3	—	2-½, 1-½, ¾E	2	1-½	50	
52151 BX*	1¼	21.0	C-3	B	2-½, 1-½, ¾E	2	1-½	25	
52151 VX*	1¼	21.0	C-3	SV	2-½, 1-½, ¾E	2	1-½	25	
52151 CVX*	1¼	21.0	C-3	CV	2-½, 1-½, ¾E	2	1-½	25	
52151 MS X*	1¼	21.0	C-3	MS	2-½, 1-½, ¾E	2	1-½	25	
<b>For Armored Cable and Metal-Clad Cable Clamps</b>									
52171 X*	2½	30.3	C-3	—	2-½, 1-½, ¾E	2	1-½	25	
52171 MSX*	2½	30.3	C-3	MS	2-½, 1-½, ¾E	2	1-½	25	
52171MSXP (With 10½" ground wire)	2½	30.3	C-3	MS	2-½, 1-½, ¾E	2	1-½	25	
52171-CVX*	2½	30.3	C-3	CV-2	½-¾	—	—	25	


\* All bracketed boxes come complete with eccentric knockouts. Per UL514A, suitable for use without a bonding jumper in circuits above or below 250 volts. Pigtail wire is #12 AWG insulated, 10½" long. All 52171 series boxes have a raised ground bump.




52151 X

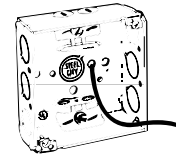


52151XP

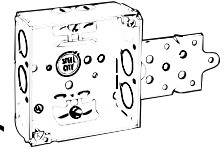


52151 BX\*  
B bracket  
mounted flush

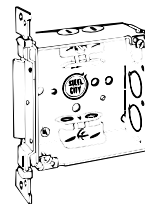


52151 VX\*  
SV bracket  
mounted flush

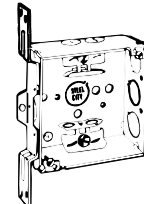


52151 CVX\*  
CV bracket  
mounted flush

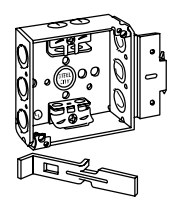


52151 MS X\*  
MS bracket for 1½",  
2½", 3¾", 4" metal studs

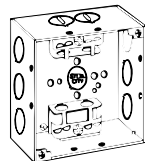

52171 X

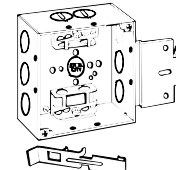

52171 MSX\*  
MS bracket for 1½",  
2½", 3¾", 4" metal studs

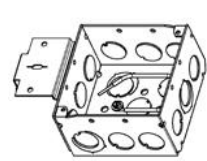

52171MSXP\*

CAT. NO.	DESCRIPTION	CLAMPS	EACH SIDE CONDUIT	EACH END CONDUIT	BOTTOM CONDUIT	CU. IN. CAPACITY	STD. PACK.
52171-EW-SSX	2½"-deep with conduit KOs	—	1½", 1½" & ¾"E	2½", 1½" & ¾"E	2½", 2½" & ¾"E	30	20
52151-EF-SSX	1½"-deep with conduit KOs	—	1½", 1½" & ¾"E	2½", 1½" & ¾"E	2½", 2½" & ¾"E	21	20
52171-X-SSX	2½"-deep with armored cable clamps	C3	1½", 1½" & ¾"E	2 Cable	1½"	30	20
52151-X-SSX	1½"-deep with armored cable clamps	C3	1½", 1½" & ¾"E	2 Cable	1½"	21	20
CXLESSX	3½"-deep with armored cable clamps	C3	2½"	1½" & 2 Cable	1½"	15	20

### Vapor Tite Boxes

- All K.O.'s pressed flush but still easy to remove
- No holes anywhere
- Top edge of boxes are flush at ears so gasket seals out all air

CAT. NO.	DESCRIPTION	DEPTH	STD. PKG.
52151-SVT	4" Sq. Box, ½" and ¾" K.O. Side and Bottom	1½"	50
52C1-VT	4" Sq. Blank Cover with Gasket	Flat	50
52171-SVT	4" Sq. Box, ½" and ¾" K.O. Side and Bottom	2½"	25
72C1-VT	4½" Sq. Blank Cover with Gasket	Flat	50
72171-SVT	4½" Sq. Box, ½" and ¾" K.O. Side and Bottom	2½"	25
54151-VT	4" Sq. Box, ½" K.O. Side and Bottom	1½"	50
54C1-VT	4" Oct. and Round Box Blank Cover	Flat	50