

Panelboards

Warehouse Stock – Type P1 Panelboards

Selection

Main Breaker Mounting Kits with Breakers for P1 Panels


(250A and lower can be used as subfeed kits also)

Nex Gen P1 Catalogue No.	Description	Ratings	
		240V	600V
MBKED33100A	Kit w/3-pole ED6 100A breaker	65kA	18kA
MBKED33125A	Kit w/3-pole ED6 125A breaker	65kA	18kA
MBKQR12225A	Kit w/2-pole QR2 225A breaker	10kA	—
MBKQR33150A	Kit w/3-pole QR2 150A breaker	10kA	—
MBKQR33200A	Kit w/3-pole QR2 200A breaker	10kA	—
MBKQR33225A	Kit w/3-pole QR2 225A breaker	10kA	—
MBKFD33200A	Kit w/3-pole FXD6 200A breaker	65kA	22kA
MBKFD33225A	Kit w/3-pole FXD6 225A breaker	65kA	22kA
MBKFD33250A	Kit w/3-pole FXD6 250A breaker	65kA	22kA
MBKHF33250A	Kit with 3-Pole HFD6 250A Breaker	100kA	25kA
MBKJD33400A ^①	Kit w/3-pole JXD6 400A breaker	65kA	25kA

NOTE: *Next Gen P1* Kits above only work for interior numbers ending in "T" or "N". Use *Original P1* main connector kits and loose breaker for all others.

Miscellaneous Parts and Accessories

Catalogue no.	Description
BK1A	Bonding Kit for 250A max. Next Gen P1 panels
EGK	Al Ground Bus 44 Connections
ECGK	Cu Ground Bus 44 Connections
IGK	Insulated Al Ground Bus
ICGK	Insulated Cu Ground Bus
DFFP1A	1" Branch circuit blank filler plate - BL/BQD/xGB/3VA41 provisions
DFFP01B	P1 Main & Sub-feed Blank Filler (Small Main & Sub-feed opening) *Replaces DFFP01ACAN
DFFPVA41A	RP1 Main/Sub-feed Breaker Filler 125A Max. - 3VA4/BL/BQD/ED/xGB *Replaces DFFPED01CAN (Ref. 12-A-1802-01)
MBKQRFK	P1/RP1 Main Breaker Filler for 1PH/3PH QR - Horizontal Mount only
DFFPFD01CAN	P1 Main Breaker, FD Filler, 250A Frame
DFFPJD01CAN	P1 Main Breaker, JD Filler, 400A Frame (Small opening - prior to 3VA)
DFFP01C	RP1 400A Main Blank Filler Plate - 1 Piece for large opening
DFFPJD02	RP1 400A w/JD Main Breaker - 1 Piece for large opening
MCHK	1 Metallic directory card holder
EWK1	End Wall Kit with KO's (20"W x 5.75"D)
IMK1	Interior Adjusting Kit
LPDC01	Panelboard Directory Card 5.5" x 5" (Pack of 10; Ref. 12-1110-01)
LPDC01CAN	Panelboard Directory Card 9" x 4" (Pack of 8; Ref. 9270-1/3/8/9)
LPDC02	Directory Card Holder for 5.5" x 5"(Pack of 10; Ref. 11-1824-01)
9271-1	Directory Card Holder for 9" x 4"
NBK01A	STICK-ON NUMBERS 1 THRU 60 (includes BT - 1/2" size)
NBK02A	STICK-ON NUMBERS 61 THRU 120 (includes BT - 1/2" size)
NBK03A	STICK-ON NUMBERS 121 THRU 240 (includes BT - 1/2" size)
P1SCRWS	Breaker Mounting Screws for P1 (Pack of 42)
P1CONBPHCU	Connector kit – 6 pcs. B-phase Copper
P1CONBPHAL	Connector kit – 6 pcs. B-phase Aluminum
P1CONACPHCU	Connector kit – 6 pcs. A or C-phase Copper
P1CONACPHAL	Connector kit – 6 pcs. A or C-phase Aluminum
JCK24	J-type Speed Nut Lighting Panel Fronts (Pack of 24)
LPKEY01ACAN	Key for FAS-Latch lock (Pack of 4; Ref. B363A)
FPLK2	2 Spare Fas-latch trim locks with 2 keys
SDKN	Dripshield kit for Standard Enclosure (20"W x 5.75"D)
TPS9IKITP1	P1 mounting bracket for SPD TPS3 09

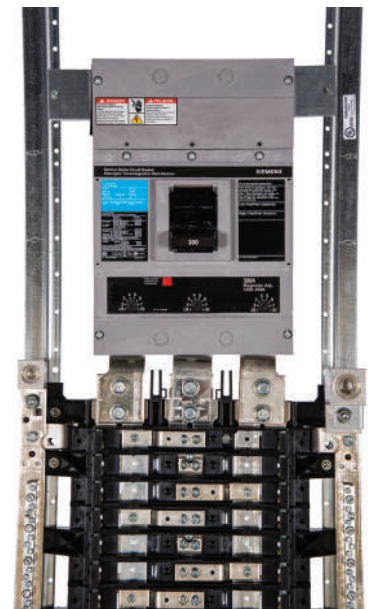

300A Main installed.
These Next Gen P1 kits can now be used as top or bottom feed.

① Kits are for Main only. New "Next Gen P1" kits can be used for either top feed or bottom feed.

Panelboards

Type P3 Panelboard Kits and Accessories

Selection

Standard Enclosures

Box Height (in.)	Catalog Number				
	Type 1 Standard Trim			Type 3R	Type 3R/12
	Box	Surface	Flush		
56	24WD56	P3S56	P3F56	24NRD56	24WPD56
62	24WD62	P3S62	P3F62	24NRD62	24WPD62
68	24WD68	P3S68	P3F68	24NRD68	24WPD68
74	24WD74	P3S74	P3F74	24NRD74	24WPD74
80	24WD80	P3S80	P3F80	24NRD80	24WPD80

Options For Type 1 Trims

Items must be ordered as manual line item on factory
 Hinged trim – Add "H" suffix
 Door-in-door – Add "D" suffix
 Metal card holder - Add "M" suffix
 Provision for padlock - Add "-PL" suffix
 Service entrance application - Add "SE" suffix

Breaker Kits and Accessories

Kit Number	Description	Contents
BBKGB32 (P2/P3)	NGB2, HGB2, LGB2 3" branch breaker kit	Kit contains top barrier, (3) A/C connectors, (1) B connector, hardware
BBKB32 (P2/P3)	BL/BQD 6-pole 3" branch breaker kit	Kit contains top barrier, (3) A/C connectors, (1) B connector, hardware
BBKNB32 (P2/P3)	NGB, 6-pole 3" branch breaker kit	Kit contains top barrier, (3) A/C connectors, (1) B connector, hardware
BBKEB32 (P3)	HEB 6-pole 3" branch breaker kit	Kit contains top barrier, (3) A/C connectors, (1) B connector, hardware
BBKED32 (P2/P3)	ED 6-pole 3" branch breaker kit	Kit contains breaker support, inter-phase barriers, (3) A/C connectors, (1) B connector, hardware
BBKQR2 ^①	P3 twin BKR mounting kit for 1-phase/3-phase.	Kit contains all connectors and cover plates necessary to mount both 2 and 3-pole breakers
DFK1	BL, BQD, ED deadfront kit for 1" pole breakers	Center strips 3", 6", 9", 15", 21" plus mounting hardware
DFFP3	Deadfront filler 3"	3" empty space filler and hardware
DFFP6	Deadfront filler 6"	6" empty space filler and hardware
P3BK1	P3 bonding kit	Bonding strap and hardware
EBF1	HEB/NEB Filler Plate	Filler Plate
BBKQRP2FK	P3 Filler for QR. Dual mount horizontal. 1-phase/3-phase.	Kit contains all cover plates necessary to change from QJ to QR both 2 and 3-pole breakers. For 1-phase panel, both breakers must change from QJ to QR, cannot have one of each installed.

^①Although QR is rated 250A, it is limited to 225A in panelboard.

Type P3 Panelboards

Miscellaneous Parts and Accessories

Catalogue Number	Description
EGK	Al Ground Bus 44 Connections
BK1	Bonding kit for 250A max. and all P1 panels
IMK1	Interior Adjusting Kit
9271-1	Directory Card Holder
NBK3	1 Numbering Button Kit "Snap-in" type 1 @ 42
NBK4	1 Numbering Button Kit "Snap-in" type 43 @ 84
NBK5	1 Numbering Button Kit "Snap-in" type 85 @ 126
NBK6	Number Strips 127-168.
NBK7	Number Strips 169-210.
NBK8	Number Strips 211-252.
ECGK	Cu Ground Bus 44 Connections
IGK	Insulated Al Ground Bus
ICGK	Insulated Cu Ground Bus
EWK2	End Wall Kit with Knockouts (24" W x 7.75" D)
DFFP1A	1" Filler Plate (Suitable for replacing QF3 in P1 thru S5 Panelboards and Switchboards)
P3BK1	P3 Bonding Kit
JCK24	24 trim screws and 24 trim clips
DFK1	BL, BQD, ED deadfront kit for 1" (include 7 different length centre strips)
12-1110-01	1 Directory card for 1-42 circuits
MCHK	1 Metallic directory card holder
FPLK2	2 Spare Fas-latch trim locks with 2 keys
DSK724	1 Dripshield 24"W x 7.75"D

Panelboards

Miscellaneous accessories

Selection

Spare Parts Kits (cont.)

Kit Number	Current Product						Old Product is no longer Manufactured, some kits are available			QTY/ Kit	Product Description Note: Some kits apply to only specific enclosures used or configurations of the product listed
	P1 Revised	P2	P3	C1	C2	P1 Original	S1, S2, SE				
Locks, Hadnles, & Keys											
LPKEY01ACAN	X	X	X	X	X	X			4	Key for FAS-Latch lock Siemens FAS-Latch and other various fronts use this standard key #B363A	
LPKEY01BCAN	X	X	X	X	X	X			25	Key for FAS-Latch lock Siemens FAS-Latch and other various fronts use this standard key #B363A	
FPLK2	X	X	X	X	X	X			1	FAS-Latch lock with 2 keys, 14-16 gauge door - for Lighting Panel Type 1 front Replacement lock for use when door thickness is 14-16 gauge painted steel	
LPLOCK02ACAN	X	X	X	X	X	X			5	Siemens FAS-Latch Replacement Lock Kit with two B363A Keys, for 12 Gauge Steel, Lighting Panel Type 1 Fronts, various styles.	
LPLOCK03ACAN	X	X	X	X	X	X			5	Siemens FAS-Latch Replacement Lock Kit with two B363A Keys, for 10 Gauge Steel, Lighting Panel Type 1 Fronts, various styles.	
K71-1804-01	X	X	X	X	X	X			1	T-Handle lock - for Lighting Panels Type 3R & 12 Replacement lock for use with any P1, P2, & P3 panels with Type 3R/12 enclosures.	
General Hardware											
JCK24	X	X	X	X	X	X			1	J-Type speed nut - lighting panel fronts - 24 pieces per pack Replacement J-nuts for use with lighting panel fronts and deadfronts.	
BNK2		X							1	P2 neutral 3-step lug - Tin-plated aluminum - 1 piece per pack with mounting hardware 14 connections for #6-1/0 wire and 12 connections for #14-#6 wire	
BNK350NCAN		X	X						10	Narrow 350 KCMIL lug - Tin-plated aluminum - 1 piece per pack with mounting hardware One #6-350KCMIL connection.	
LPP2NB01CAN		X							10	P2 Neutral 2-Step lug - Tin-plated aluminum - 1 piece per pack with mounting hardware Three connections for #6-1/0 wire and 18 connections for #14-#6 wire.	
ECGK	X	X	X			X			1	ECGK Copper Ground Bus Kit, Connection count: (6) of #14-1/0 and (15) of #14-6 Connections (21 Holes total). Some connections allow multiple wires.	
EGK	X	X	X			X			1	EGK Al/Cu Ground Bus Kit, Connection count: (6) of #14-1/0 and (15) of #14-6 Connections (21 Holes total). Some connections allow multiple wires.	
ICGK	X	X	X			X			1	ICGK Insulated Copper Ground Bus Kit, Connection count: (6) of #14-1/0 and (15) of #14-6 Connections (21 Holes total). Some connections allow multiple wires.	
IGK	X	X	X			X			1	IGK Insulated Al/Cu Ground Bus Kit, Connection count: (6) of #14-1/0 and (15) of #14-6 Connections (21 Holes total). Some connections allow multiple wires.	
IMK1	X	X	X			X			1	Interior Mounting Kit with Adjustment Provisions for P1/P2/P3	
LPDC01CAN	X	X	X	X	X	X	X		10	Panelboard Directory Card 9 x 4 - 8 pieces per pack Kit includes 8 cards. New cards have 1-42, 43-84, 85-126, and 127-168 circuits.	
LPDC01	X	X	X	X	X	X	X		10	Panelboard Directory Card. 5.5X5, for 1-90 circuits.	
LPDC02	X	X	X	X	X	X	X		10	Panelboard Directory Vinyl Pouch, 6.3x6.1.	
9271-1	X	X	X	X	X	X	X		10	Directory Card Holder for 9 x 4	
P1CONACPHCU	X								6	RP1 A/C-Phase Replacement Copper Connectors, Kit of 6 pcs plus mounting hardware. Also can be used to replaced AL A/C-Phase Connectors.	
P1CONBPHAL	X								6	RP1 B-Phase Replacement Aluminum Connectors, Kit of 6 pcs plus mounting hardware	
P1CONBPHCU	X								6	RP1 B-Phase Replacement Copper Connectors, Kit of 6 pcs plus mounting hardware	
P1SCRWS	X					X			42	P1 Branch breaker mounting screws - pack of 42 screws, part #11-A-1505-03, 10-32 x 0.312 Hex Washer Head Screw - Do Not Substitute	
MCHK	X	X	X	X	X	X	X		1	Metal Card Holder Kit - Field Installable	
SDKN	X	X				X			1	Dripshield kit for Standard Enclosure (20W x 5.75D)	
DSK724			X						1	Dripshield 24"W x 7.75"D	
Bonding Kits											
BK1A	X								1	Revised P1 Bonding Kit including Service Disconnect Label	
P2BK1		X							1	P2 250A Max Horiz. MB Bonding Strap Kit	
P2BK2		X							1	P2 125A max. Main Lug Bonding Strap Assembly	
P2BK3		X							1	P2 250-600A MLO and all Vert MB Bonding Kit	
P3BK1			X						1	P3 bonding kit 800A max MLO+MB	