

EAN:	4013288101457	Size:	105x55x14 mm
Part number:	05104631001	Weight:	14 g
Article number:	846 HSS	Country of origin:	CN
		Customs tariff number:	82075060

- Hex shaft for very good power transfer
- Finely-tuned material elasticity for great durability
- Very good centring properties
- Perfect chip removal
- Precise return movement

High quality 3-flute countersink bit for deburring, chamfering and countersinking. A finely-tuned material elasticity provides for great durability. Perfect chip removal and a low tilt risk ensure pleasant working. Cutting section as per DIN 335-C, 90° with 3 cutters. ¼" hexagon, suitable for holders with take-up as per DIN ISO 1173-D 6.3.

Web link


<https://www.wera.de/en/05104631001>

Wera - 846 HSS

05104631001 - 4013288101457



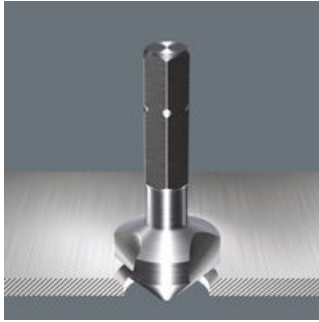

Wera Werkzeuge GmbH
Korzter Straße 21-25
D-42349 Wuppertal
Tel: +49 (0)2 02 / 40 45-0
E-Mail: info@wera.de

3-flute countersink bits



3-flute countersink bits,
90°Application:
Deburring, chamfering and
countersinking1/4" drive
suitable for holders as per DIN
3126-D 6.3 (ISO
1173)Hexagon shaft for
very high torque
transferHSS = high
speed steelFinely
adjusted material elasticity for long
service life3
tipsExcellent centring
propertiesStraightforward
cuttingPerfect chip
removalLow jamming
riskPrecise return
controlHigh corrosion
protection

Further versions in this product family:

				
	mm	mm	mm	
05104630001	6.30	20.00	31.0	M 3
05104631001	8.30	20.00	31.0	M 4
05104632001	10.40	20.00	34.0	M 5
05104633001	12.40	20.00	35.0	M 6
05104634001	16.50	20.00	40.0	M 8
05104635001	20.50	20.00	41.0	M 10

Web link

<https://www.wera.de/en/05104631001>

Wera - 846 HSS

05104631001 - 4013288101457

Wera Werkzeuge GmbH
Korzter Straße 21-25

D-42349 Wuppertal

Tel: +49 (0)2 02 / 40 45-0

E-Mail: info@wera.de