



Features

- Up to 180 lumens per foot and 82+ CRI for 2700K (WW) and 5000K (WH) reels
- 120V reels consume only 2.3 watts per foot
- Dimmable with most CL and ELV dimmers
- Cuttable* every 18"
- Economical for larger installations - no need for a driver (150ft max run)
- cETLus Listed†
- Suitable for indoor and outdoor use
- 30,000 hours rated life

Available Colors



2700K 5000K

Dimming Options

- CL (10-100%)
- ELV (10-100%)

Listing / Ratings†



Hybrid 2 Reels

Superb light output for indoor and outdoor use. Parallel wiring in 18" increments ensures that if one LED goes out, the rest of the LEDs continue to operate. Warm White and Bright White emit 145 and 180 lumens per foot of light, respectively, providing an effective general lighting option that is both vibrant and energy efficient for hospitality, home theater, and other various entertainment applications.


Technical Information

Series	H2
Input Voltage	120V AC
CCT	2700K / 5000K
CRI	82+ (2700K / 5000K)
Wattage	2.3W per ft
Lumens	Up to 180Lm per ft (see individual product)
Max Run	150 feet
Cuttable	Every 18"
IP Rating	IP65**
Dimmable	10-100%*
Rating	cETLus Listed† for indoor/outdoor use
Rated Life	30,000 hrs

*Minimum loads may apply. Per the NEC, switched wall outlets cannot be used with wall dimmers.

**IP65 rated only when used with pre-attached molded power cord and end cap is either pre-attached or properly sealed with dielectric grease, silicone and shrink tube

†cETLus Listing is void if product is cut

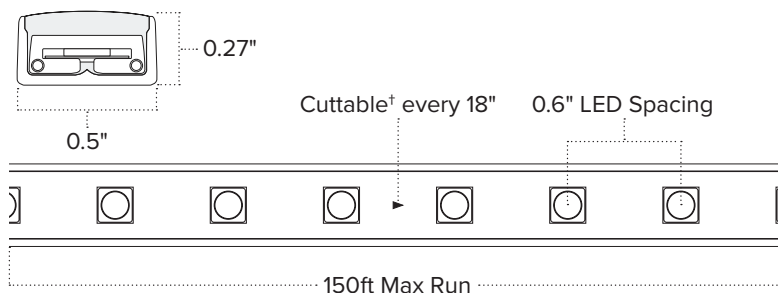

Hybrid 2 Reels



Warm White - 2700K
82+ CRI / Up to 145Lm/ft



Bright White - 5000K
82+ CRI / Up to 180Lm/ft

120V Bulk Reels

120-H2-WW (150ft)

120-H2-WH (150ft)

120V Hybrid 2 Bulk Reels Include: (1) 150ft reel of Hybrid 2 / (1) Attached H2-CONKIT-8A / (4) H2-CONKIT-8A* / (1) Removable end cap
(50) Clear plastic mounting clips with screws

Hybrid 2 Reel Accessories



120V Power Connector Kit*
(1) 5ft plug-in power cord with fused plug and 8A inverter,
(1) power pin, (1) end cap, and (2) 4" pieces of shrink tube
H2-CONKIT-8A



120V Junction Box + Rectifier
120V 8A Junction Box enclosure with 7/8" bored input port and (2) output ports;
Includes (2) H2 connection leads (1 attached, 1 loose) + compression clamps
120-JBOX-H2



Linking Cables
(1) linking cable,
(2) Power pins, and
(2) 3" pieces of shrink tube
H2-JUMP.5 (6")
H2-JUMP3 (3ft)
H2-JUMP10 (10ft)



In-Line Splice Kit
(1) connection sleeve, (2) Power pins,
and (2) 3" pieces of shrink tube
H2-SPL



Mounting Track
Clear plastic
H2-TRACK-3 (3ft)



Mounting Channel
Aluminum
H2-CHAN-3 (3ft)




End Caps
(1) Clear plastic end caps
H2-ENDS



Mounting Clips
(10) Clear plastic clips
with (20) screws
H2-CLIPS

Hybrid 2 Reel Set-up*

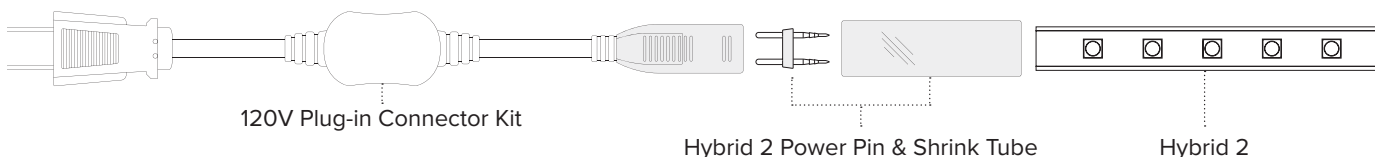

*H2-CONKIT-8A power connector kits are non-rated (four are included with each 150ft reel). The set-up illustration above is an example of how to connect non-rated power connector kits to cut product. Reels have pre-attached cETLus Listed power connection kit for 150ft installations.