


Meter stack modules—residential

Product overview

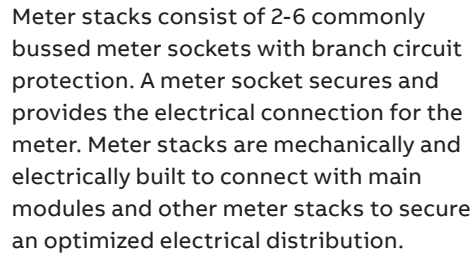

- All enclosures are NEMA 3R indoor/ outdoor construction
- Ring-type and ringless socket designs
- Ring-type meter stacks supplied with 4-jaw meter sockets (5th jaw kit available)
- 1PH ringless meter sockets supplied with 5-jaw meter sockets and available with factory-installed horn or lever bypass
- 3PH ringless meter sockets supplied with 7-jaw meter sockets and have lever bypass factory installed

[illegible]

Meter Mod III

Single phase 800A horizontal bussing 125 & 200A sockets

Socket amps	No. of sockets	Ordering code		
		Ring type socket (4 jaw socket standard)	Ringless type socket (5th jaw socket standard)	Ringless type socket (5th jaw socket standard) horned bypass factory installed
125	2	TMP8212R ¹	TMPR8212R	TMPR8212RHB
	3	TMP8312R ¹	TMPR8312R	TMPR8312RHB
	4	TMP8412R ¹	TMPR8412R	TMPR8412RHB
	5	TMP8512R ¹	TMPR8512R	TMPR8512RHB
	6	TMP8612R ¹	TMPR8612R	TMPR8612RHB
200	2	TMP8220R ¹	TMPR8220R	TMPR8220RHB
	3	TMP8320R ¹	TMPR8320R	TMPR8320RHB
	4	TMP8420R ¹	TMPR8420R	TMPR8420RHB
	5	TMP8520R ¹	TMPR8520R	TMPR8520RHB
	5	TMP8520RBUS ^{1,2}	TMPR8520RBUS ²	—

Single phase 800A horizontal bussing 125 & 200A sockets - CON ED approved

Socket amps	No. of sockets	Factory phase balancing	Ordering code	
			Ring type socket factory phase balanced with copper bus (4 jaw socket standard)	
			NEMA 1 indoor enclosure	NEMA 3R outdoor enclosure
125	2	AB	TMP8212AB	TMP8212RAB
		AC	TMP8212AC	TMP8212RAC
		BC	TMP8212BC	TMP8212RBC
	3	AB	TMP8312AB	TMP8312RAB
		AC	TMP8312AC	TMP8312RAC
		BC	TMP8312BC	TMP8312RBC
	4	AB	TMP8412AB	TMP8412RAB
		AC	TMP8412AC	TMP8412RAC
		BC	TMP8412BC	TMP8412RBC
	5	AB	TMP8512AB	TMP8512RAB
		AC	TMP8512AC	TMP8512RAC
		BC	TMP8512BC	TMP8512RBC

Single phase 1200A horizontal bussing 125 & 200A sockets

Socket amps	No. of sockets	Ordering code		
		Ring type socket (4 jaw socket standard)	Ringless type socket (5th jaw socket standard)	Ringless type socket (5th jaw socket standard) horned bypass factory installed
125	2	TMP12212R ¹	TMPR12212R	TMPR12212RHB
	3	TMP12312R ¹	TMPR12312R	TMPR12312RHB
	4	TMP12412R ¹	TMPR12412R	TMPR12412RHB
	5	TMP12512R ¹	TMPR12512R	TMPR12512RHB
	6	TMP12612R ¹	TMPR12612R	TMPR12612RHB
200	2	TMP12220R ¹	TMPR12220R	TMPR12220RHB
	3	TMP12320R ¹	TMPR12320R	TMPR12320RHB
	4	TMP12420R ¹	TMPR12420R	TMPR12420RHB
	5	TMP12520R ¹	TMPR12520R	TMPR12520RHB
	5	TMP12520RBUS ^{1,2}	TMPR12520RBUS ²	TMPR12520RHBUS ²

¹ One snap-type, aluminum sealing ring (TSR5) per socket included

² BUS suffix indicates change to centerline of horizontal bussing from 28.88" to 41.01" from bottom of unit