



Zurn One Sensor Wall Hung Toilet System with 1.28 GPF EcoVantage® Battery Powered Flush Valve Z.WC2.S

TAG _____

ARCHITECTURAL & ENGINEERING SPECIFICATION

Complete EcoVantage® high efficiency 1.28 gpf sensor actuated, battery powered, wall mounted commercial water closet system with ZER6000AV-HET-SM exposed, sensor activated chrome-plated closet diaphragm flushometer for either left or right hand supply, Z5955SS-EL open front commercial toilet seat, Z5615-BWL wall mounted vitreous china water closet with Z5977-NEO NeoSeal outlet sealing gasket assembly kit and Z5610-NUT-EXT-KIT manufactured by Zurn.

PRODUCT FEATURES

- 1.28 gpf (gallons per flush)
- Wall mounted elongated front rim top spud toilet
- High efficiency siphon jet flush action
- 2-1/8" fully glazed trapway
- Large water spot - 12" x 10"
- Vitreous china wall bowl construction
- Static weight load of 1000 lb*
- *Not intended for bariatric use
- Diaphragm- type flushometer complete with Zurn's Go Blue® TPE, chloramine resistant, dual seal diaphragm with a clog resistant, triple filtered bypass
- High pressure vacuum breaker with one piece hex coupling nut
- Adjustable tailpiece
- True mechanical override button
- Control Stop has internal siphon-guard protection, sweat solder kit, wall flange with set screw
- Open front, elongated, white commercial toilet seat with SS check hinges
- NeoSeal® outlet gasket assembly
- 20% water savings over standard 1.6 gpf system

COMPLIANCE AND CERTIFICATION:

Meets the American Disabilities Guidelines and ANSI A117.1 requirements when installed according to these requirements.

- Fixture - Complies with ASME A119.2 / CSA B45.1
- Flush Valve - Complies with ASSE 1037 / ASME A112.10.37 / CSA B125.37



This product should be used with a WaterSense labeled counterpart with a compatible flow volume to ensure that the entire system meets the requirements for water efficiency and performance.



This system complies with the Buy American Act: Valve manufactured in the United States; Fixture manufactured in China.



1 ZURN
ONE
SYSTEMS

ZURN ONE SYSTEM PACKOUT INCLUDES:

FIXTURE - Z5615-BWL:

Vitreous China, 1.1 gpf [4.2 Lpf] or greater high efficiency wall hung toilet with siphon jet flushing action and elongated front rim with 1-1/2" [38mm] top spud

FLUSH VALVE - ZER6000AV-HET-SM:

Exposed, quiet diaphragm-type, chrome-plated flushometer valve with a polished exterior. Complete with Zurn's AquaVantage® TPE, chloramine resistant, dual seal diaphragm with a clog resistant, triple filtered bypass. The valve incorporates a 6VDC motor actuator, a battery powered automatic sensor, chrome-plated metal cover with manual override push button and 10 degree angled sensor

Z5955SS-EL:

Elongated, open front white toilet seat with stainless steel check hinges

Z5610-NUT-EXT-KIT:

Retrofit nut kit for extending carrier studs from existing wall

Z5977-NEO:

NeoSeal® gasket kit for wall mounted bowls


RECOMMENDED CARRIER:

Z1201 or Z1202 EZCarry™ 500 lbs load rated High Efficiency Carrier

ARCHITECTURAL & ENGINEERING APPROVAL

The information contained in this document is subject to change without notice. Please contact Zurn for most up to date information.

Rough-in / Overview dimensions

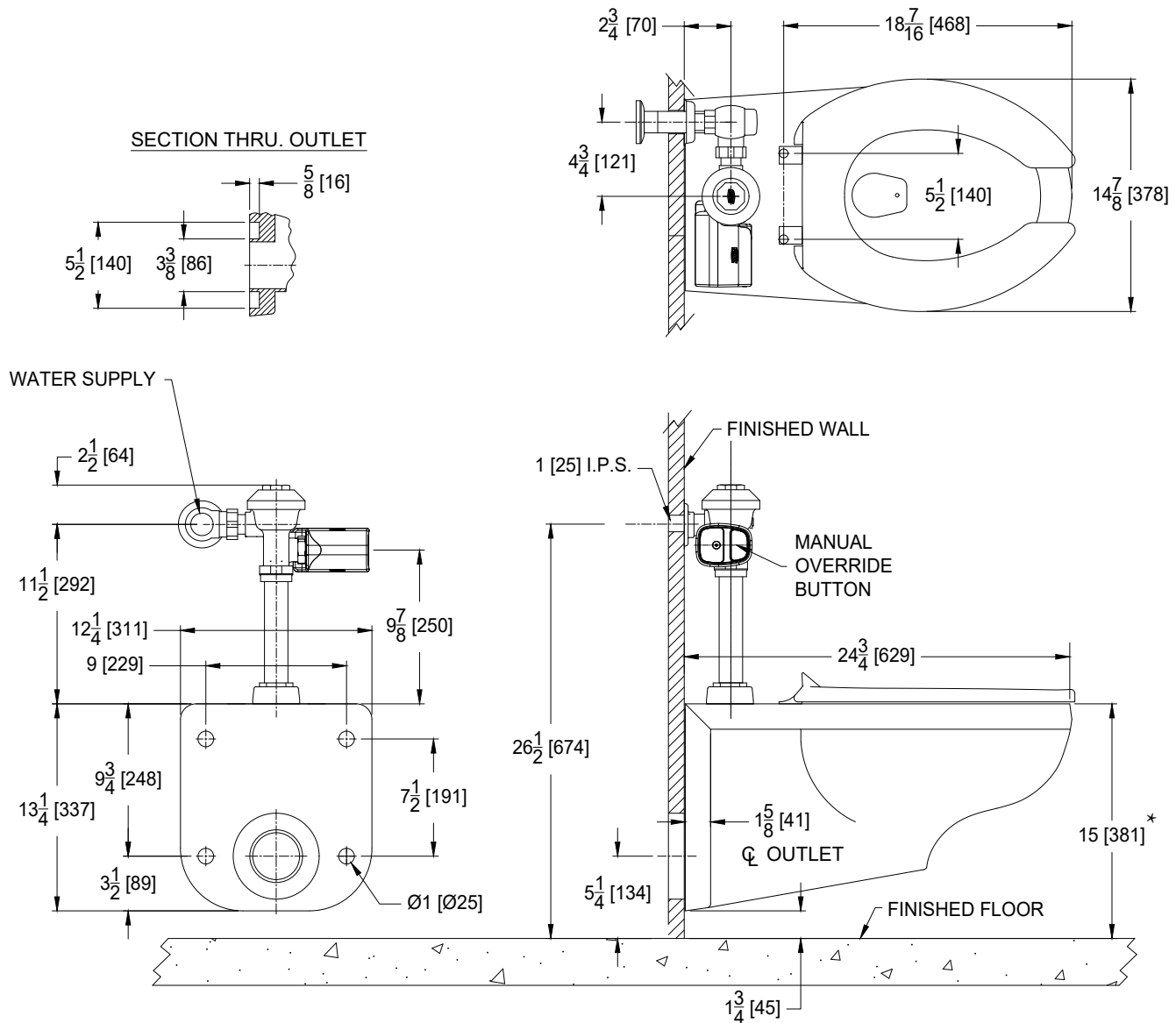

*NOTE: For ADA compliance, top of seat height should be installed at 17" [431mm] -19" [482mm] from finished floor.