

20A | 100PSI

NOCO® AIR20



ULTRAFAST® PORTABLE AIR COMPRESSOR.

UNPARALLELED SPEED.

NOCO AIR has been tested and proven to operate longer and inflate faster than leading competitors. Inflate flat tires from 0 to 40 psi in under 3 minutes.

COMPACT DESIGN.

Integrated hose clips, dedicated slots for accessories, and effortless power-cord storage allow AIR to be quickly and easily stored or used.

PREMIUM BUILD.

NOCO AIR is built with solid aluminum, heavy-duty powder coat, and reinforced plastic.

LED FLASHLIGHT.

Provides a tactical-grade experience with long-range, bright illumination, controllable luminosity, and emergency modes.



NOCO®

30339 Diamond Parkway, #102
Glenwillow, OH 44139 | USA
1.800.456.6626

no.co

ULTRAFAST[®] INFLATION



SMART PRESSURE AUTO-SHUTOFF

AIR automatically shuts off upon reaching the desired pressure. Utilizing a unique algorithm — AIR achieves precise accuracy even at higher pressure.



Integrated Hose Clip

Adapters

280 W
MOTOR POWER

2.5 MIN 0-40 PSI
TIME TO INFLATE
*205-65R16 95H TIRE

47 SLPM
FLOW RATE

INTUITIVE INTERFACE.



Compressor
On/Off



Digital
Display

PSI,KPA,
BAR,SET

Pressure
Down/Up

LED
On/Off

WHAT'S IN THE BOX

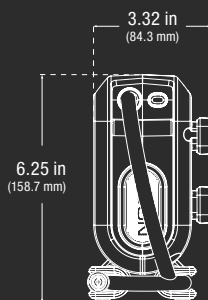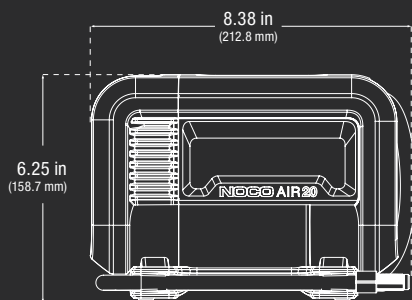

AIR20 Portable Air Compressor
w/ 3ft Braided Hose & 20ft
Power Cord + Clamps



User Guide &
Warranty Information



Needle Adapter



Presta Valve Adapter



Inflatable Toy Adapter



Microfiber Storage Bag

TOTAL VERSATILITY.

With its rugged portable design, integrated cord management, dedicated slots for accessories, and ultra-compact size, it can easily be stored - and ready to take on anything.

TECHNICAL SPECIFICATIONS

MAX AIRFLOW AT 0 PSI:	47 SLPM
MAX PRESSURE:	100 psi / 6.89 bar / 689.48 kPa
MOTOR RATING:	280W
MOTOR MAX CURRENT DRAW:	22A
DUTY CYCLE:	15 min @ 30PSI on time/45 min off time
MANUAL MODE DUTY CYCLE:	5 min on time/30 min off time
APPROXIMATE INFLATION TIME at 13.8V (0-40 PSI):	2.7 min +/- 10% with 205-65R16 95H Tire
AIR HOSE LENGTH:	3 ft
POWERCORD LENGTH:	20 ft
WIRE GAUGE:	14 AWG
POWER TYPE:	Clamps
IP RATING:	IP55
COOLING:	Natural Convection
OPERATING TEMPERATURE:	-4° to 122° F (-20° to +50° C)
STORAGE TEMPERATURE:	-4° to 122° F (-20° to +50° C)
WEIGHT:	6.81 lbs (3.09 kg)
VOLUMETRICS:	Retail Packaging: Dimensions: 11.81" x 5.79" x 9.02" Weight: 8.84 lbs UPC: 0-46221-23004-8 Master Carton: Dimensions: 19.33" x 13.78" x 12.64" Weight: 38.40 lbs Quantity: 4 ITF-14: 10046221230045 Inner Carton: Dimensions: 12.13" x 6.38" x 9.41" Weight: 9.24 lbs Units Per Pallet: NA: 72 units AU/UK/HP/JP: 48 units EU/ND/RM/FN: 40 units

NOCO

30339 Diamond Parkway, #102
Glenwillow, OH 44139 | USA
1.800.456.6626

no.co

IP55



FC CE

