

LONG FOOT SEALER W/ SLIDING CUTTER

MODEL WN-900C

sealersales



Make bags out of poly tubing

- Easy to operate
- Ideal for high volume sealing
- Cut and seal materials up to 35.4"
- Plug-in electronic timer for variable control
- All metal heavy duty construction
- No warm up time
- Sits on rectangular base for stability
- Includes work table

Video Demo →




Our **WN-900C Long Foot Impulse Sealer with Sliding Cutter** are perfect for long poly bag sealing at high volumes, featuring a built-in sliding cutter for added convenience. Available in a 35.4" length and producing a 2.7mm seal, they can seal 15-20 bags per minute. With hands-free operation, you can achieve faster and more accurate seals. Once the timer is set, the sealer ensures a consistently flat and secure seal.

The WN-900C model comes equipped with a durable 26" steel frame for increased safety and stability. It also includes a height-adjustable working plate for added versatility. The manufacturer's replacement kit comes with two elements.

Easy to Operate: Set the timer. Insert the bag between the two sealing bars and press down on the foot board. Hold down the foot board for an additional 2-3 seconds after the timer light goes off to set the seal. To use the sliding cutter, slide the cutting blade across the material.


SPECIFICATIONS	WN-900C
POWER	110V / 50HZ / 600W
SEAL AND CUT LENGTH	35-2/5" (900MM)
SEAL WIDTH	2.7MM
STANDING HEIGHT	33-1/2"
TRAY DIMENSIONS	27-1/2" x 7"
TRAY ADJUSTMENT HEIGHT	UP TO 6-1/2"
THROAT DEPTH	3-1/2"
DIMENSIONS	38" X 19" X 38"
WEIGHT (NET / GROSS)	75-LBS / 88-LBS

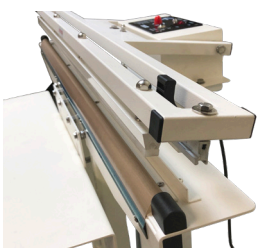

Sliding Cutter



Adjustable Work Table

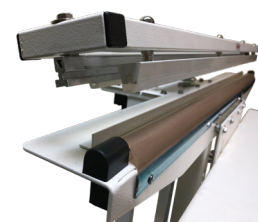

3-1/2" Throat Depth