


ADPD703H, ADPD1103H, ADPD453L, ADPD4FBL3P

Paddle™ Style Dimmers

adorne® Paddle™ Style Dimmers include a slider for dimming or brightening lights paired with a switch that features a wide graceful paddle that works with a simple up and down motion, allowing you to turn lights on and off with ease. Integral silver contacts provide long-lasting performance.

Pair a Locator Status Light with your Paddle Dimmer to add illumination and make it easier to locate in the dark. adorne® Paddle™ Style Switches/Dimmers are available in white, magnesium or graphite finishes to complement the broad range of adorne device plate options that are available.

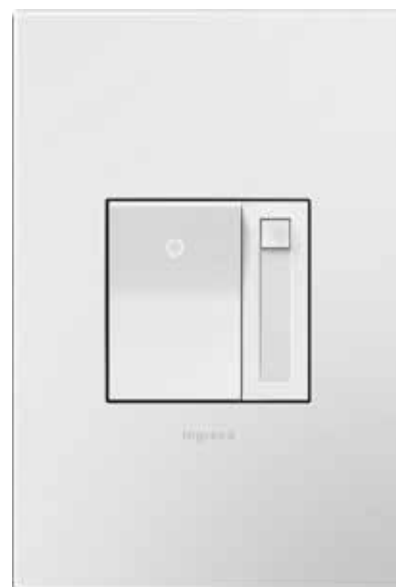


FEATURES & BENEFITS

adorne devices fit in all existing NEMA-approved wallboxes.

Heavy gauge steel frame is grounded via factory installed 12AWG ground lead. Device and metal wall plates are self-grounded to frame.

Device snaps into the frame and self-aligns without any screws.

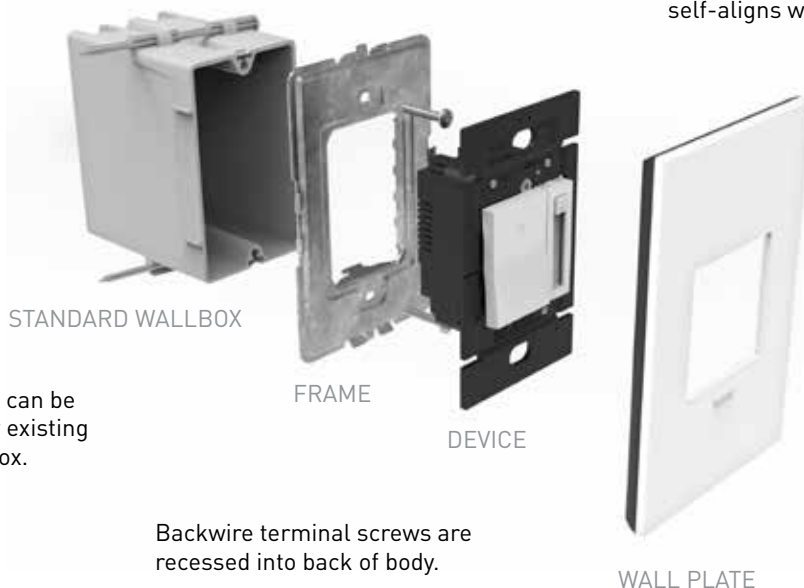

adorne devices can be installed in any existing standard wallbox.

Backwire terminal screws are recessed into back of body.

Wall plate snaps onto frame; no screws required.

Modular system solves device alignment problems, improving fit and finish in multi-gang installations.

Wall plate and frames available in 1-6 gang sizes.

ORDERING INFORMATION

CATALOG NUMBER	DESCRIPTION	RATING	COMPATIBLE LOADS	COMPLIANCE	COLORS	COO
ADPD4FBL3P2M4	Single-Pole/ 3-Way 2 Wire	0-10V	Fluorescent, LED		Magnesium	China
ADPD4FBL3P2W4	Single-Pole/ 3-Way 2 Wire	0-10V	Fluorescent, LED		White	China
ADPD4FBL3P2G4	Single-Pole/ 3-Way 2 Wire	0-10V	Fluorescent, LED		Graphite	China
ADPD453LM2	Single-Pole/ 3-Way 2 Wire	450W	CFL, LED		Magnesium	China
ADPD453LW2	Single-Pole/ 3-Way 2 Wire	450W	CFL, LED		White	China
ADPD453LG2	Single-Pole/ 3-Way 2 Wire	450W	CFL, LED		Graphite	China
ADPD703HM4	Single-Pole/ 3-Way 2 Wire	700W	Incandescent, Halogen		Magnesium	China
ADPD703HW4	Single-Pole/ 3-Way 2 Wire	700W	Incandescent, Halogen		White	China
ADPD703HG4	Single-Pole/ 3-Way 2 Wire	700W	Incandescent, Halogen		Graphite	China
ADPD1103HM2	Single-Pole/ 3-Way 2 Wire	1100W	Incandescent, Halogen		Magnesium	China
ADPD1103HW4	Single-Pole/ 3-Way 2 Wire	1100W	Incandescent, Halogen		White	China

Accessories, Locator Status Light

AALS6



Locator Status Light

Add a stylish, small locator light to your Paddle switch or dimmer and you'll never again have to slide your hand across the wall trying to find that switch.

Locator light is on when the load is off and off when the load is on.



COMPLEMENTARY PRODUCTS

adorne® also offers Paddle Style Dimmers and Fan Control Devices to pair with our Paddle Style Switches for an overall, aesthetically pleasing and multi-functional installation.

adorne® Wall Plates provide the perfect complement to adorne Switches, Dimmers, Outlets, and Accessories. The collection includes a variety of finishes, from metals to leather and wood, as well as plastic plates that are available in contemporary and classic colors.

Each wall plate is packaged with a metal frame to enable easy installation when paired with a device. All plates are screwless and simply snap onto the included metal frame.

All adorne wall plates are UL and ETL-approved.



2-Module
Paddle Fan
Speed Control



1-Module
Paddle Switch

VERTICAL MARKETS

- Residential
- Hospitality
- Luxury Office
- Light Commercial

TECHNICAL SPECIFICATIONS

3rd Party Compliance

cULus Listed, File Number E95219, Standard UL1472, Dimmers

Performance

ELECTRICAL

RATINGS

ADPD453L	ADPD703H	ADPD1103H
120VAC	120VAC	120VAC
60Hz	60Hz	60Hz
600W INC 450W CFL/LED	700W Inc/Halogen	1100W Inc/Halogen

MECHANICAL

Back Wire	With internal pressure plates, #8-32 screw
Terminal Accommodations	#14AWG-#12AWG

ENVIRONMENTAL



Flammability	UL94 V2
--------------	---------

Materials

Paddle	Polycarbonate	Terminal	Brass
Back Body	Polycarbonate	Termination	Steel Plated Screws
Contacts	Silver		

Warranty

Lifetime Limited Warranty

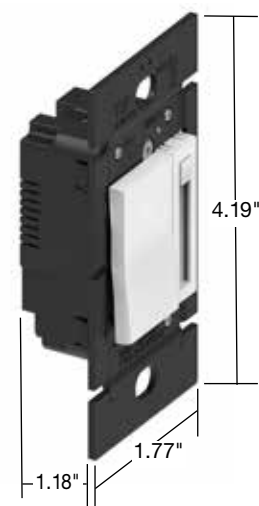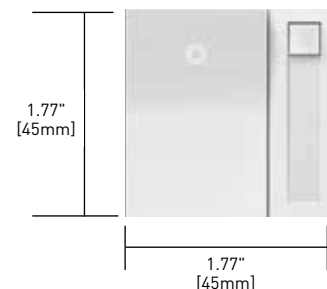

COMPLEMENTARY DEVICES & ACCESSORIES



sofTap™

Switches & Dimmers – designed with an innovative micro-movement that turns lights on and off with just a soft “tap” of the finger.



SensaSwitch™

Switches & Dimmers – Sensor turns lights on when you enter a room and off when you leave. (Also available in Manual-ON/Auto-OFF format.)




Whisper™

Switches & Dimmers – A smart design that features elegant lines and a quiet, fluid motion.



Touch™

Switches & Dimmers – A stunning translucent face works just like an iPhone® — simply touch your finger on the circle to turn lights on and off.

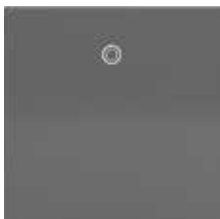

Paddle™

Switches, Dimmers & Fan Speed Controls – A wide, graceful curve works with a simple up-and-down motion, allowing you to turn lights on and off with ease.




Wave™

Switches – Smart technology combined with sleek, modern design. Simply wave your hand to turn lights on and off.



Push™

Switches – A tactile, finger-sized impression lets you turn lights on and off with a simple push-button motion.

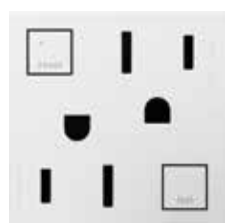

Tamper-Resistant Outlets/ Tamper-Resistant GFCI Outlets



USB Charging Outlets



Nightlight/Portable Nightlight Flashlight

PLUS: Compatible Wall Plates, Accent Lights, Locator Lights, Under-Cabinet Lighting System

NOTE: All brand and product names referenced in this document are registered trademarks or trademarks of their respective holders.



NOTE: The paper used to print this document is an environmentally responsible paper with 10% post consumer waste, with FSC and SFI Chain of Custody certifications, Lacey Act compliant. 100% of the electricity used to manufacture Flo sheets is generated with Green-e certified renewable energy.



Legrand, North America
60 Woodlawn Street
West Hartford, CT 06110
1.877.BY.LEGRAND (295.3472)
www.legrand.us

Canada
905.738.9195
www.legrand.ca

FOLLOW US

