

PRODUCT SPECIFICATIONS

MODEL NO.	MOTOR	RPM		AMPS		HP	kW	NET WT.		CAPACITOR	
		60HZ	50HZ	60HZ	50HZ			lbs.	kg	mfd.	VOLT
87R642-PS103R-N470X	115-120/230-240 (60Hz) 110-120/220-240 (50Hz)	1725	1425	5.7/2.8	5.1/2.6	1/2	0.37	19.1	8.6	30	370

SOUND LEVEL LESS THAN 60 db(A)

NORMAL AMBIENT +5 °C - +40 °C


RELATIVE HUMIDITY 20% - 80%

ENVIRONMENT CLEAN DUST FREE

NOTES:


1. TECHNICAL DATA SUBJECT TO CHANGE WITHOUT NOTICE.
2. THIS PUMP MUST BE INSTALLED IN AN ENCLOSURE.
3. ALL DIMENSIONS ARE FOR REFERENCE ONLY.
4. KIT P/N: K965
5. THIS MODEL HAS A BIASED VALVE TO AID RESTART.
6. THIS UNIT UTILIZES SOUND SHIELD (SSP-87R6-02), WHICH HAS A RECOMMENDED SERVICE INTERVAL OF 2,000 HOURS OR 2 YEARS.

PRODUCT PERFORMANCE:

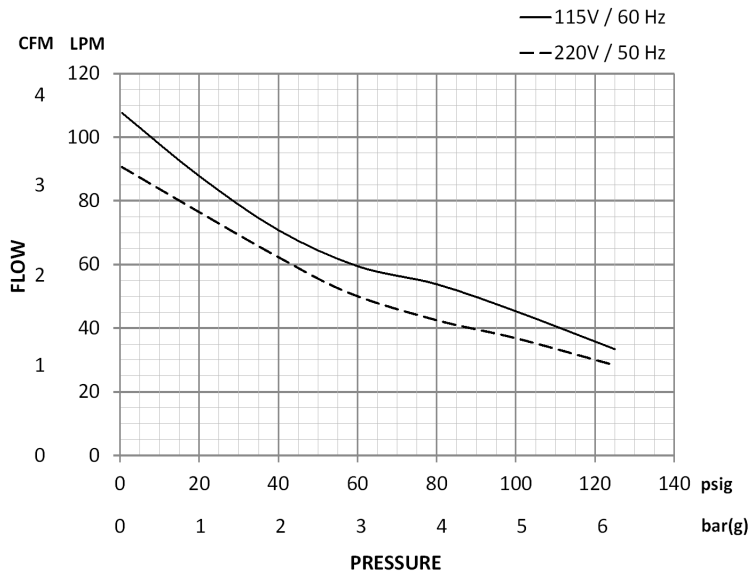


PRODUCT DIMENSIONS:

WIRING DIAGRAM

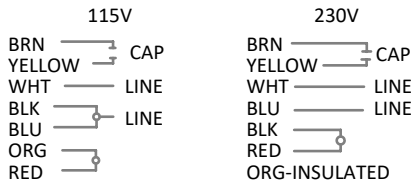

CAPACITOR MOUNTING KIT TO BE SHIPPED UNATTACHED.

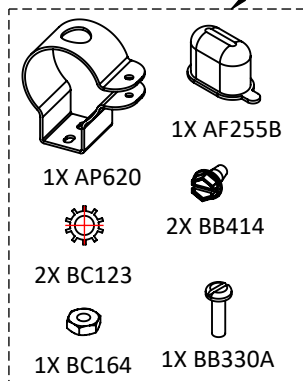

CAPACITOR TO BE SHIPPED UNATTACHED

