



**MCR
SAFETY**

N9699

Ninja

Dipped

Specification Sheet

PRODUCT DESCRIPTION:

MCR Safety Ninja® gloves are engineered to provide the highest level of innovation. Each of the offerings in the Ninja® series include a unique shell and polymer combination incorporating the latest in hand protection technology. Our Ninja® glove line offers the greatest assortment of dexterity, sense of touch, and protection. The Ninja® N9699 HPT coated work gloves feature a 15 gauge black nylon shell and a dark gray foam sponge coated palm and fingertips. The HPT material repels liquids and is a great option for firm grip general purpose gloves in wet or dry conditions. Looking for the best work gloves? Look no further than MCR Safety!

FEATURES:

- 15 Gauge Black Nylon Shell
- Black HPT Foam Coated Palm and Fingertips
- Dark colors hide dirt, grit and grime
- Firm grip general purpose gloves
- The porous HPT coating with Anti-Wet treatment repels liquid for an unprecedented firm grip in wet or dry conditions
- Encapsulated Air Molecules provide a cushioning effect to minimize impact



APPLICATIONS:

Automotive Assembly, Farming, Landscaping, Material Handling, Warehousing

TECHNICAL DATA FOR: N9699

Series	Ninja	EN 388: CE Score - Abrasion	4
Material Group	Strings	EN 388 : CE Score - Cut	1
Product Type	Dipped	EN 388 : CE Score - Tear	3
Glove Size	Large	EN 388 : CE Score - Puncture	1
Gauge	15 Gauge	ANSI Puncture	2
Material	Nylon	ANSI Abrasion	3
Made In	Pakistan		

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA


Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2021 MCR Safety - All Rights Reserved



MCR
SAFETY

N9699
Ninja
Dipped
Specification Sheet

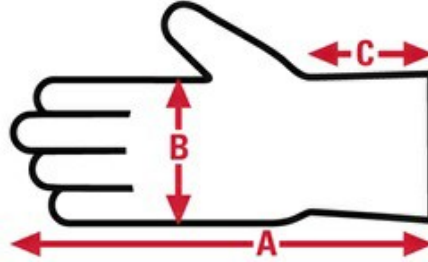

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
N9699M	Medium	10.039	3.780	N/A	21.816 lb.	1.818
N9699XL	X - Large	10.827	4.173	N/A	25.104 lb.	2.092
N9699S	Small	9.646	3.642	N/A	17.784 lb.	1.482
N9699L	Large	10.425	3.976	N/A	22.656 lb.	1.888

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2021 MCR Safety - All Rights Reserved