


Ocal® PVC-coated hanger rod beam clamps

Corrosion-protected clamps for hanging threaded rod

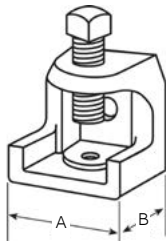

500-G
Hanger Rod Beam Clamp



Product features

- Malleable iron construction
- Nominal .007 - .015" (7 - 15 mil) PVC coating in blue, white, gray or custom colors
- 500, 502 and 503 also available uncoated in Type 316 stainless steel; add -SS316 to catalog number to order (for example: 502-SS316)

Ocal® PVC-coated hanger rod beam clamps

Product Code	Base "A"		Base "B"		Jaw Opening		Tapped Hole		Load Rating [‡]	
	(in.)	(mm)	(in.)	(mm)	(in.)	(mm)	(in.)	(mm)	(lbs.)	(kg)
500- <u> </u>	1	25.40	1¼	31.75	15/16	23.81	¼-20	6.35 - 20	450	204.12
501- <u> </u>	1½	38.10	1⅝	41.28	7/8	22.23	15/16-18	7.94 - 18	800	362.87
502- <u> </u>	2	50.80	2	50.80	1	25.40	3/8-16	9.53 - 16	1300	589.67
503- <u> </u>	2⅝	66.68	2½	63.50	1	25.40	1/2-13	12.70 - 13	1300	589.67
508- <u> </u>	2½	63.50	2⅜	60.33	2⅛	53.98	1/2-13	12.70 - 13	1700	771.11

* Metric size designator (ANSI C80.1-1994).

‡ Load ratings based on bottom hole of beam clamp with safety factor of three.
CSA File No. LR-52208

Product Code	Colour
500- <u> </u>	<u> </u>
<u> </u>	= space for color identifier
G = Gray	
W = White	
B = Blue	
Custom colors also available.	

Ocal® PVC-coated mini conduit hangers

Includes stainless steel bolt and nut for fast, easy installation



MINE3/4-G
Mini Conduit Hanger

Product features

- Nominal .007 - .015" (7 - 15 mil) PVC coating in blue, white, gray or custom colors
- Rated for loads of up to 500 lbs. (226.80kg) with a safety factor of three

Ocal® PVC-coated mini conduit hangers

Product Code	Pipe Size (in.)	Metric Size Designator*
MINE1/2- <u> </u>	½	16
MINE3/4- <u> </u>	¾	21
MINE1- <u> </u>	1	27
MINE1-1/4- <u> </u>	1¼	35
MINE1-1/2- <u> </u>	1½	41

* Metric size designator (ANSI C80.1-1994).

Product Code	Pipe Size (in.)	Metric Size Designator*
MINE2- <u> </u>	2	53
MINE2-1/2- <u> </u>	2½	63
MINE3- <u> </u>	3	78
MINE3-1/2- <u> </u>	3½	91
MINE4- <u> </u>	4	103

Product Code	Colour
MINE1- <u> </u>	<u> </u>
<u> </u>	= space for color identifier
G = Gray	
W = White	
B = Blue	
Custom colors also available.	