

TOULOUSE

504-31-VB

FINISHES

VINTAGE BRASS

Coastal Suitable Finish (EPM): No

DIMENSIONS

Height: 25"

Width/Diameter: 31"

Minimum Height: 29.75"

Maximum Height: 98.25"

Canopy/Backplate: 13.75"

Hanging Type: 72" Chain

Product Weight: 60.858lb

Canopy/Backplate Shape: Round

Sloped Ceiling Compatible: No

Living Finish: Yes

Uplight Only: No

Shade

Shade 1: Glass

Shade 1 Finish: Light Bronze

Shade 1 Top Width: 10.75"

Shade 1 Height: 6.25"

Shade 2: Acrylic

Shade 2 Finish: Opal Glossy

Shade 2 Top Width: 2.25"

Shade 2 Height: 20"



ELECTRICAL



Bulb 1

Bulb Included: N/A

Socket: Integrated LED

Bulb Type: LED

Max Wattage: 40

Bulb Quantity: 5

Bulb Included: Yes

Wire Length: 144"

Cord Type: SPT-1 SILVER W/ TINNED GROUND
WIRE

Dimmer Type: TRIAC, 0-10 VOLT

Gem Box Required (2"x3"): No

Dark Sky: No

CRI: 90

Color Temp.: 2700k

Lumens: 1725

Title 24: No

Field Serviceable: Yes


SHIPPING

Carton 1: 50" x 25" x 25"

Carton 1 Weight: 90lb

Shipping Method: Truck Only

Country of Origin: VN

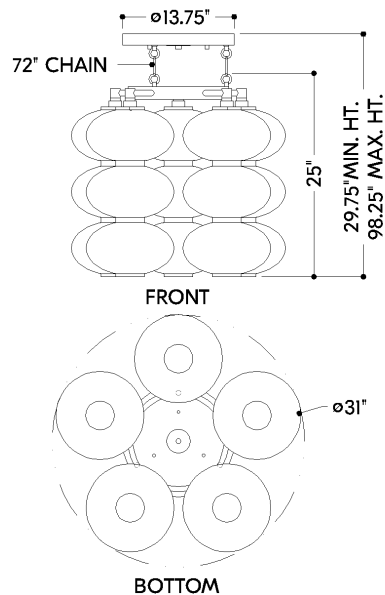

HUDSON VALLEY
LIGHTING GROUP

| hvlgroup.com | 1.800.814.3993

REVISED 3.11.2022