



EAN: 4013288221278
Part number: 05134025001
Article number: Wera 2go E 1

Size: 370x345x140 mm
Weight: 7300 g
Country of origin: DE (05)
Customs tariff number: 82032000

- Extensive 73-piece tool set in the compact Wera 2go 2 tool container for electricians in mobile operations
- Premium brand tools by Wera, Jung, KNIPEX®, Lyra®, PICARD®, PUK® and Stabila®
- Wera Kraftform Kompakt Turbo i 1 Tool Finder (16-piece handle/interchangeable blades VDE set) for four times the screwdriving speed and Wera 8100 SA 6 Zyklus Speed ratchet set (1/4", 28-piece set)
- Joker 6004 S self-setting spanner for bolts and screws of 10-13mm (metric) and 7/16"-1/2" (imperial)
- With chiseldriver for screwdriving, chiselling, mortising as well as 4 VDE screwdrivers - 2 of which with stainless steel blade to prevent extraneous rust

Compact tool set with the 73 most important tools for electricians with products by Wera, Jung, KNIPEX®, Lyra®, PICARD®, PUK® and Stabila®. Mobility is made considerably easier thanks to the compact tool container from the Wera 2go system.



Web link
<https://www.wera.de/en/05134025001>

Wera - Wera 2go E 1
05134025001 - 4013288221278


Wera Werkzeuge GmbH
Korzter Straße 21-25
D-42349 Wuppertal
Tel: +49 (0)2 02 / 40 45-0
E-Mail: info@wera.de

Fast movers




The Zyklop Speed ratchets are really fast movers. The gyrating mass design means that screwdriving is accelerated. The rotation-symmetric structure of the Kraftform handle and the free-turning sleeve reinforce this rapid twisting process, particularly when the ratchet does not engage due to too little resistance in the thread.

Joker 6004: automatically and continuously self-setting

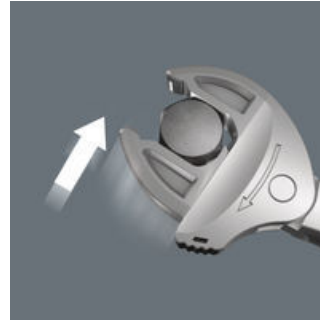

With its automatically and continuously gripping parallel jaws the Joker spanner 6004 covers all dimensions in the respective field of application. The tool automatically finds the required size when placed on the bolt or screw, no setting required.

Joker 6004: low return angle

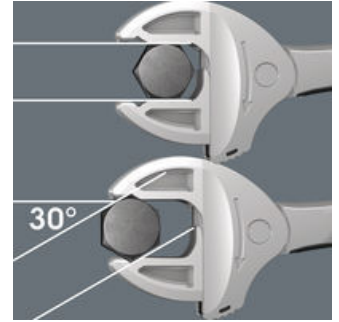

The corner-width rectangular prisms in the jaw allow a return angle of only 30°.

Joker 6004: Ratchet mechanism for quick working



The ratchet feature in the jaw ensures fast and consistent screwdriving without removing the tool.

Wera Stainless Steel Tools.




Solution to the rust problem: screwdriving stainless steel together with stainless steel! Wera stainless steel tools are manufactured out of stainless steel so unsightly rust can be avoided.

Kraftform Kompakt Turbo VDE



Many users would like to be able to carry out screwdriving processes faster without compromise. With a screwdriver that is precise, allows powerful screwdriving, and is much faster than a conventional screwdriver. A part-time universal gear is the solution: Integrated in the screwdriver handle, it quadruples the working speed with smooth couplings - purely mechanically. One hand holds the front part of the handle, the other hand turns the rear part of the handle. The turbo function can be switched on or off at the push of a button. Turning it off is recommended for tightening and loosening with high torque, e.g. for screw connections in wood, as well as for fine adjustments. Robust, maintenance-free gear made of steel with a maximum torque of 14 Nm when the turbo function is deactivated. With the Wera VDE interchangeable blades individually tested as per IEC 60900, the VDE version of the Kraftform Turbo hand holder 827 T i guarantees fast and safe working even in live environments (up to 1,000 volts).

Take it easy Tool Finder

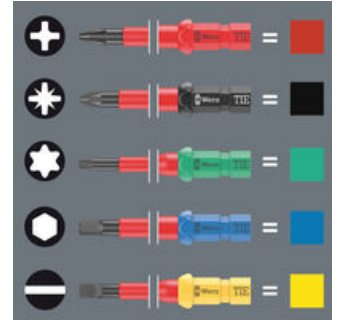

The Kraftform Kompakt VDE blades are equipped with the Take it easy Tool finder. The colour coding by profile and the laser-engraved size indication make it easy to identify the required tool quickly.

Web link

<https://www.wera.de/en/05134025001>

Wera - Wera 2go E 1

05134025001 - 4013288221278

Wera Werkzeuge GmbH

Korzerter Straße 21-25

D-42349 Wuppertal

Tel: +49 (0)2 02 / 40 45-0

E-Mail: info@wera.de

Set contents:

Wera 2go 2 Tool Container, 3 pieces

05004351001

1x 3 pieces



8100 SA 6 Zyklop Speed Ratchet Set, 1/4" drive, metric, 28 pieces

05004016001

1x 28 pieces



950/9 Hex-Plus Multicolour HF 1 L-key set, metric, BlackLaser, with holding function, 9 pieces

05022210001

1x 9 pieces



Kraftform Kompakt Turbo i 1 Tool finder, 16 pieces

05006640001

1x 16 pieces



932 A Screwdriver for slotted screws, 1.2 x 7 x 125 mm



05018266001

1x 1.2 x 7 x 125 mm



3162 i PH VDE Insulated screwdriver for Phillips screws, stainless, PH 2 x 100 mm

05022734001

1x PH 2 x 100 mm



3165 i PZ VDE Insulated screwdriver for Pozidriv screws, stainless, PZ 2 x 100 mm

05022741001

1x PZ 2 x 100 mm



Web link

<https://www.wera.de/en/05134025001>

Wera - Wera 2go E 1

05134025001 - 4013288221278

Wera Werkzeuge GmbH

Korzerter Straße 21-25

D-42349 Wuppertal

Tel: +49 (0)2 02 / 40 45-0

E-Mail: info@wera.de

160 i VDE Insulated screwdriver for slotted screws, 1.2 x 6.5 x 150 mm



05006125001

1x 1.2 x 6.5 x 150 mm



160 iS VDE Insulated screwdriver with reduced blade diameter for slotted screws, 0.6 x 3.5 x 100 mm

05006440001

1x 0.6 x 3.5 x 100 mm



6004 Joker S Self-setting spanner, 10; 11; 12; 13 x 7/16; 1/2" x 154 mm

05020100001

1x 10; 11; 12; 13 x 7/16; 1/2" x 154 mm



KNIPEX Combination pliers 160mm 01 06 160

1x KNIPEX Combination pliers 160mm 01 06 160



KNIPEX Diagonal insulation stripper 14 26 160

1x KNIPEX Diagonal insulation stripper 14 26 160



KNIPEX Snipe nose pliers with blade (stork beak pliers) 26 16 200

1x KNIPEX Snipe nose pliers with blade (stork beak pliers) 26 16 200



KNIPEX Cobra® VDE Hightech water pump pliers, insulated, 87 26 250

1x KNIPEX Cobra® VDE Hightech water pump pliers, insulated, 87 26 250



KNIPEX Cable knife 98 52

1x KNIPEX Cable knife 98 52



KNIPEX ErgoStrip® Universal dismantling tool 16 95 01

1x KNIPEX ErgoStrip® Universal dismantling tool 16 95 01



PUK® 2200 Hand saw frame

1x PUK® 2200 Hand saw frame



Lyra® Construction marker DRY PROFI 4494202

1x Lyra® Construction marker DRY PROFI 4494202



Web link

<https://www.wera.de/en/05134025001>

Wera - Wera 2go E 1

05134025001 - 4013288221278

Wera Werkzeuge GmbH

Korzerter Straße 21-25

D-42349 Wuppertal

Tel: +49 (0)2 02 / 40 45-0

E-Mail: info@wera.de

STABILA® Spirit level Pocket Electric 17775



1x STABILA® Spirit level Pocket Electric 17775

STABILA® Spirit level type 70, 30 cm, 02281



1x STABILA® Spirit level type 70, 30 cm, 02281

STABILA® Wooden folding rule type 607, 2 m, yellow, 01104



1x STABILA® Wooden folding rule type 607, 2 m, yellow, 01104

PICARD® Fitter's hammer 400 g, German shape, 000101-0400



1x PICARD® Fitter's hammer 400 g, German shape, 000101-0400

Jung Plastering cup 127mm, 946 127 00



1x Jung Plastering cup 127mm, 946 127 00

Jung Scraping knife with natural wood handle, 922 050 00



1x Jung Scraping knife with natural wood handle, 922 050 00

Web link

<https://www.wera.de/en/05134025001>

Wera - Wera 2go E 1

05134025001 - 4013288221278

Wera Werkzeuge GmbH

Korzerter Straße 21-25

D-42349 Wuppertal

Tel: +49 (0)2 02 / 40 45-0

E-Mail: info@wera.de