




Ortronics
Clarity 6 TracJack, T568A/B, 180 degree, Orange
Part No. TJ600-43

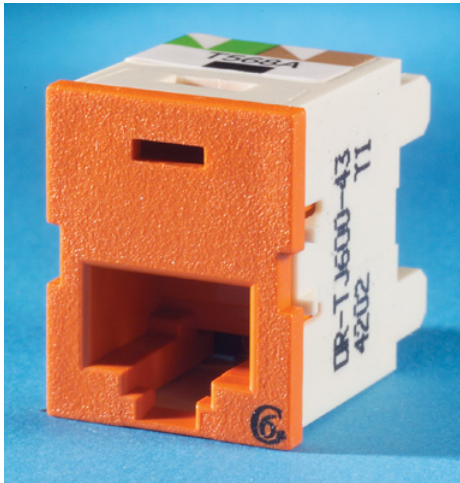

Clarity 6a, 6 & 5e TracJacks, ETL verified to TIA Category 6a, 6 & 5e component specification. Front-loading and front removable. New universal T568A/B wiring label and tapered wiring towers simplify termination. Center tuned to Clarity patch cords for optimum performance.

TracJack® modules combine the ease and reliability of a front-loading individual jack with 110 termination.

Features & Benefits

ETL Verified to Category 6A component standard: Ensures standards compliance.

Easy to follow universal wiring label: Quick and user-friendly, eliminates confusion.

Center tuned design: Transparent interface with Clarity 6A/10G cords

Easy lace IDC housing: Reduces wiring time

Standard TracJack footprint: Fits in all TracJack faceplates and housings

Icon compatible, C6A marking on jack face: Supports 606 designation requirements

Specifications

General Info

Product Line	Ortronics	Color	Orange
UPC Number	662875437901	Country Of Origin	Mexico
Application Sector	Commercial, Industrial	Standard	TIA-568.2-D, 802.3bt Type 3 and Type 4, FCC part 68 Subpart F, IEC-603-7 compliant, IEEE 802.3af / 802.3at, UL 1863
Warranty Type	5-Year	Type	Jack

Dimensions

Product Width US	0.73 in	Product Depth US	1.1 in
Product Height US	0.92 in		

Additional Information

RoHS Compliant	Yes	Product Environmental Profile	Yes
----------------	-----	-------------------------------	-----

Technical Information

Wire Gauge	22-24 AWG	Termination Style	110
------------	-----------	-------------------	-----

Connector Type	RJ-45	IDC Wire Gauge	22-26 AWG
----------------	-------	----------------	-----------

Impedance	100 Ohm
-----------	---------
