

FLOODLIGHTS

35 - 150W HID / 26 - 84 CFL



Future Flood



EZ Flood




EZ Flood with Visor


- Die-cast aluminum housing
- Hinged door frame for easy relamping
- Tempered glass lens
- White or bronze chip & fade resistant polyester powder coat finish
- Silicone gasket
- Lamp supplied



Built-in Glare Shield

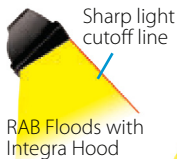


RAB Floods with Integra Hood

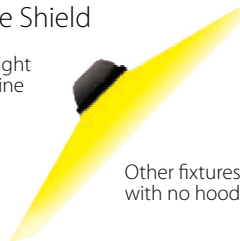

Other fixtures with no hood

Variable Beam Spread

2 position adjustable socket on FF.

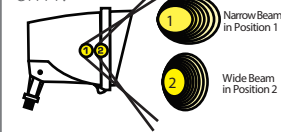

Make the Switch to

LED



Save energy
Save money

Future Flood



EPA = .4

Catalog #	White	Lamp Watts	Lamp Type	Lamp Base	Ballast	Input Watts	Lamp ANSI	Initial Lumens	Lamp Hours	Consider LED Replacement
HPS										
FF35	FF35W	35	ED17	Med	R-NPF 120V	46	S76	2,300	24,000	
FF50	FF50W	50	ED17	Med	R-NPF 120V	62	S68	4,000	24,000	FFLED18
FF70	FF70W	70	ED17	Med	R-NPF 120V	86	S62	6,300	24,000	
FF100	FF100W	100	ED17	Med	R-NPF 120V	115	S54	9,500	24,000	
FF150	FF150W	150	ED17	Med	R-NPF 120V	170	S55	16,000	24,000	FFLED39
MH										
FFH50	FFH50W	PS 50	ED17	Med	HX-NPF	72	M110	3,400	10,000	FFLED18
FFH70	FFH70W	PS 70	ED17	Med	HX-NPF	94	M98	5,600	15,000	FFLED18
CFL										
FF42QT	FF42QTW	42	Triple	Med	Electronic QT	46		3,200	12,000	FFLED18

Patents: The design of the Future Flood is protected by U.S. Patent #D420458 and similar patents pending in China, Taiwan and Canada.

EZ Flood



EPA = .6

HPS										
EZSH35	EZSH35W	35	ED17	Med	R-HPF 120V	46		2,300	24,000	
EZSH50	EZSH50W	50	ED17	Med	R-HPF 120V	62		4,000	24,000	
EZSH70	EZSH70W	70	ED17	Med	R-HPF 120V	86	S76	6,300	24,000	FFLED18
EZSH70QT	EZSH70QTW	70	ED17	Med	HX-HPF QT	91	S68	6,300	24,000	
EZSH100	EZSH100W	100	ED17	Med	R-HPF 120V	115	S62	9,500	24,000	
EZSH100QT	EZSH100QTW	100	ED17	Med	HX-HPF QT	130	S62	9,500	24,000	
EZSH150	EZSH150W	150	ED17	Med	R-HPF 120V	170	S54	16,000	24,000	FFLED39
EZSH150QT	EZSH150QTW	150	ED17	Med	HX-HPF QT	188	S54	16,000	24,000	
MH										
EZHH50QT	EZHH50QTW	50	ED17	Med	HX-HPF QT	72	S55	3,400	10,000	
EZHH70QT	EZHH70QTW	PS 70	ED17	Med	HX-HPF QT	90	S55	5,600	15,000	FFLED18
EZHH100QT	EZHH100QTW	PS 100	ED17	Med	HX-HPF QT	129	M110	9,000	15,000	
EZHH125PSQ	EZHH125PSQW	PS 125	ED17	Med	CWA-HPF QT	150	M98	12,000	15,000	
EZHH150QT	EZHH150QTW	150	ED17	Med	CWA-HPF QT	185	M90	12,500	10,000	FFLED39
EZHH150PSQ	EZHH150PSQW	PS 150	ED17	Med	CWA QT	185	M150	14,000	15,000	
CFL										
EZF26QT	EZF26QTW	26	GX24q-3	Triple	Electronic QT	29	M107	1,800	12,000	
EZF32QT	EZF32QTW	32	GX24q-3	Triple	Electronic QT	36	M102	2,400	12,000	
EZF42QT	EZF42QTW	42	GX24q-4	Triple	Electronic QT	46		3,200	12,000	FFLED18
EZF84QT	EZF84QTW	84	2-42w Triple	GX24q-4	Electronic QT	93		6,400	12,000	



Patents: The design of the EZ Flood is protected by patents and patents pending in the U.S., China and Taiwan

ACCESSORIES



FF Guard (GDFF)



EZ Hood (EZH6)



EZ Guard (GDEZW)
(chrome finish)



Button Photocell
Add suffix /PC for 120V
(after Catalog #)
PC2 for 208-277V
(after Catalog #)



Swivel Photocell
Add suffix /PCS for 120V (after Catalog #)
PCS2 for 208-277V (after Catalog #)