

16 AWG

GC019



EXPAND YOUR CAPABILITIES. 12V PLUG 12-FOOT EXTENSION CABLE.

12V

DIRECT 12V POWER.

Power 12V accessories directly from battery terminals. Permanently attach eyelets to a battery for quick connections and easy access to 12V power.

15A

HIGH CONDUCTIVITY.

Made from a high-conductivity 16AWG 100-percent copper wire and a rated capacity of 15-amperes.



NOCO

30339 Diamond Parkway, #102
Glenwillow, OH 44139 | USA
1.800.456.6626

no.co

ADDITIONAL REACH.

TIRE PUMPS, VACUUMS, AND MORE.

The GC019 12-volt adapter plug socket extension cable extends the reach of your favorite 12-volt devices by an additional 12-feet. Features inline fused connection to prevent dangerous short circuits, water resistant cap to protect the 12-volt female socket from the elements, and a LED indicator to show when your 12-volt socket is active.

12FT



3.66M

20A MICRO BLADE FUSE

Built-in 20A fuse protection for increased safety. The 20A fuse provides equal protection while being 45% smaller than the previous NOCO 10A Fuse.



THE ALL NEW NOCO 20A FUSE
NEXT TO THE PREVIOUS NOCO 10A FUSE.




12V
IN



RUGGED
Water resistant cap.

12V
OUT

WHAT'S IN THE BOX

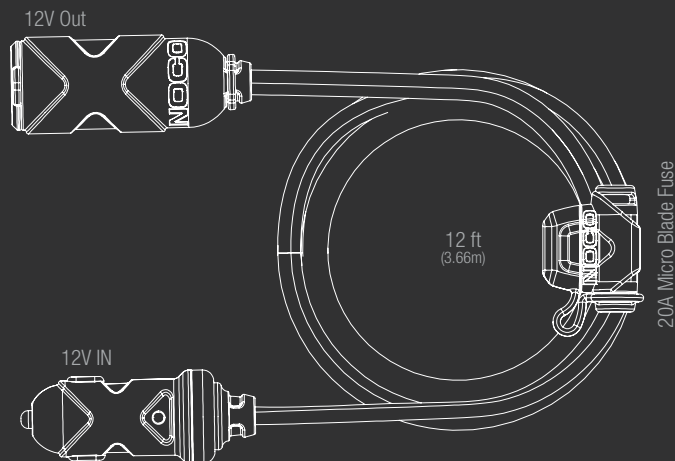

TECHNICAL SPECIFICATIONS

WIRE SIZE:	16 AWG	
INPUT:	12 Volt Male Plug Adapter	
FUSE:	20 Amp Micro Blade	
CABLE LENGTH:	12 Feet (3.66m)	
WEIGHT:	0.26 lbs (0.12kg)	
VOLUMETRICS:	Retail Packaging: Dimensions: 2.7" x 2.3" x 7.0" Weight: 0.62 lbs UPC: 0-46221-13086-7	Master Carton: Dimensions: 7.7" x 8.6 x 6.9" Weight: 4.4 lbs Quantity: 6 UCC: 20046221130861
	Inner Carton: Dimensions: 7.1" x 2.6" x 3.0" Weight: 0.64 lbs	Units Per Pallet: 960 Units

NOCO

30339 Diamond Parkway, #102
Glenwillow, OH 44139 | USA
1.800.456.6626

no.co