

SHORE

C7212-PBR/GSL

Shore takes the traditional flush mount silhouette in a new direction. The monolithic form flares subtly around a white glass diffuser, creating a soft, ambient glow. Available in two sizes with either a cream or slate gesso finish, it brings a contemporary point of view to entryways, living rooms, and hallways.

FINISHES

PATINA BRASS w/ Slate Gesso

Coastal Suitable Finish (EPM): No

DIMENSIONS

Height: 3.5"

Width/Diameter: 12"

Canopy/Backplate: 8.75"

Product Weight: 6.6lb

Canopy/Backplate Shape: Round

Sloped Ceiling Compatible: No

Living Finish: No

Uplight Only: No

Shade


Shade 1: Glass

Shade 1 Finish: White Glass

Shade 1 Top Width: 11.5"

Shade 1 Bottom L/W: 0" / 11.5"

Shade 1 Height: 0.5"

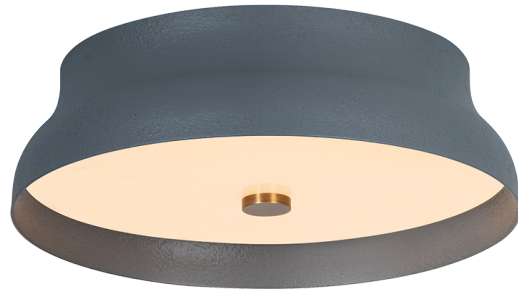

ELECTRICAL



Bulb 1

Bulb Included: N/A

Socket: Integrated LED

Max Wattage: 16

Bulb Quantity: 1

Wire Length: 7"

Cord Type: B & W TEFLON W/ GROUND WIRE

Gem Box Required (2"x3"): No

Dark Sky: No

CRI: 90

Color Temp.: 2700k

Lumens: 500

Title 24: No

Field Serviceable: Yes

SHIPPING

Carton 1: 16" x 16" x 9"

Carton 1 Weight: 10lb

Shipping Method: Ground

Country of Origin: PH