

PHILIPS

Home Access


Smart lever lock

2000 series

Philips Built-in WiFi Fingerprint Touchscreen Smart Lever Lock

DDL0M1020X-1HW

Integrated smart lever lock
Effortless access with fingerprint unlock

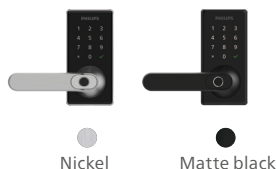

Specifications

Overview

Material	Aluminum alloy
Color	Nickel / Matte black
Bolt type	Latch bolt
Keyway	SC1
Connectivity	Built-in Wi-Fi / Bluetooth

Unlock Methods

Unlocking from outside	Fingerprint / PIN code / Home Access app / Key
Unlocking from inside	Lever
	Home Access app
	Voice assistant

Max Credentials Capacity

Fingerprint	50
Master PIN code	1
User PIN code	100
One-time PIN code	Unlimited
Traditional key	2

Modes

Operation mode	Auto mode
	Passage mode
Security mode	Privacy mode

Power

Power supply	8 AA batteries
--------------	----------------

Operating Environment

Temperature	From -35 °C to 66 °C
Humidity	0-93%

Installation Requirements

Door thickness	1-3/8 to 2 inch (35-50mm)
Opening direction	Left inside / Left outside
	Right inside / Right outside
Cross bore hole	2-1/8 inch (54mm)
Backset	2-3/8 or 2-3/4 inch (60mm/70mm)

Key Features

Safety	Meets ANSI/BHMA standard
	AES128
	Local storage
Alarms	Low battery alarm
	Wrong entry limit alarm
	Jam alarm
Remote control	App unlock
	Manage user accounts
	Create schedule PIN codes
	Simple sharing
Language	English / French / Spanish
Voice navigation	Real person voice navigation
Works with voice assistant	Amazon Alexa
	Google Assistant



Fingerprint
unlock



PIN code
unlock



Integrated
lever



Traditional
key



Remote control
through app