


# CFP

## Edge-Lit Flat Panel

The CFP offers Edge-Lit LED technology in a sleek, modern, flat panel design. Light classrooms, offices, medical facilities, cleanrooms and general public spaces using edge-to-edge illumination, without pixelation or bright spots. Switchable Lumen technology creates built-in versatility; choose between three configuration options for the right output with one easy switch.



Switchable Lumen

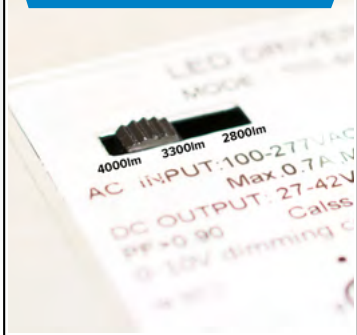

Smooth, narrow frame



1x4, 2x2, and 2x4 sizes



Emergency Backup Compatible





# CFP

An attractive, cost-effective, and reliable flat panel family.



- ▶ IC rated
  - ▶ 80+ CRI
  - ▶ 120-277V
  - ▶ -20°C to +40°C
  - ▶ 0-10V dimming
  - ▶ Cleanroom suitable
  - ▶ 5 year warranty
- ▶ T-bar clips for secure mounting
  - ▶ 60,000 hour LEDs at L70
  - ▶ DLC® (DesignLights Consortium) Qualified, with some Premium Qualified configurations - see [www.designlights.org](http://www.designlights.org)

Catalog No.	UPC	Description	Lumens	Watts	LPW	Qty on Pallet
CFP14-55/41/3435	78531140953	1x4 Edge-Lit Flat Panel, 5500/4100/3400 Switchable Lumens, 3500K	5880	50	117	28
			4837	40	121	
			3847	31	125	
CFP14-55/41/3440	78531140960	1x4 Edge-Lit Flat Panel, 5500/4100/3400 Switchable Lumens, 4000K	6084	50	122	28
			5035	40	126	
			3980	31	130	
CFP22-40/33/2835	78531140977	2x2 Edge-Lit Flat Panel, 4000/3300/2800 Switchable Lumens, 3500K	4281	40	108	56
			3338	30	113	
			2876	25	115	
CFP22-3335-HE	78531140571	2x2 Edge-Lit Flat Panel, 3300 Lumens, 3500K	3469	26	131	56
CFP22-40/33/2840	78531140984	2x2 Edge-Lit Flat Panel, 4000/3300/2800 Switchable Lumens, 4000K	5001	40	125	56
			3905	30	131	
			3382	26	133	
CFP22-3340-HE	78531140595	2x2 Edge-Lit Flat Panel, 3300 Lumens, 4000K	3502	26	134	56
CFP24-55/41/3435	78531140991	2x4 Edge-Lit Flat Panel, 5500/4100/3400 Switchable Lumens, 3500K	5024	49	102	28
			4069	39	104	
			3197	30	107	
CFP24-4135-HE	78531140632	2x4 Edge-Lit Flat Panel, 4100 Lumens, 3500K	4103	32	129	28
CFP24-55/41/3440	78531141004	2x4 Edge-Lit Flat Panel, 5500/4100/3400 Switchable Lumens, 4000K	6143	50	122	28
			5030	40	125	
			3945	31	128	
CFP24-4140-HE	78531140656	2x4 Edge-Lit Flat Panel, 4100 Lumens, 4000K	4350	32	137	28
CFP24-7535	78531140687	2x4 Edge-Lit Flat Panel, 7500 Lumens, 3500K	7364	56	132	28
CFP24-7540	78531140694	2x4 Edge-Lit Flat Panel, 7500 Lumens, 4000K	7534	56	135	28

Accessories (Order Separately)	
PLD10M	Dual-Lite® Emergency LED Battery Pack, field installed
PLRTS	Remote Test Switch/Charge Indicator Module (fits single-gang box)
FK14	1' x 4' Single Flange Kit
FK22	2' x 2' Single Flange Kit
FK24	2' x 4' Single Flange Kit
CFPSMK-14	1' x 4' CFP Surface Mount Kit
CFPSMK-22	2' x 2' CFP Surface Mount Kit
CFPSMK-24	2' x 4' CFP Surface Mount Kit
CFPCM36YSC5F-KIT	36" Cable Mount Kit for 1' or 2' wide Cable Mount fixtures, 5 Wire