

# CABLE TIES

## Cable Ties Adhesive Mounts



### FTH Series

#### SPECIFICATIONS

- Temperature Rating: -80 °C to 538 °C (-112 °F to 1000.4 °F).

#### FEATURES

- Mounts are used to route and fasten cable-tied bundles to flat surfaces.
- Cable ties may be inserted from any of four directions, eliminating orientation time.
- The top of the mount has a cradle design which allows the bundle to fit snugly and a mounting hole for additional support, where required.

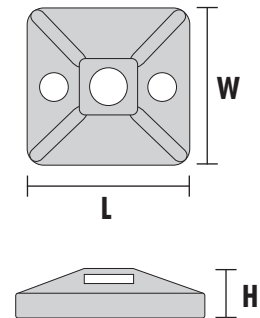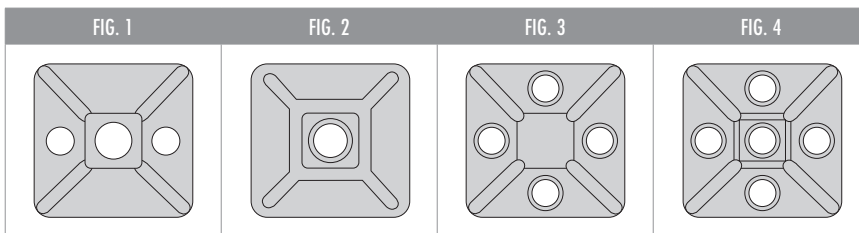

| CAT. NO. | FIG. NO. | COLOR   | SLOT WIDTH | LENGTH (IN.) | WIDTH (IN.) | HEIGHT |
|----------|----------|---------|------------|--------------|-------------|--------|
| FTH5A    | 1        | Natural | 0.140      | 0.750        | 0.750       | 0.140  |
| FTH5A-B  | 1        | Black   | 0.140      | 0.750        | 0.750       | 0.140  |
| FTH7A    | 2        | Natural | 0.203      | 1.000        | 1.000       | 0.160  |
| FTH7A-B  | 2        | Black   | 0.203      | 1.000        | 1.000       | 0.160  |
| FTH15A   | 3        | Natural | 0.394      | 1.500        | 1.500       | 0.300  |
| FTH15A-B | 3        | Black   | 0.394      | 1.500        | 1.500       | 0.300  |
| FTH20A   | 4        | Natural | 0.500      | 2.000        | 2.000       | 0.500  |
| FTH20A-B | 4        | Black   | 0.500      | 2.000        | 2.000       | 0.500  |