

# AUTOMATIC FOOT OPERATED IMPULSE SEALER

KS-FS SERIES

sealersales



Easy to operate - no warm up time

- Ideal for high volume sealing
- Plug-in digital timer for various material thicknesses
- Dual mode: auto or manual
- Foot switch allows for hands free operation
- Seal length: 18" (450mm), 24" (600mm), 32" (800mm)
- Seal width: 5mm

Video Demo →



## KS-FS Series Automatic Foot Sealers: High-Speed, Hands-Free Sealing for Demanding Workflows

Boost your packaging efficiency with the **KS-FS Series—our automatic foot impulse sealers** designed for high-volume poly bag and thermoplastic sealing. With hands-free operation and precise electronic controls, you get faster, more accurate seals every time.

These sealers feature impulse sealing technology controlled by an internal circuit board and a digital timer display for quick, accurate settings. Once programmed, the KS-FS delivers consistent, reliable seals automatically—no adjustments needed between cycles.

Fine tune your sealing process by adjusting heat (seal), cool (congeal), and auto-recycle times to match your material thickness. Prefer manual control? A foot switch is included. Every unit ships with a manufacturer's replacement kit (2 heating elements + 1 upper barrier cloth) and a durable work table—everything you need to hit the ground sealing.


SPECIFICATIONS	KS-FS455	KS-FS605	KS-FS805
SEALING LENGTH	17.7"	23.6"	31.5"
SEAL WIDTH	5MM	5MM	5MM
POWER	110V / 1050W	110V / 1300W	110V / 1500W
DIMENSIONS	22" X 21" X 35"	28" X 22" X 35"	32" X 24" X 35"
WEIGHT (NET /GROSS)	75-LBS / 118-LBS	83-LBS / 130-LBS	88-LBS / 136-LBS



Seal Width  
5mm (1/4")



Adjustable Timer

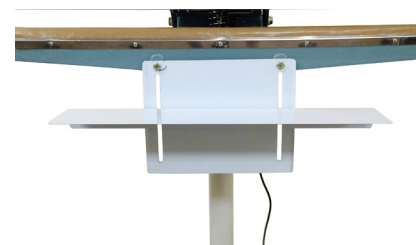

Work Table