



DO NOT RETURN TO RETAILER

IF YOU HAVE ANY QUESTIONS OR CONCERNS
PLEASE VISIT OUR WEBSITE AT:

www.sunjoyonline.com

OR TOLL FREE AT:

1-866-578-6569

8:00 AM EST to 8:00 PM PST

SUNJOY GROUP INTERNATIONAL PTE LTD

619 Slack Street
Steubenville, Ohio 43952 USA


ASSEMBLY INSTRUCTIONS

ITEM# A102007203

SKU# 283308

THIS UNIT IS HEAVY!

**GAZEBO KINGSTON 11FT. X 11FT.
CEDAR FRAME HARDTOP /POLY**

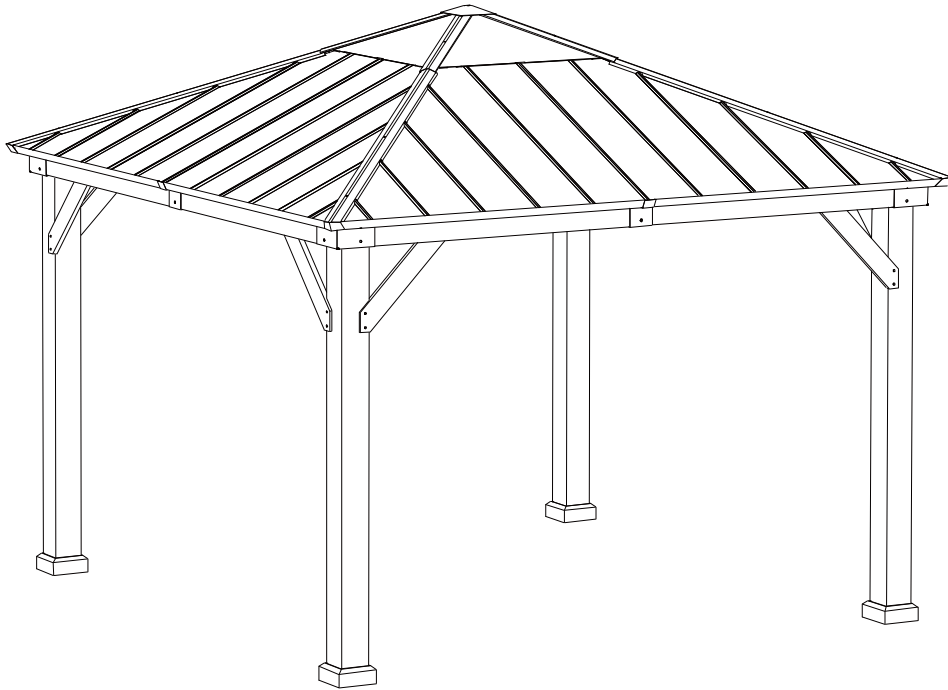

WARNING:

1. **This unit is heavy.** Do not assemble this item alone. 4 or more people are recommended for safe assembly.
2. Assembly Instructions must be followed.
3. Gazebo must be secured / anchored when fully assembled.

WARNING:

In order to reduce the risk of personal injury and damage to equipment, basic safety precautions should always be followed when assembling and using this product. Read all instructions carefully before assembly and use.

All you will need is a screwdriver, a hammer and two ladders of at least 8 feet (2.5 m) high (not included).

NOTE: DO NOT ASSEMBLE THIS ITEM ALONE FOR SAFETY.

IMPORTANT:


1. Keep all children and pets away from assembly area. Children and pets should be supervised when they are in the area of gazebo construction.
2. The area for assembly should not be less than 6 feet from any obstruction such as fence, garage, house, overhanging branches, laundry line or electrical wires.
3. Some parts may contain sharp edges. Wear protective gloves if necessary during assembly.
4. When assembling and using this product, basic safety precautions should always be followed to reduce the risk of personal injury and damage to equipment. Please read all instructions before assembly and use.

5. For outdoor use only. Install on level ground. Stakes are provided to secure the gazebo in grass ground. If you wish to secure the gazebo to a wood deck or concrete surface, you will need to purchase fasteners appropriate for these surfaces. These are readily available at your local hardware store or home center.
6. Check all bolts for tightness before and during usage.
7. Please check your state and local regulations prior to purchasing. Some jurisdictions may require permits for, or otherwise regulate, installation and use.
8. In areas subject to frequent severe weather, securing the gazebo to a deck, concrete patio or footings is recommended.
9. Removal of accumulated snow on the gazebo roof with a roof rake is recommended. In areas that are regularly subject to blizzard conditions however, removal of the roof panel is suggested. The assembled roof structure can simply be left in tact until warmer conditions return.
10. Never barbecue under this item or use lanterns that contain open flames.
11. Center hook's maximum weight capacity is 25 lbs.








CARE AND MAINTENANCE:







1. This item is intended for decorative and sunshade purposes only, and is not designed to withstand severe weather, including high winds, sustained tropical downpours, and snow. Disassemble the item in the reverse order of the assembly steps if necessary prior to a severe storm.
2. Do not use bleach, acid, or other abrasive cleaners on the roof or frame parts.
3. Steel components of garden accessories and furniture are treated with rust inhibiting paint. However, due to the nature of steel, surface oxidation (rusting) will occur if this protective coating is scratched. This is a natural process. To minimize this condition, it is recommended that care be taken when assembling and handling the product, in order to prevent the paint from being scratched.
4. Surface rust can be removed easily using a very light application of common cooking oil. If surface oxidation (rusting) occurs and no measures are taken to correct it, the oxidation may start dripping onto the assembly surface, which may cause damaging stains that may be difficult to remove.

Item Identification: For ease of identification, all parts are labeled to correspond to the Step number in which the part is used.












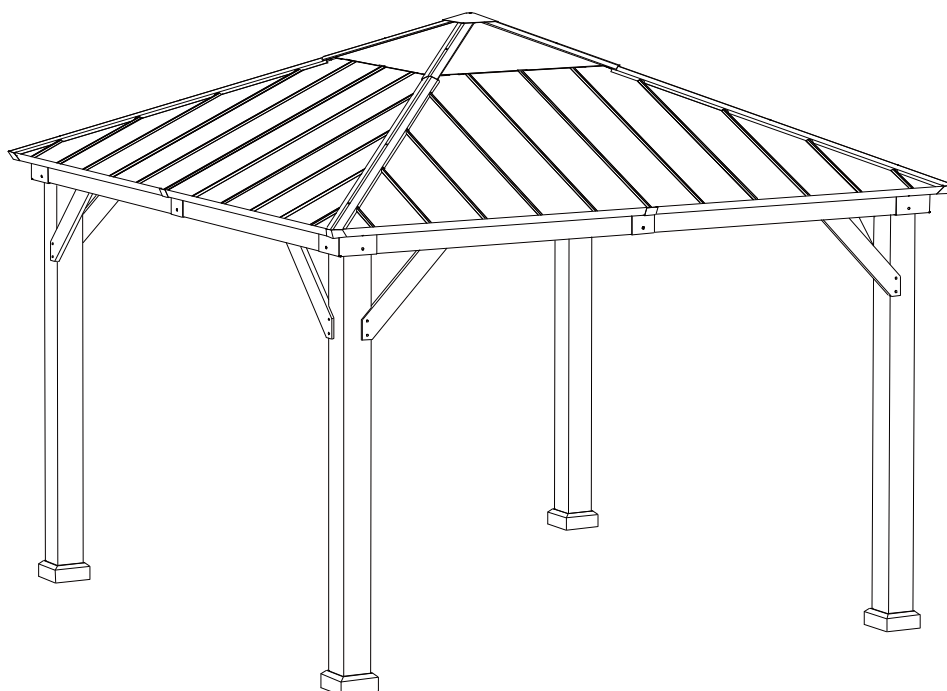


Parts List

       Description	Part NO.	QTY	CS NO.	Image
Post	08	4	P000200227	
Arc Support 1	10	4	P005000200	
Arc Support 2	11	4	P005000201	
Outer Left Beam	03	4	P000400508	
Outer Right Beam	04	4	P000400509	
Inner Long Beam	05	4	P000400510	
Inner Short Beam (Short Side)	06	4	P000400512	
Inner Short Beam (Long Side)	21	4	P000400960	
Base Cover	A	4	P00610021602	
Base	B	4	P00010025802	
Decorative (Middle)	C	4	P00560042801	
Middle Beam Connector	D	4	P00050025102	
Decorative (Conner)	E	4	P00560042901	
Slanting Beam Connector	F	4	P00050024802	
Big Roof Short Connector Tube	J	4	P00050157401	
Big Roof Sloping Beam	K	4	P00060197102	
Big Roof Middle Beam	L	4	P00060198302	
Left Mosquito Netting Rod	AF	4	P00570034502	
Right Mosquito Netting Rod	AG	4	P00570034602	
Small Roof Oblique Beam (Short Side)	N	4	P00060105901	
Small Roof Connector	AU	1	P00050156501	
Small Roof Top Beam(Short Side)	Q	4	P00060196201	

 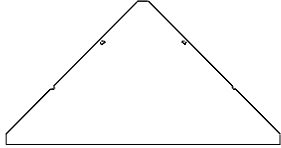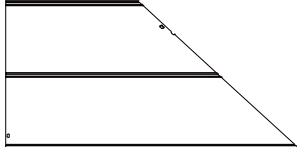
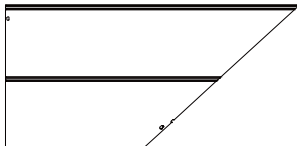
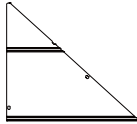
 
Description	Part NO.	QTY	CS NO.	Image
Hook	R	1	P005800001	
Small Roof Panel	S	4	P00070094501	
Small Roof Inclined Beam Cover	U	4	P00080019101	
Top Cover	AV	1	P00090015401	
Big Roof Top Beam(Upper)	W	8	P00060198902	
Big Roof Top Beam(Middle)	Y	8	P00060199902	
Big Roof Panel Flashing (Short Side) 1	AB	4	P00060201202	
Big Roof Panel Flashing (Short Side) 2	AC	4	P00060201603	
Big Roof Big Left Panel	AM	4	P00070102102	
Big Roof Big Right Panel	AN	4	P00070102602	
Big Roof Middle Left Small Panel	AP	4	P00070101402	
Big Roof Middle Right Small Panel	AQ	4	P00070101602	
Big Roof Left Small Panel	AR	4	P00070101002	
Big Roof Right Small Panel	AS	4	P00070101202	
Big Roof Inclined Beam Cover	AT	4	P00080034403	

            Hardware Pack 1


Part NO.	Description	QTY	Add	CS NO.	Image
H1	Bolt M6*20	172	9	H100010047	
H2	Bolt M6*35	5	1	H100010069	
H3	Bolt M6*45	8	1	H100010059	
H4	Bolt M10*205	8	1	H010010449	
H5	Bolt M8*25	24	2	H100010054	
H6	Bolt M8*35	16	1	H100010055	
H7	Screw M5*30	64	4	H030050058	
H8	Screw M5*40	56	3	H030050057	
H9	Bolt M8*35	16	1	H030030010	
H10	Screw M10*80	8	1	H030010031	
H11	Flat Washer M8	16	1	H050080007	
H12	Flat Washer M10	24	2	H050080008	
H13	Non-slip Nuts M10	8	1	H040050026	
H14	T-Nut M8*8	24	2	H040090004	
H15	T-Nut M8*20	16	1	H040090005	
H16	M3 Drill	2	0	H090990002	
HS	Stake Φ8*180	8	0	H070010003	
HW1	M6 Wrench	2	0	H090010017	
HW2	Allen Key M8	1	0	H090030005	
HW3	M10 Wrench	2	0	H090010015	

HELPFUL HINTS


- Tools needed and not included
- Estimate assemble time: 120~150 Minutes

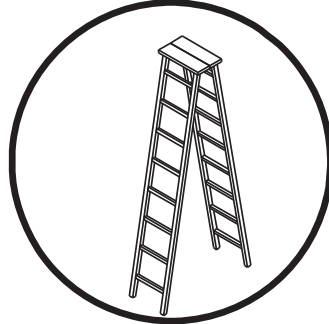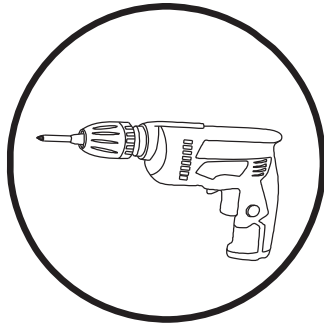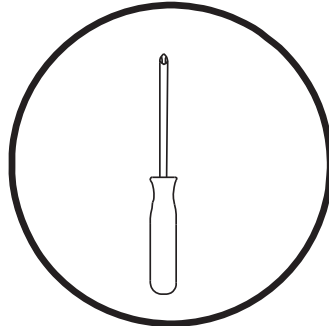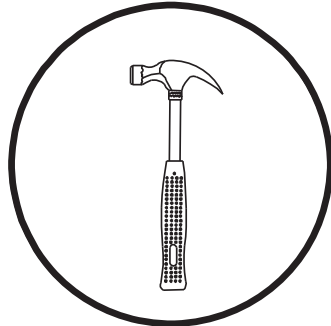

- Hand tighten all bolts using only tools Provided
- Overtightening bolts by hand or with power tools may damage product

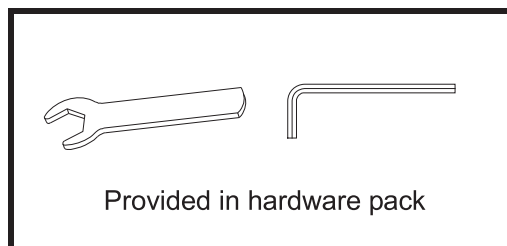


5 people needed for the installation work


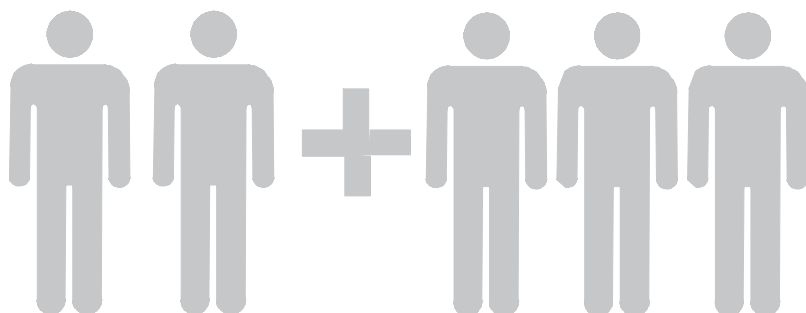


ASSEMBLY INSTRUCTIONS:








Step 1

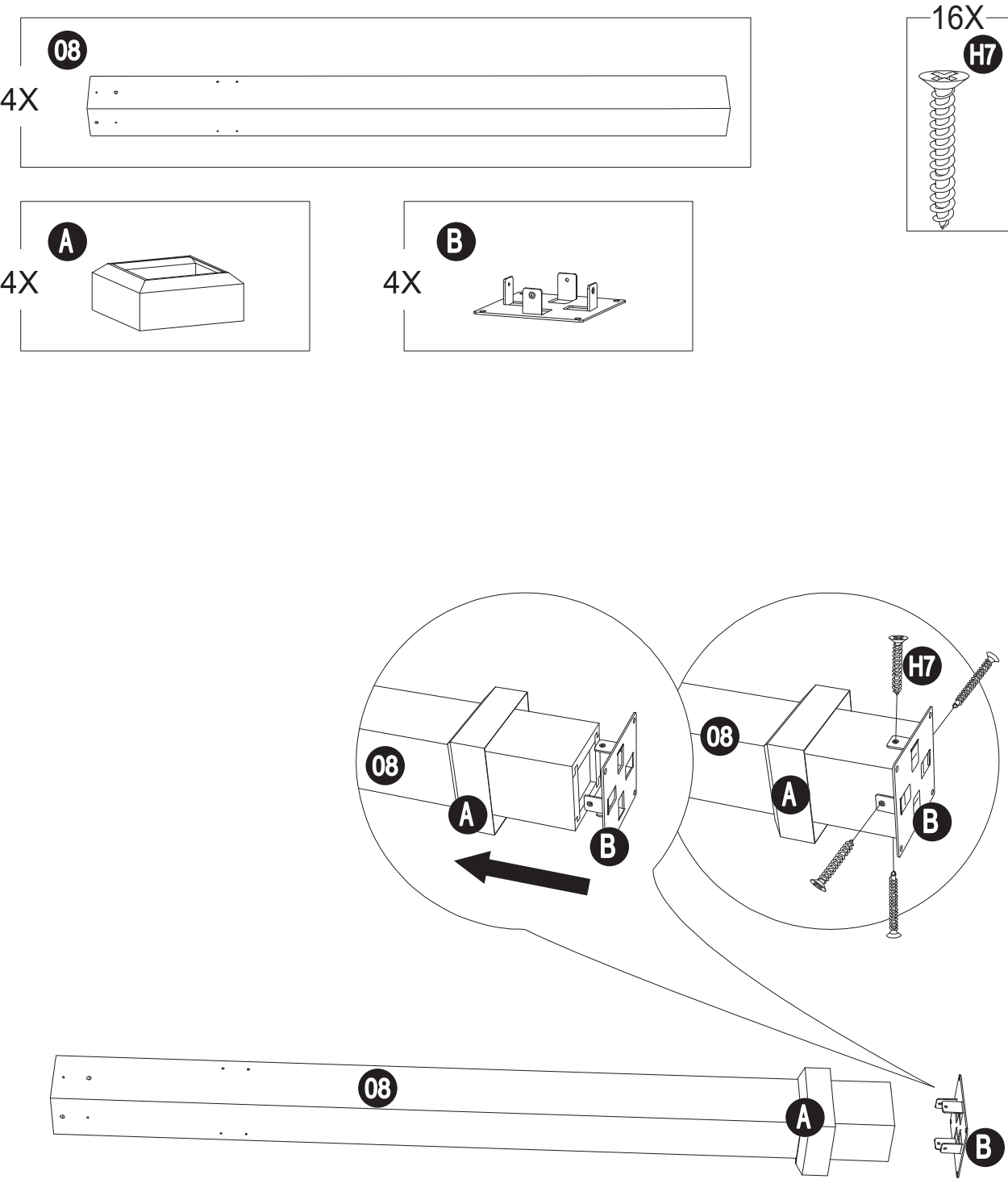


Step 2

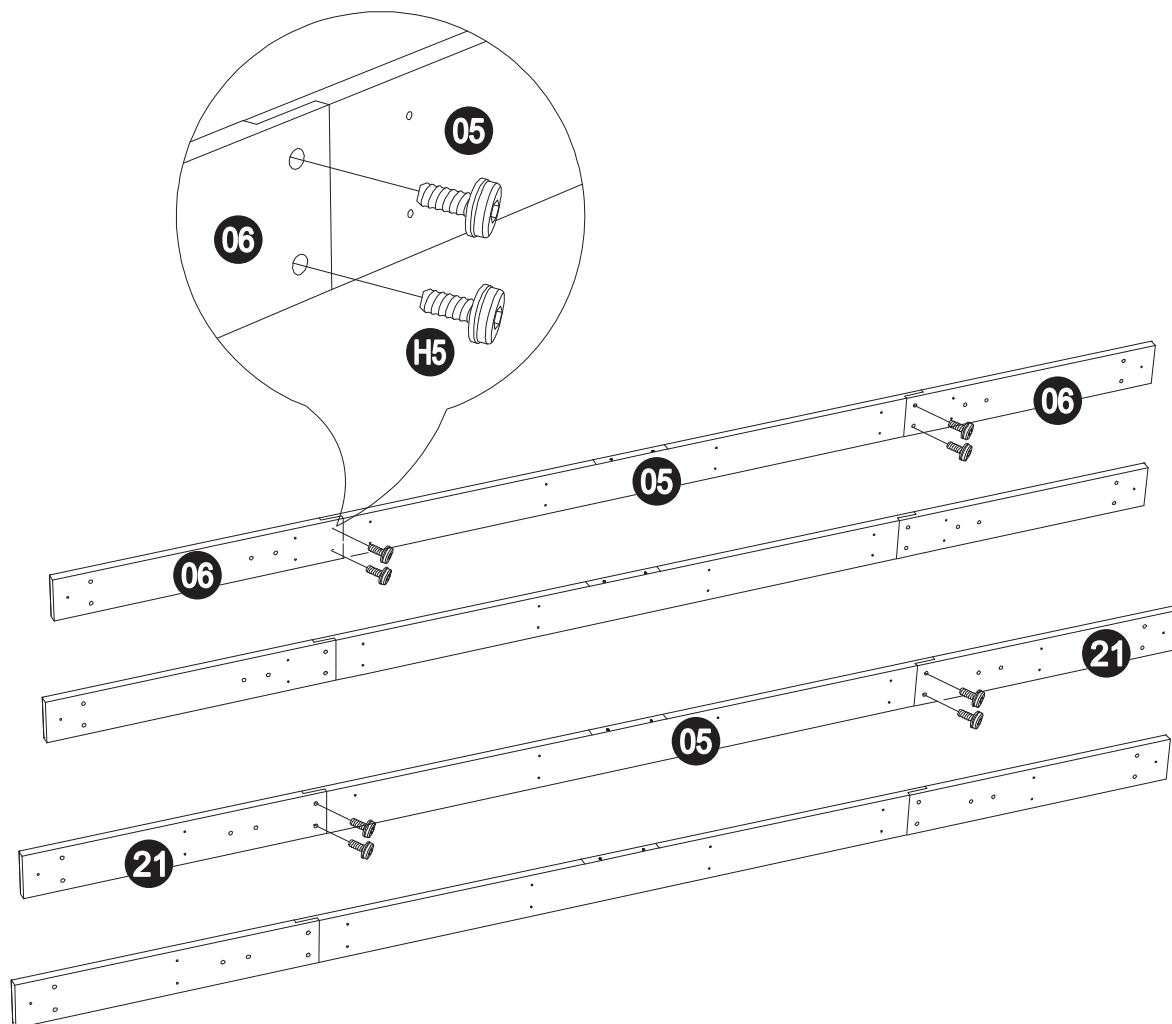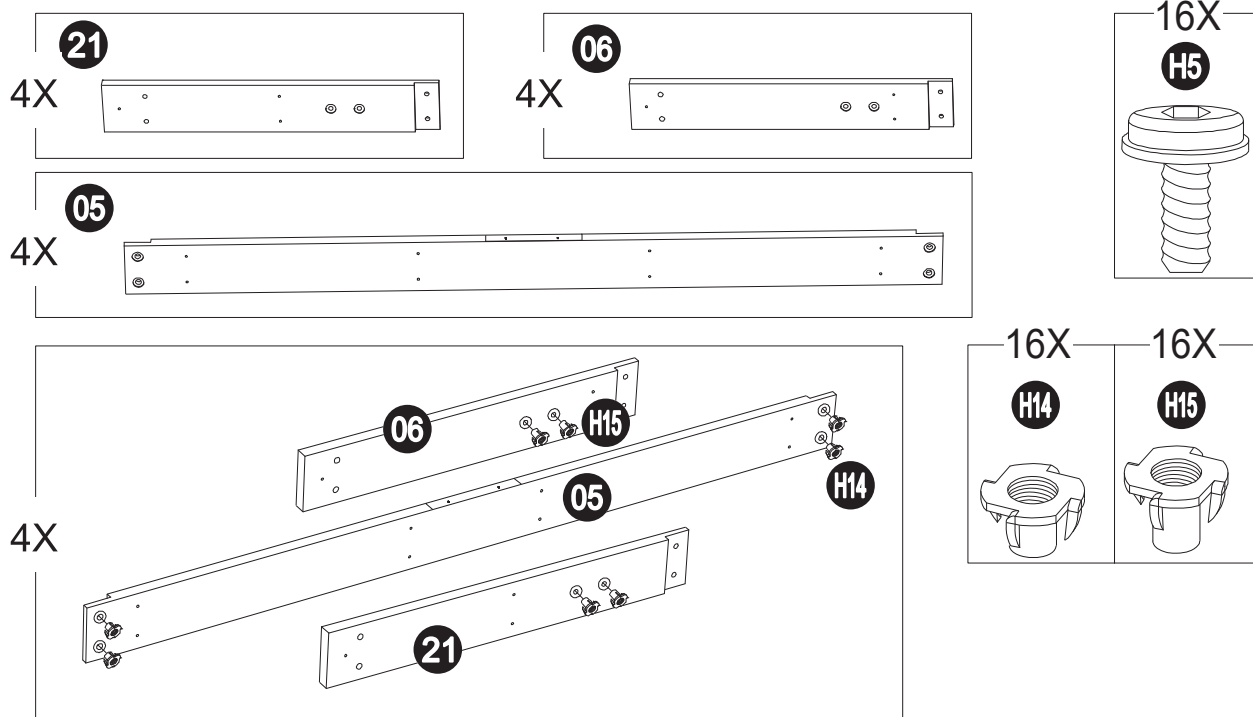





Step 3

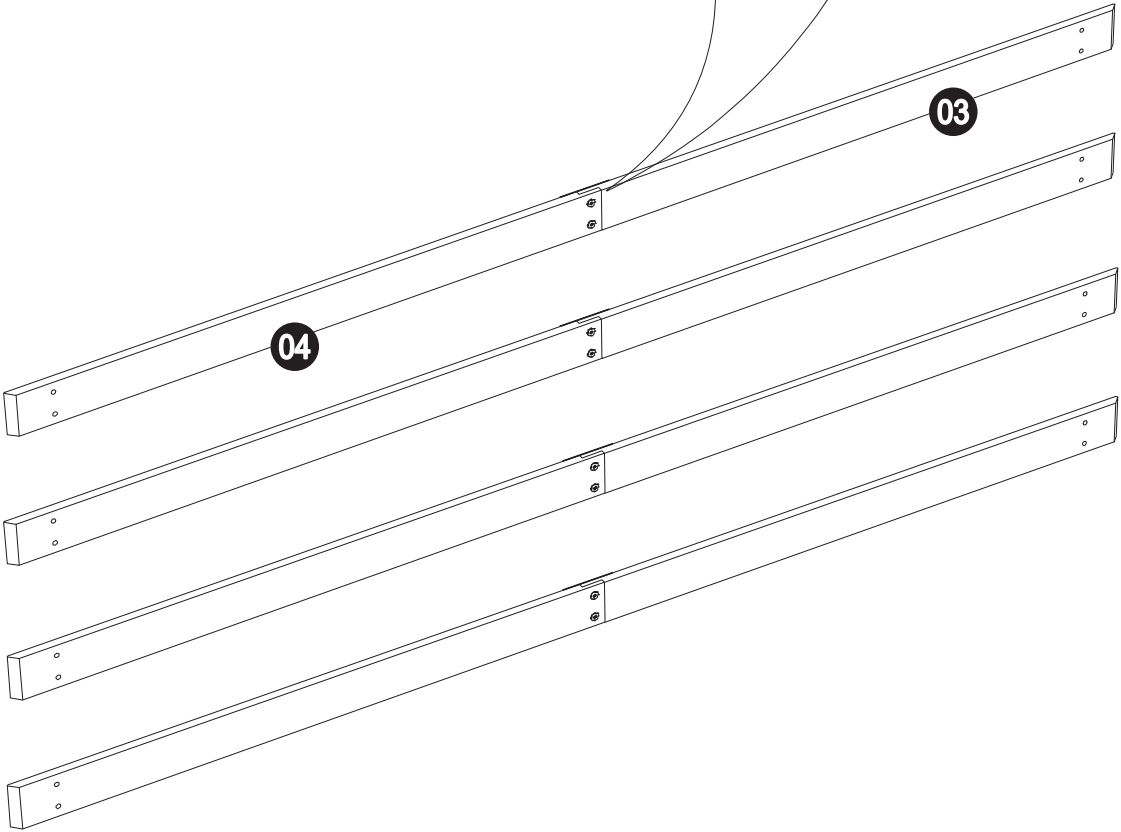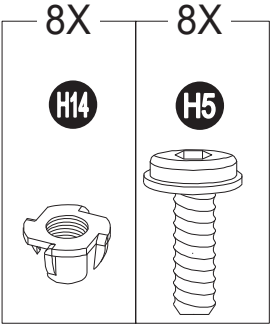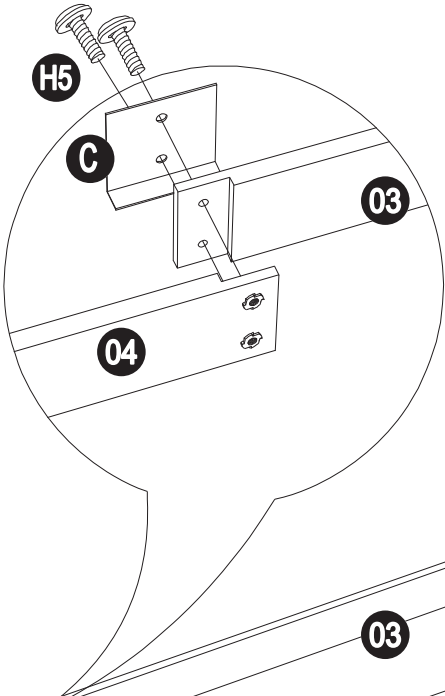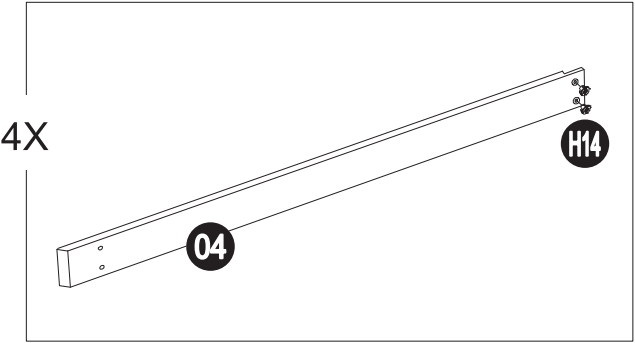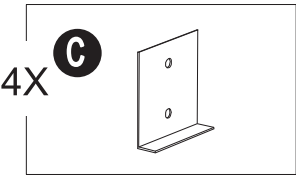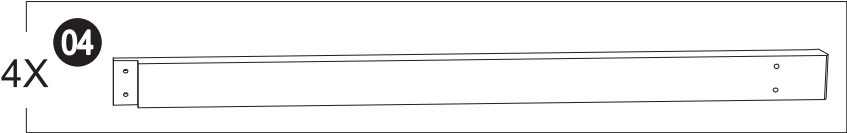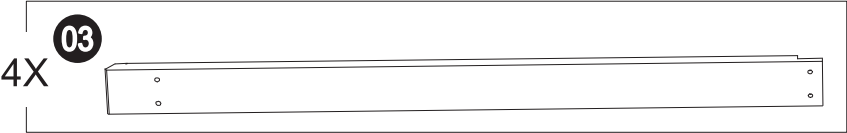




Step 4

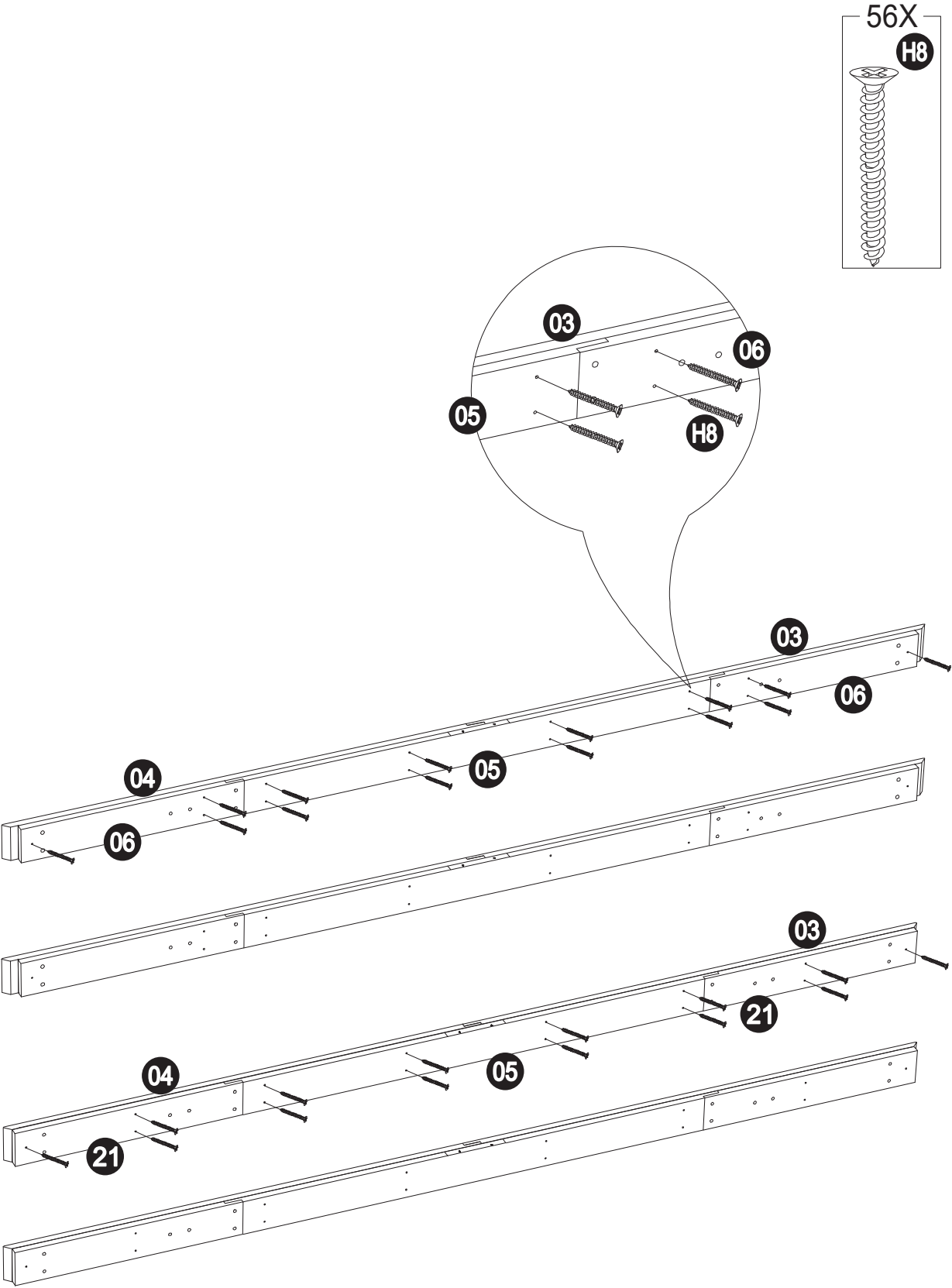




Step 5

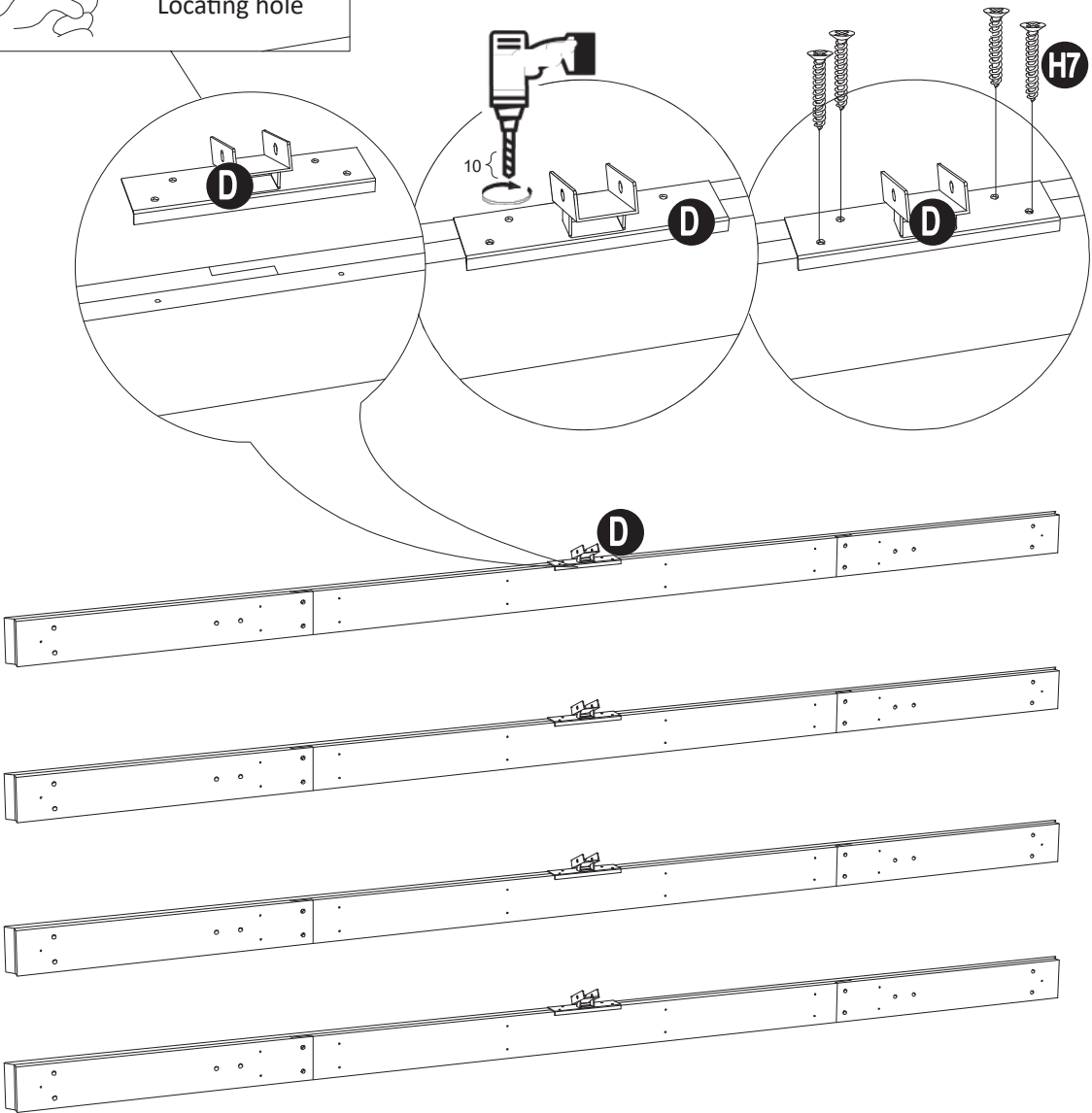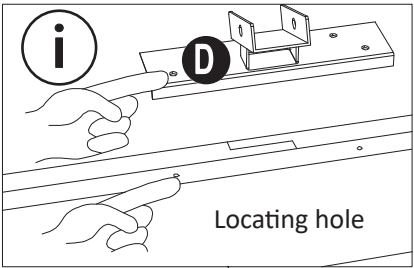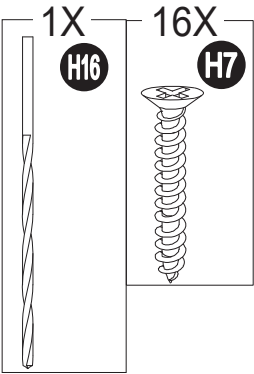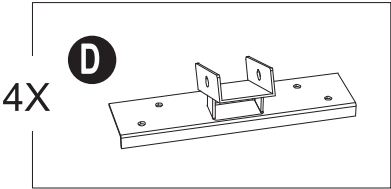





Step 6

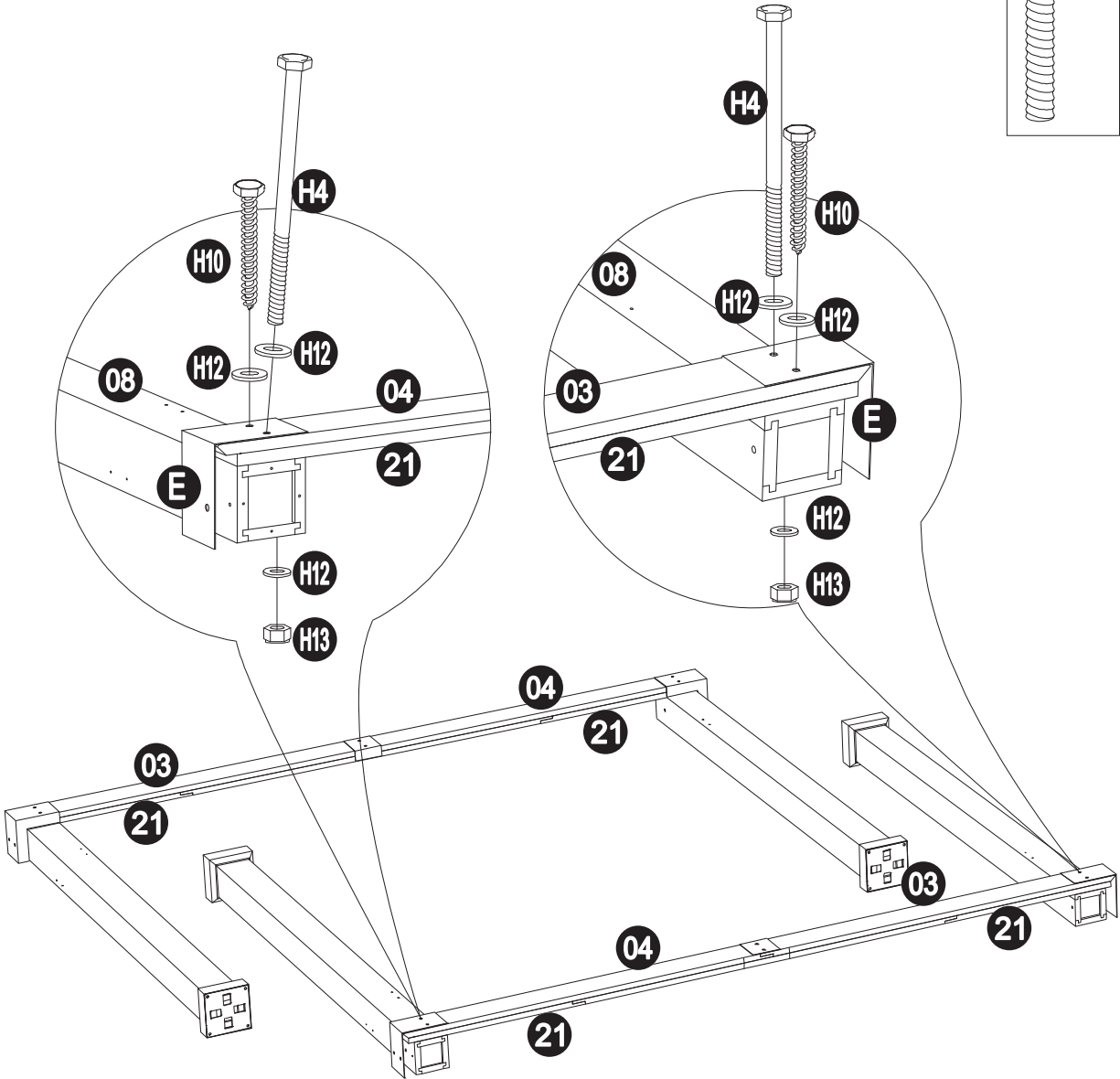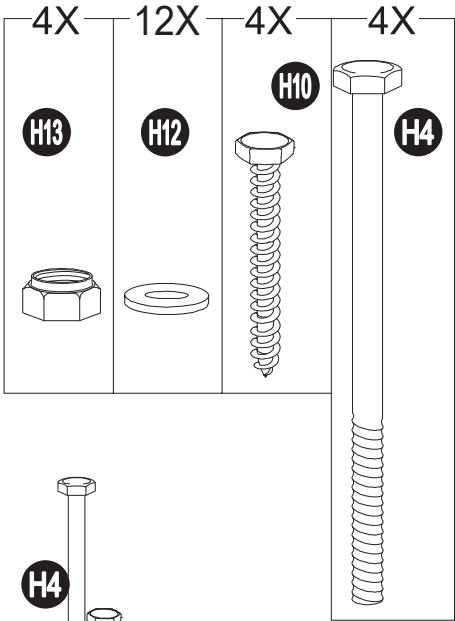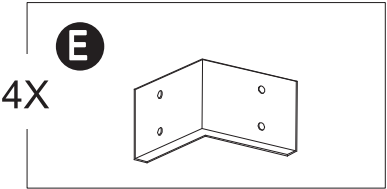

Step 7

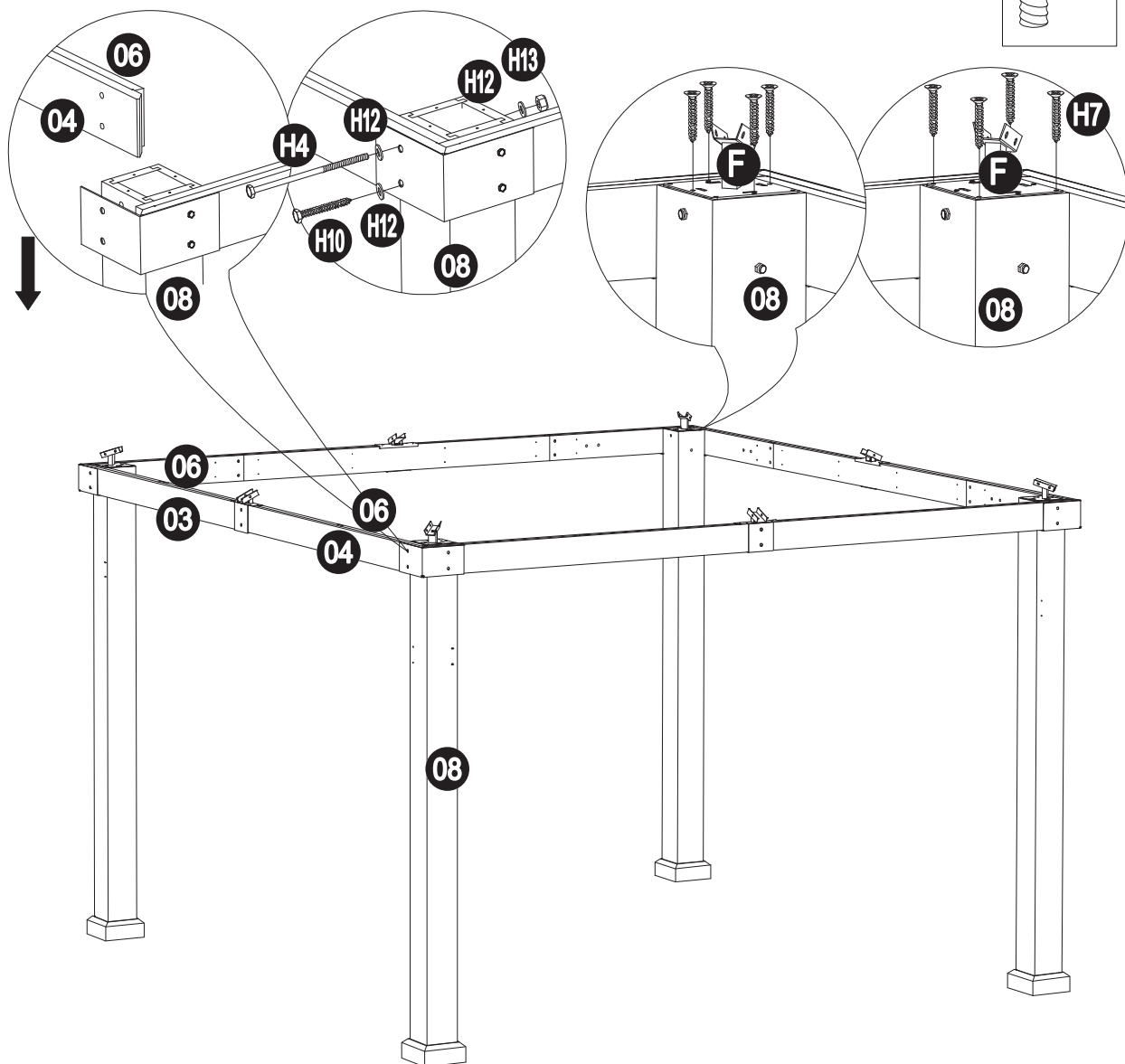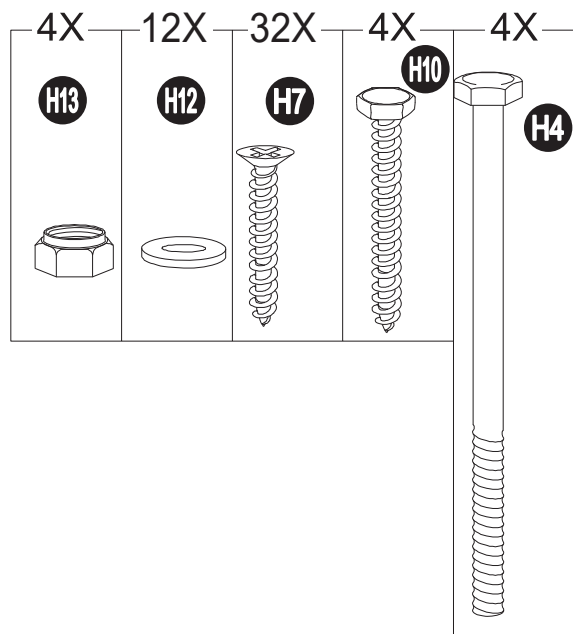
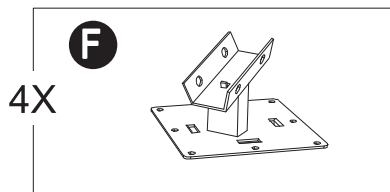


Step 8

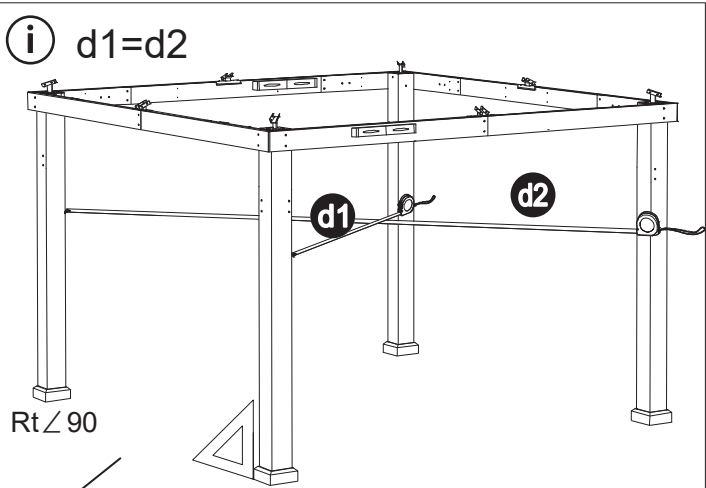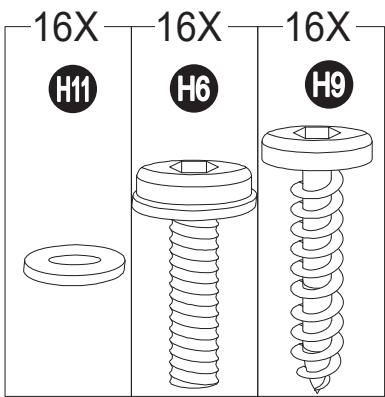
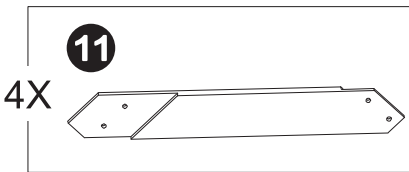
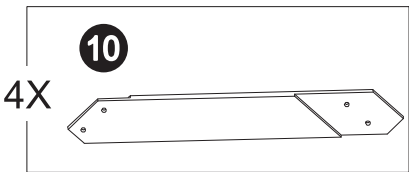


Assembly Tip on Step 8:




Please measure to make sure the length of d1 is equal to d2 before moving to next step to ensure a square frame and best results. Keep the beam at right angles to the post, the post at right angles to the ground, and keep the beam horizontal.

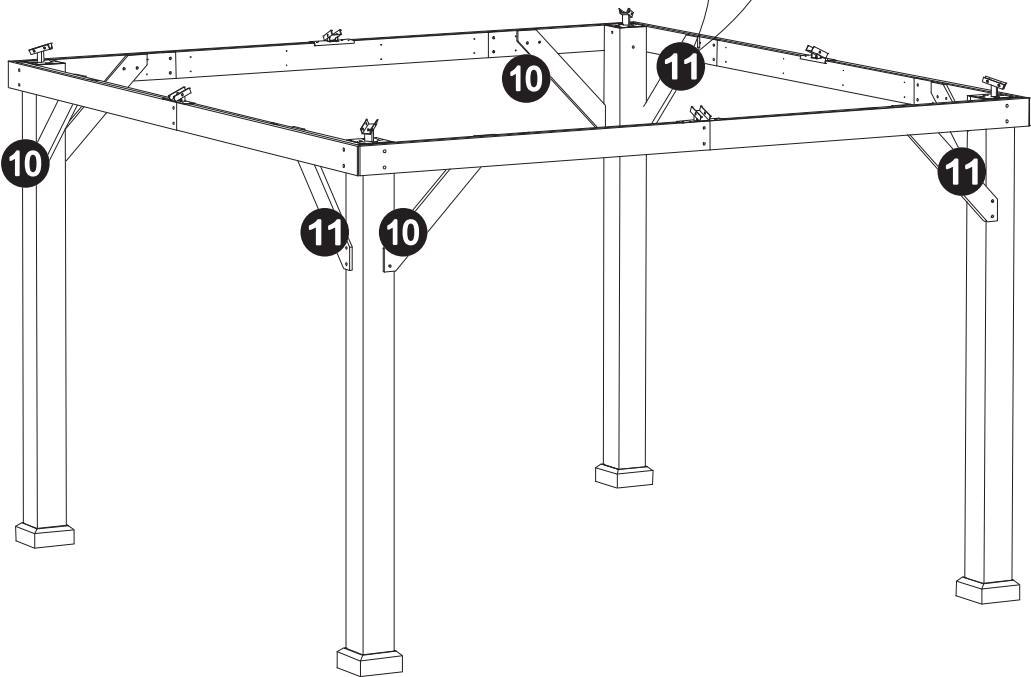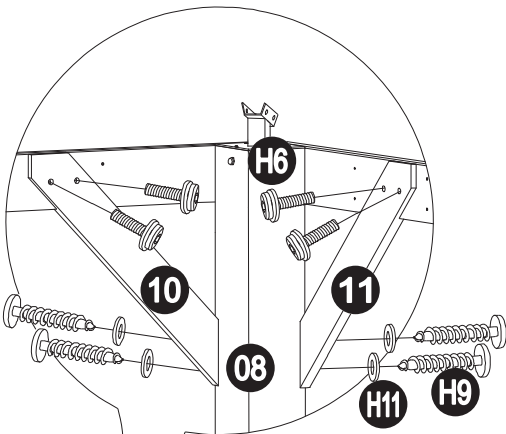




Step 9

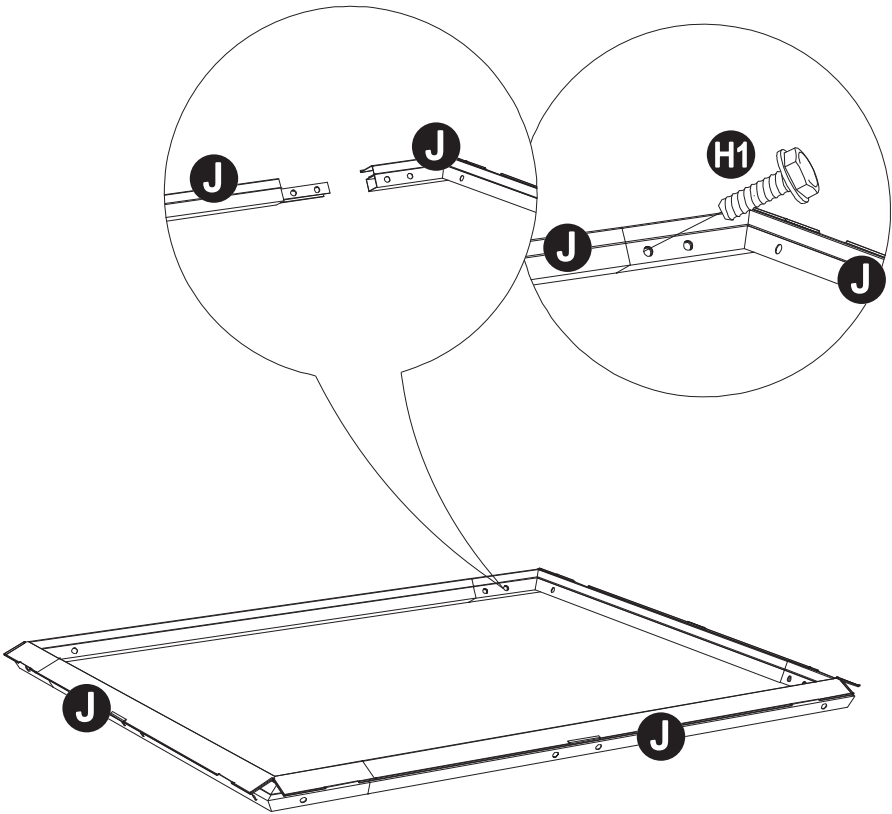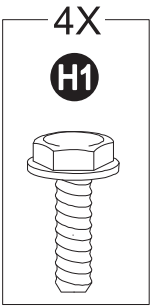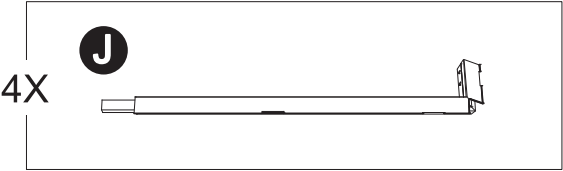




Step 10

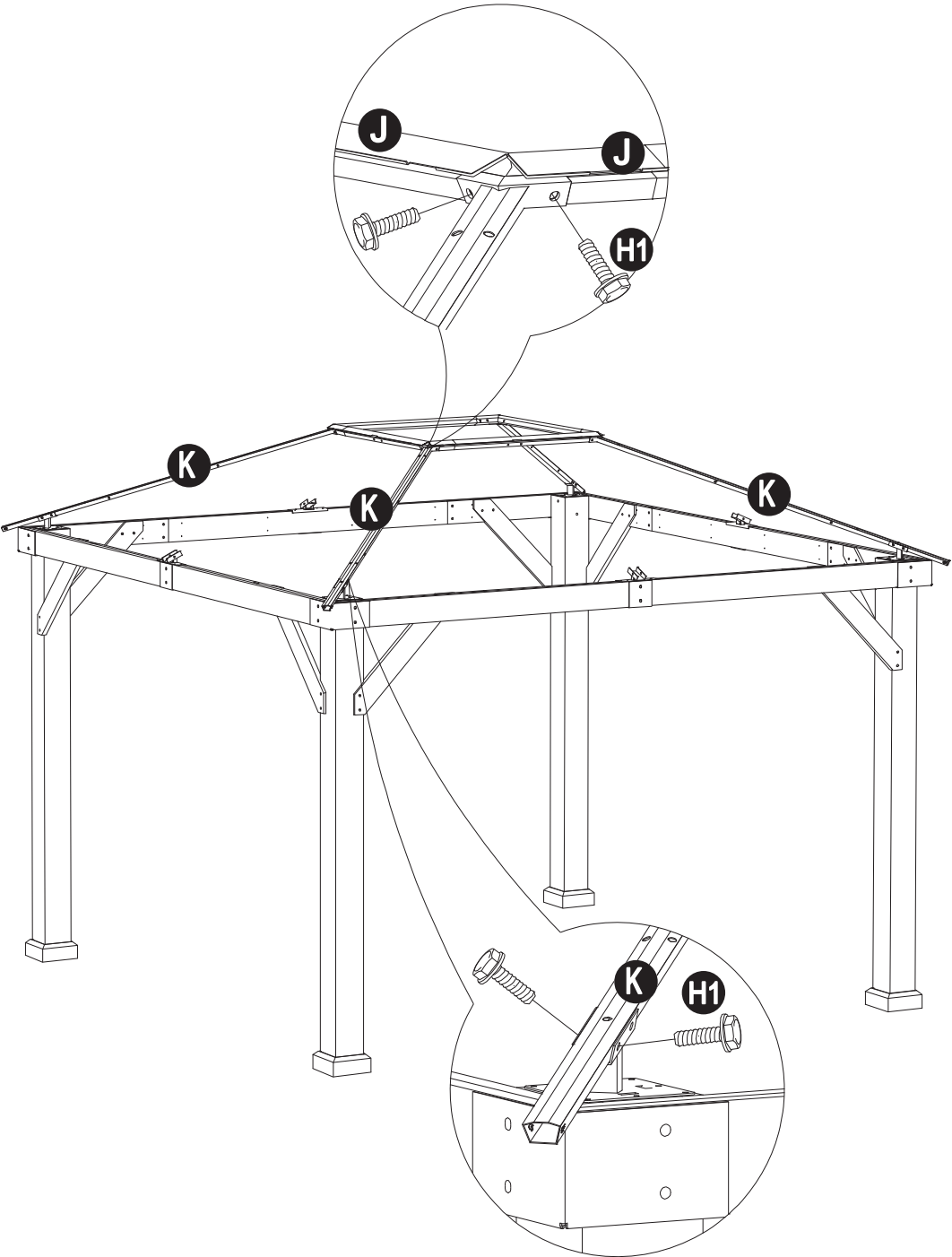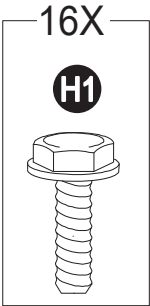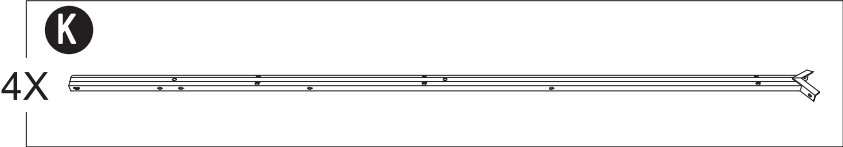







Step 11

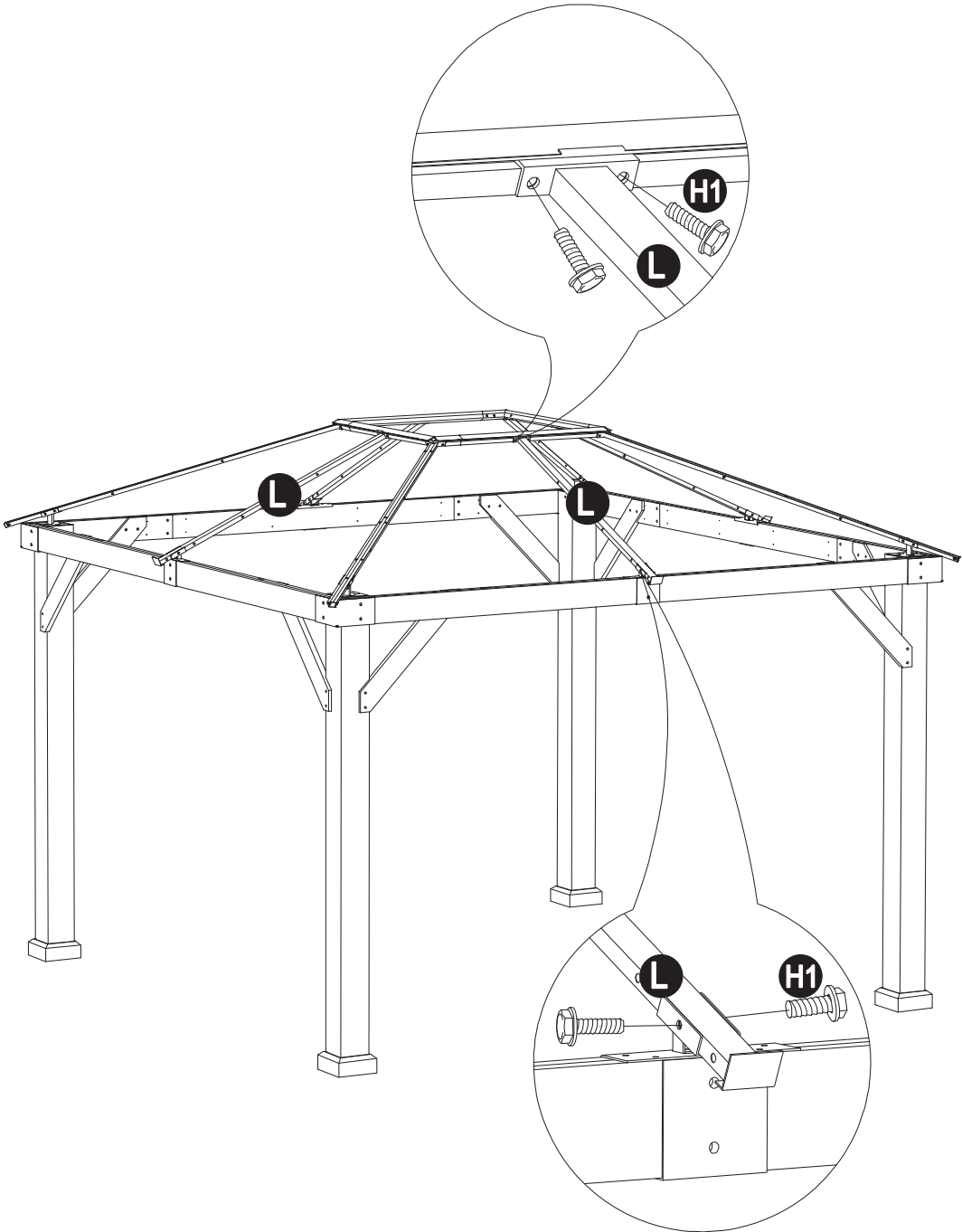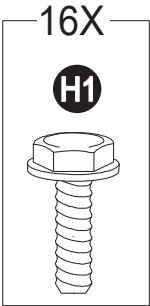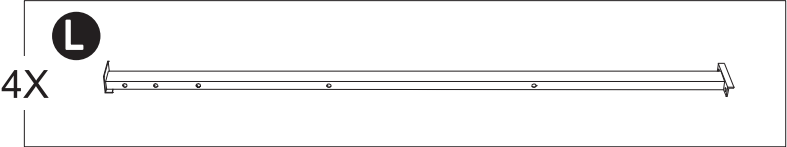



Step 12

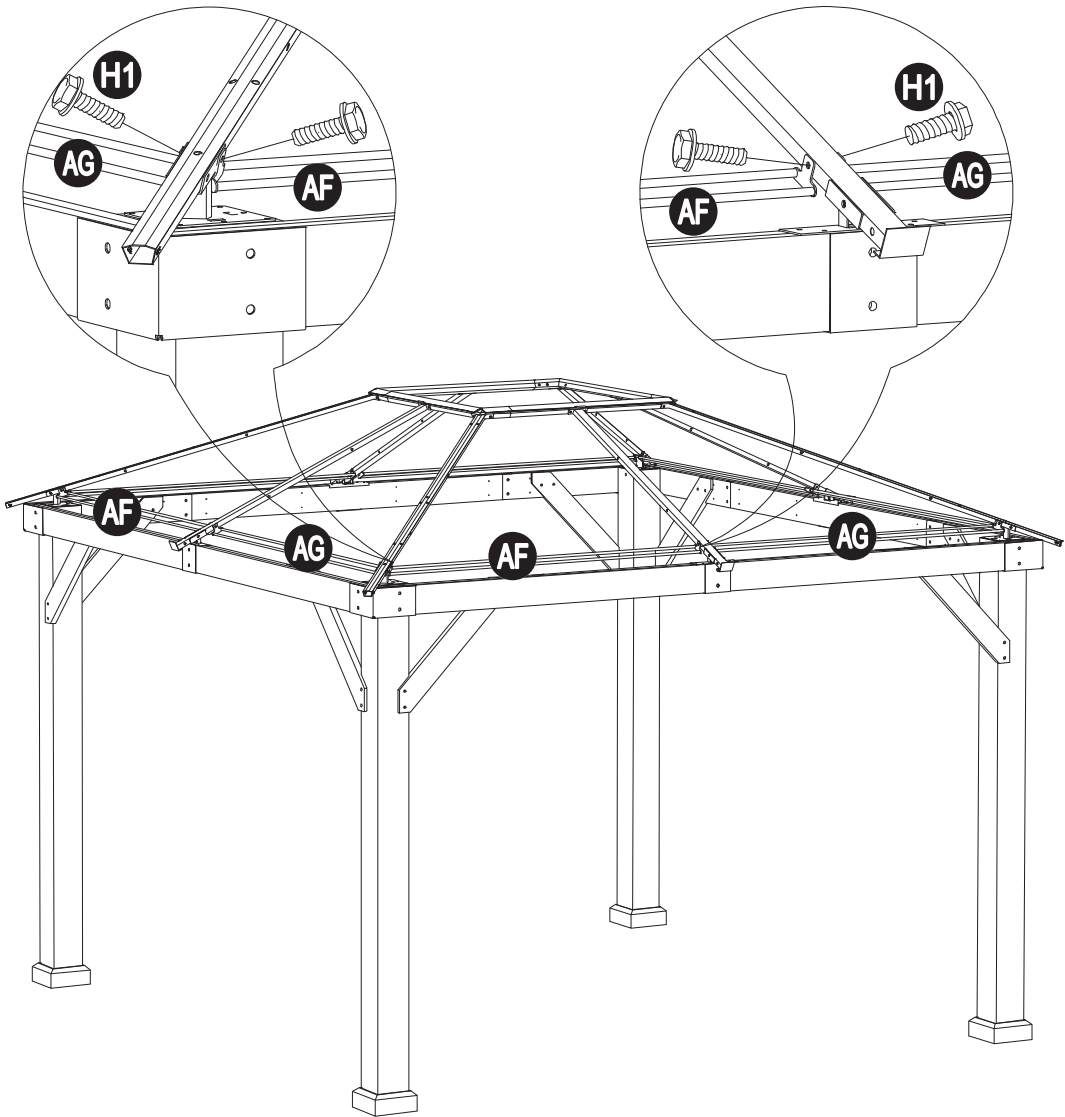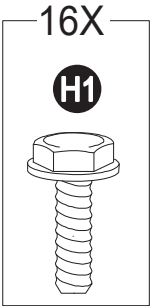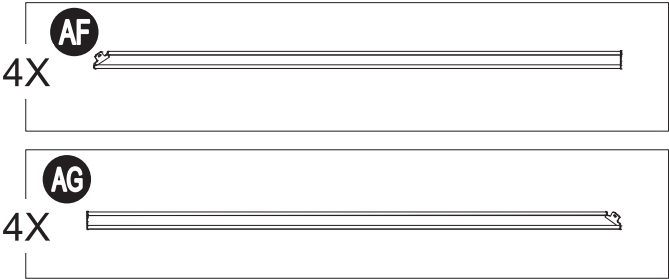




Step 13

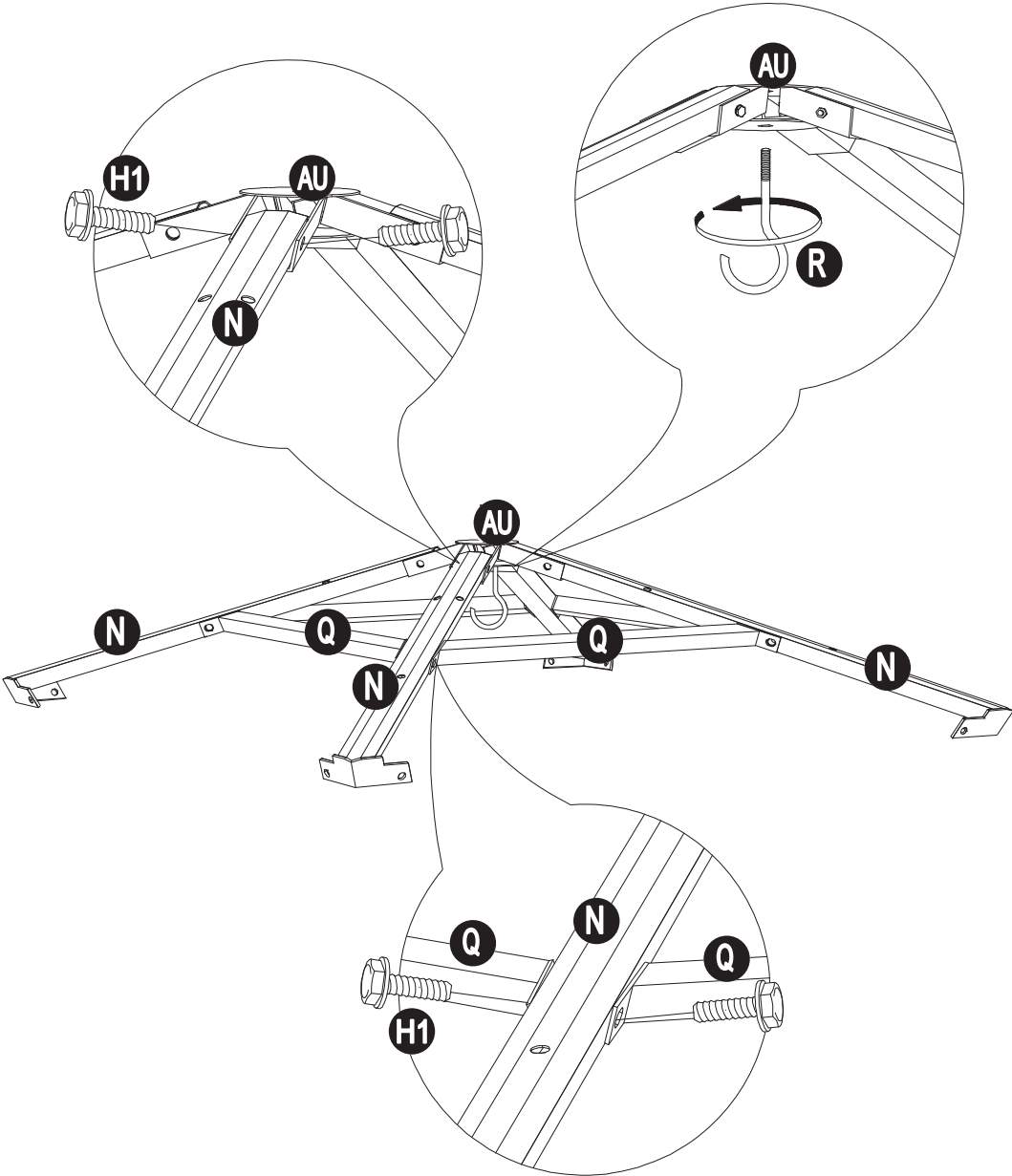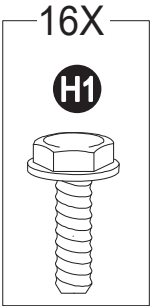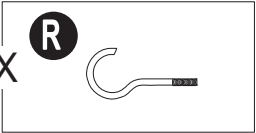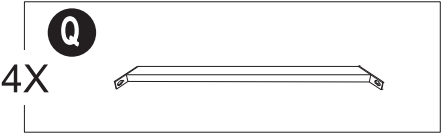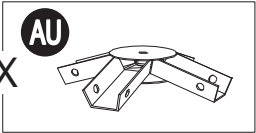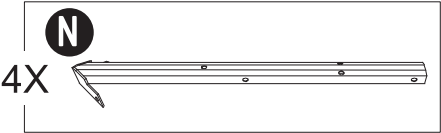





Step 14

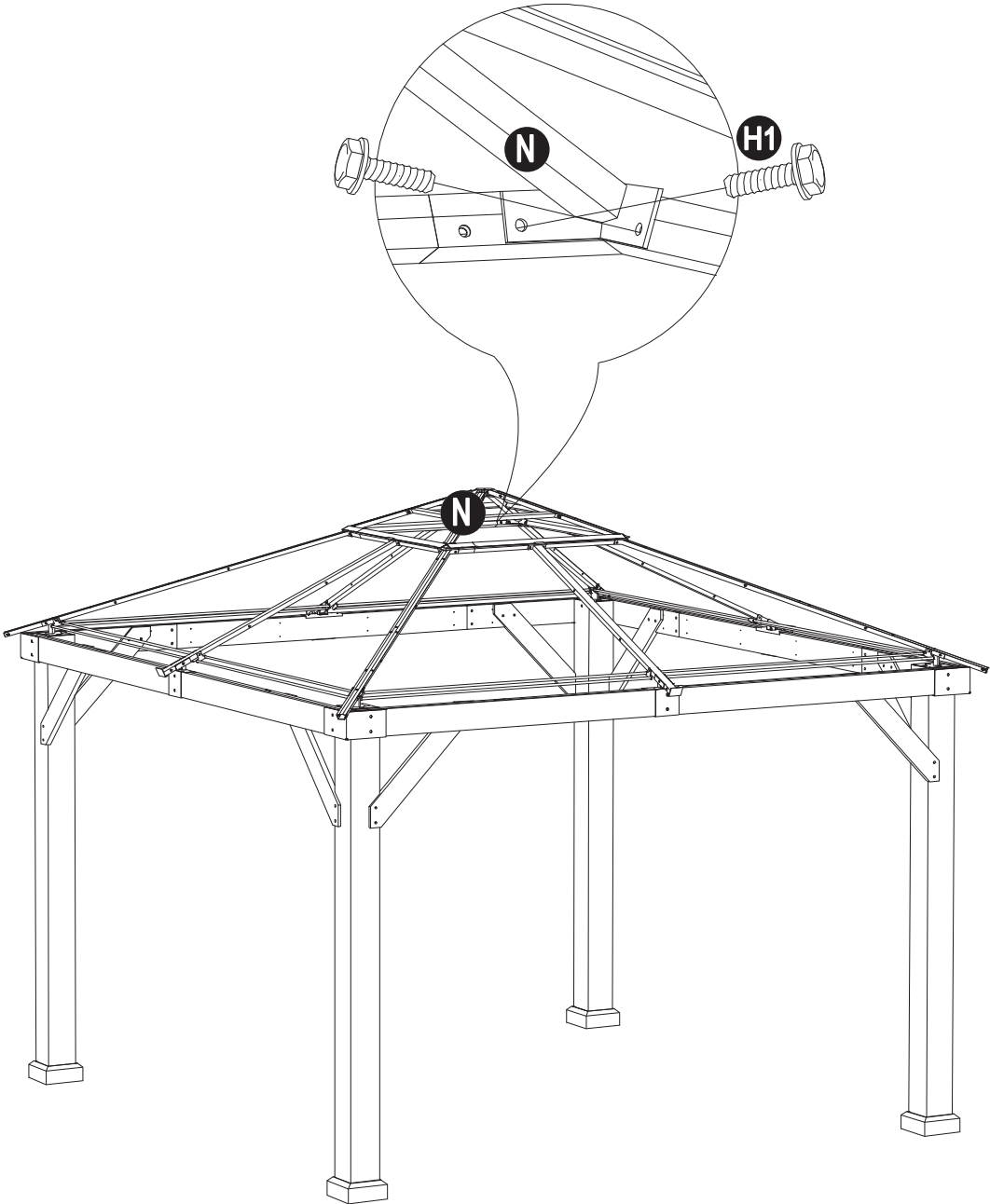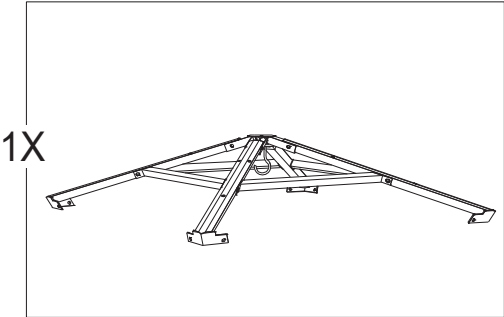


Step 15

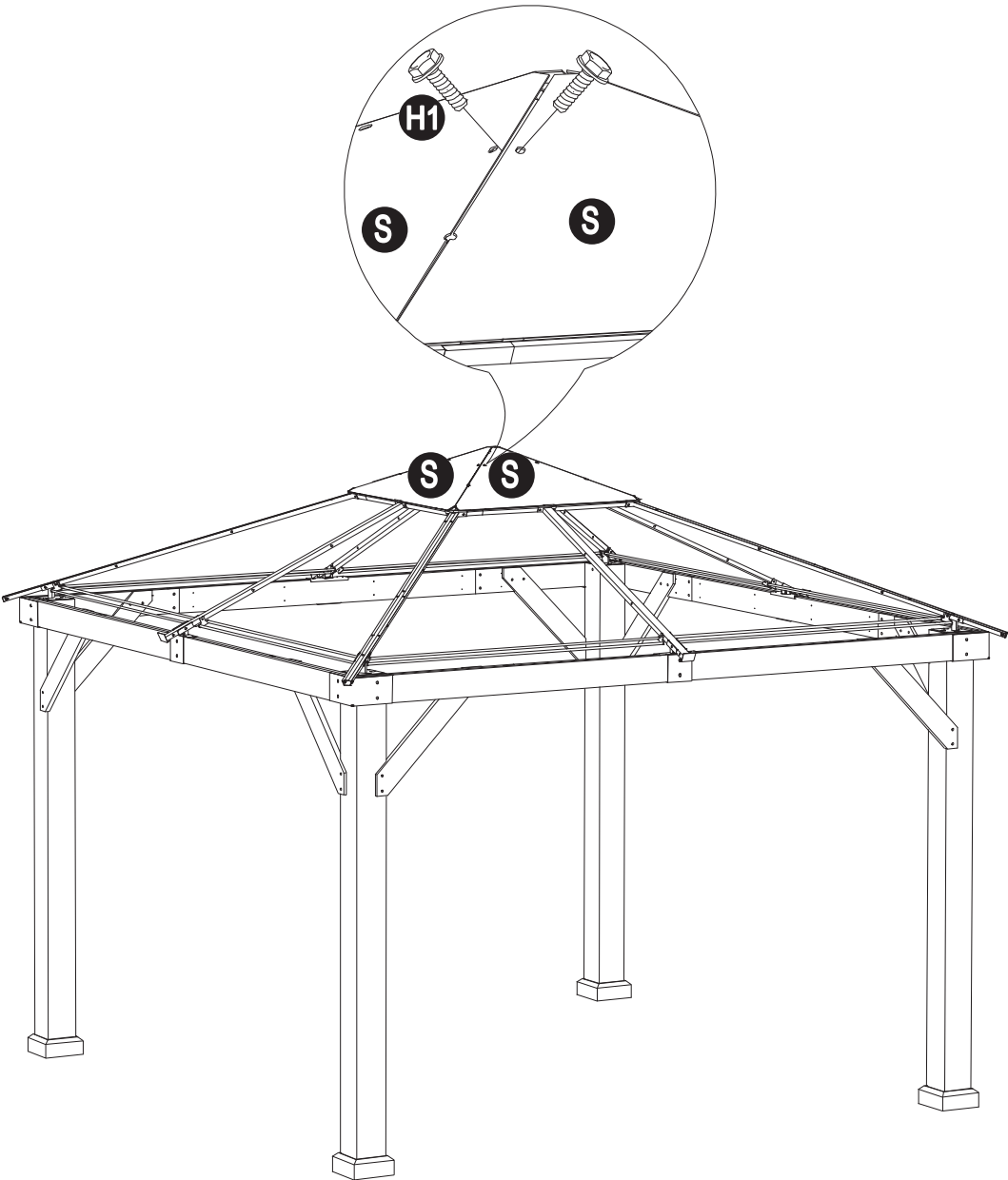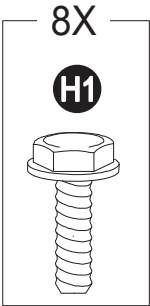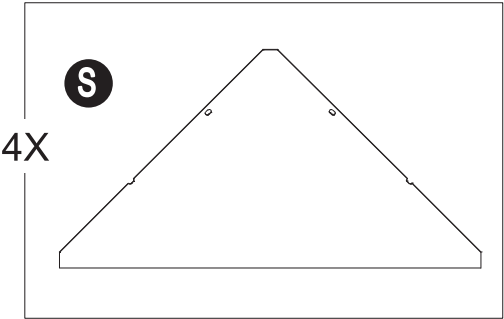



Step 16

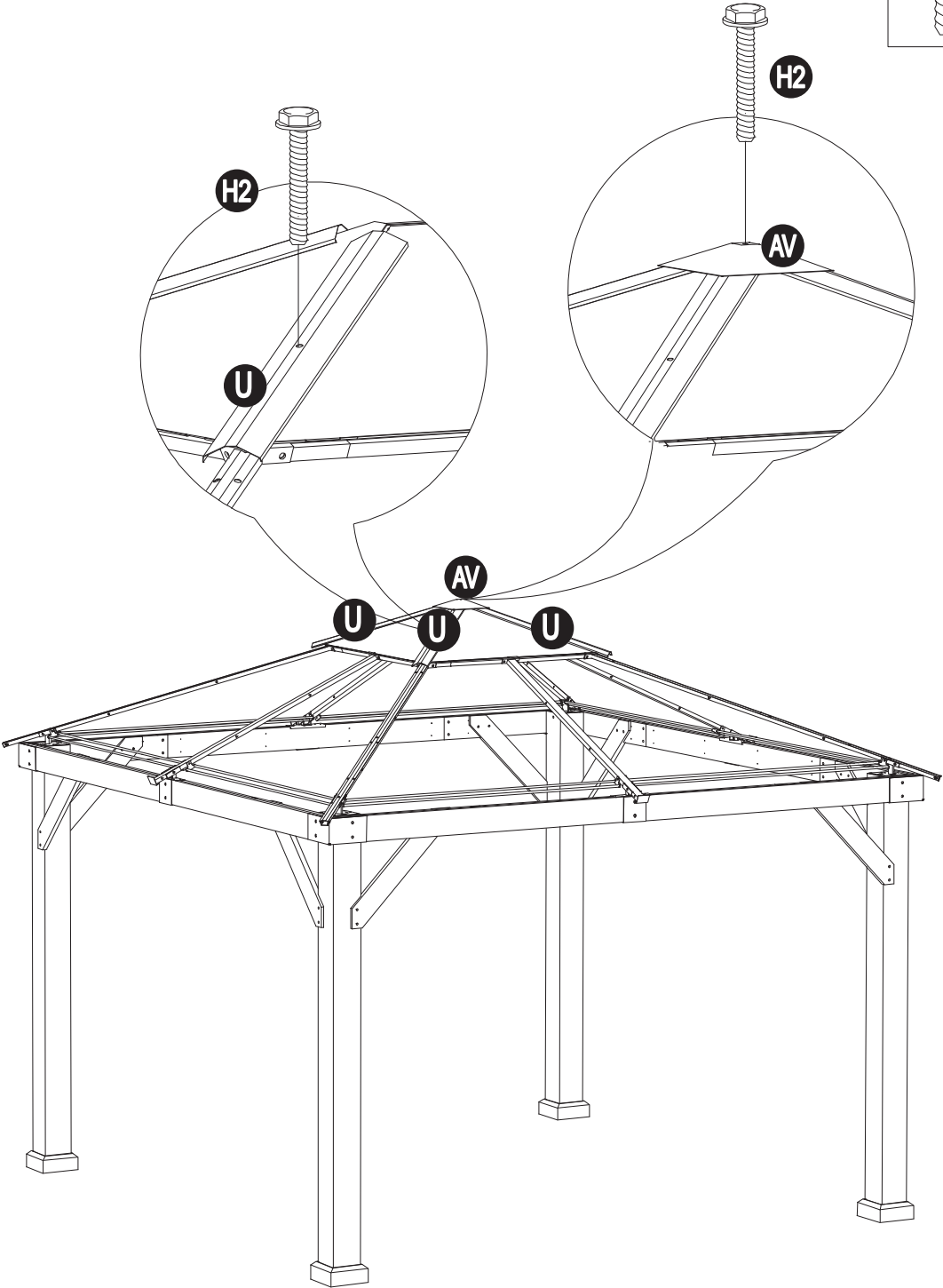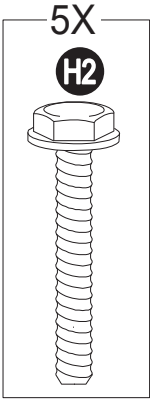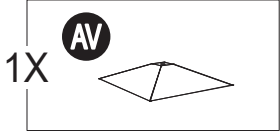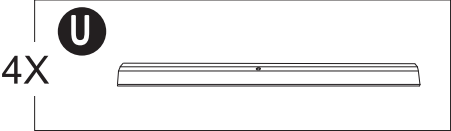




Step 17

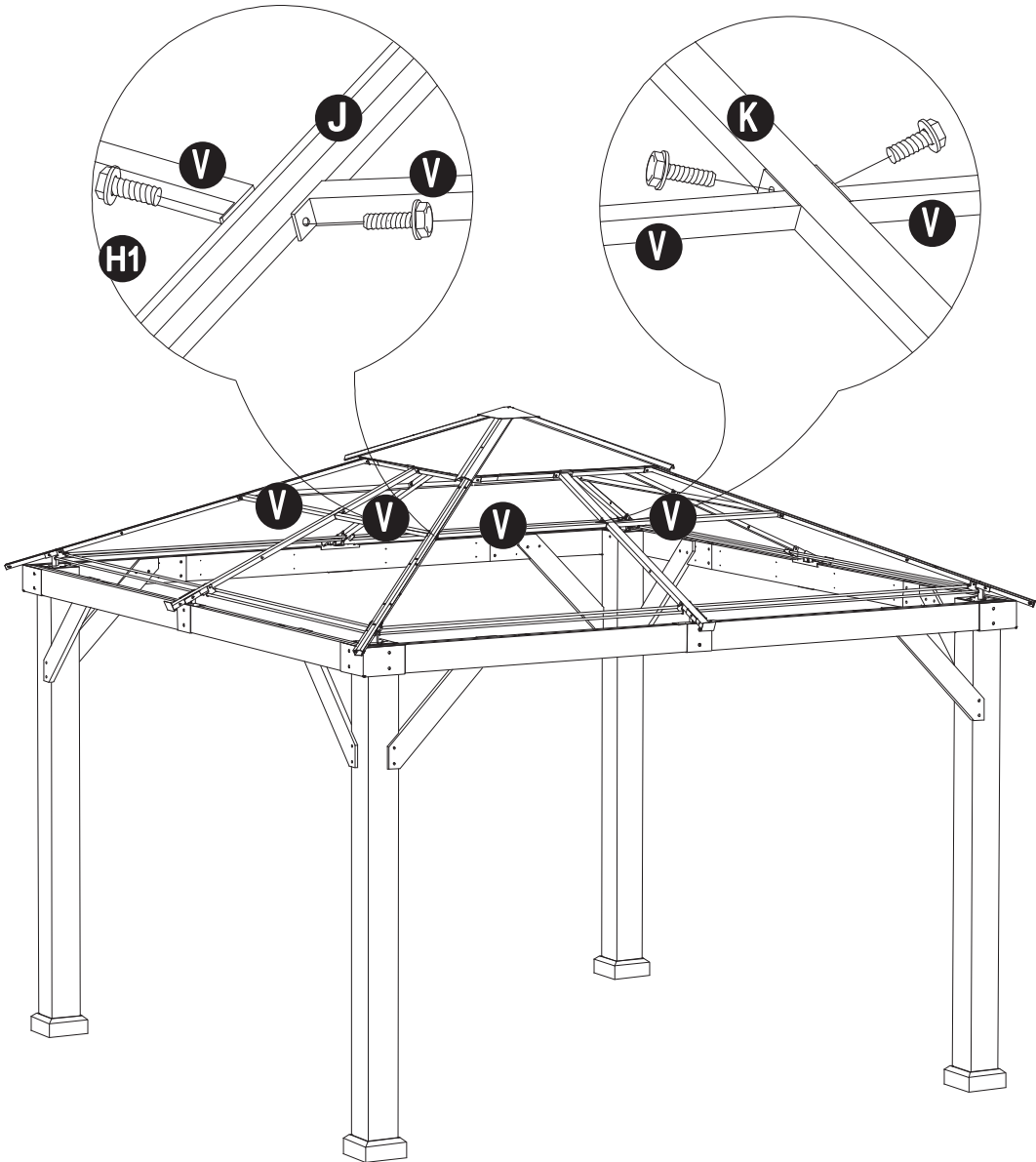


Step 18

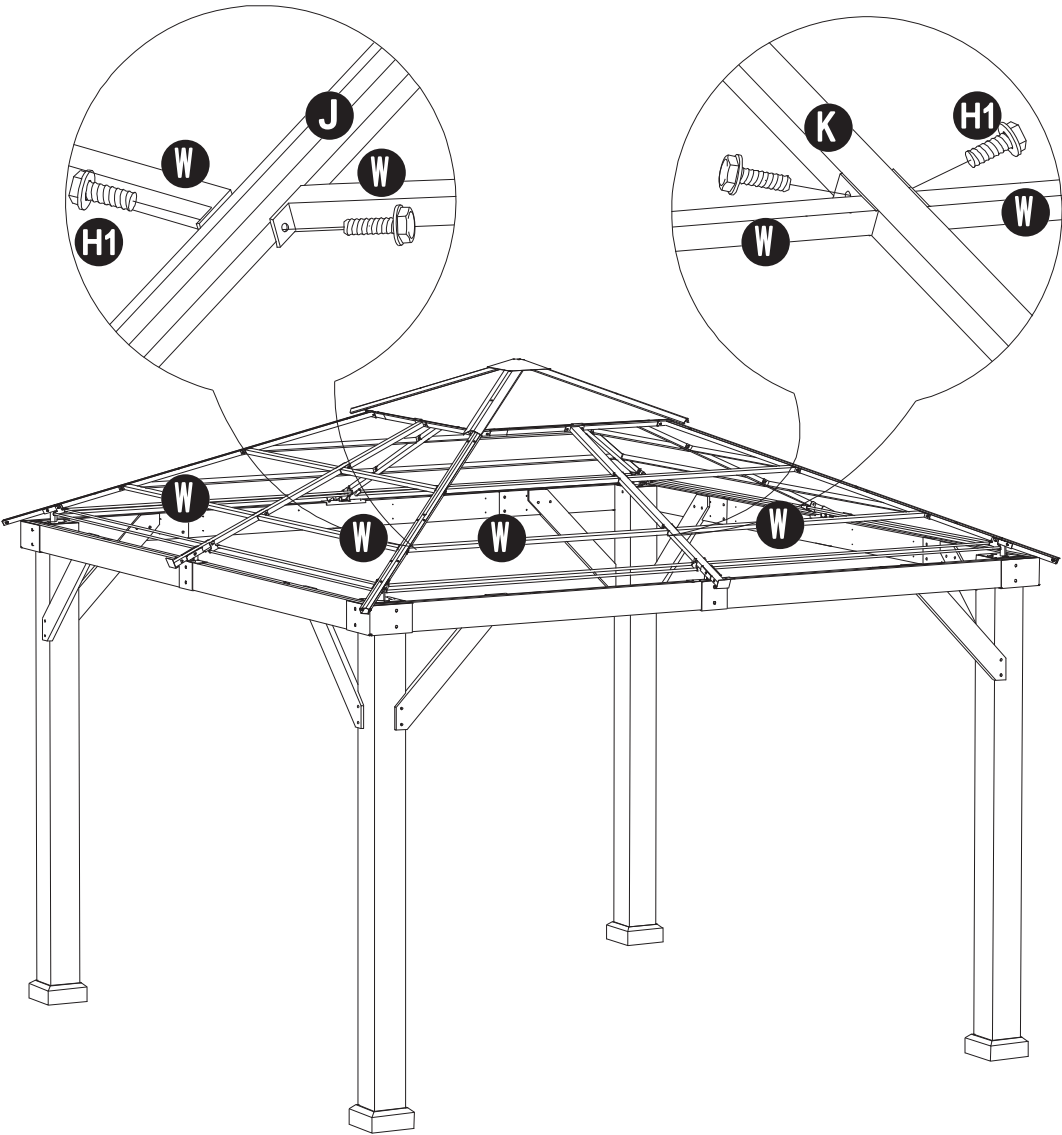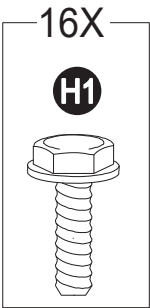


Step 19

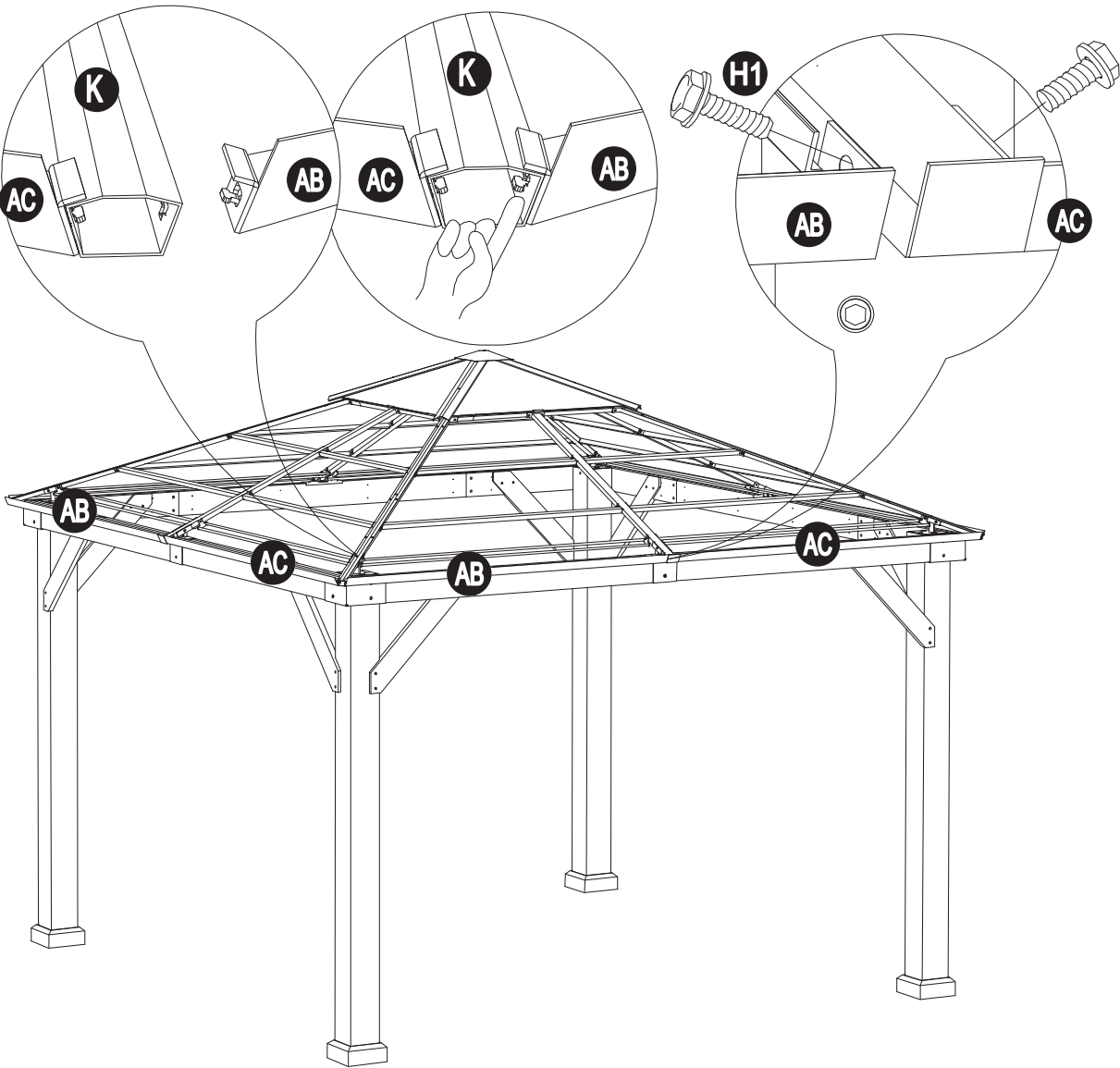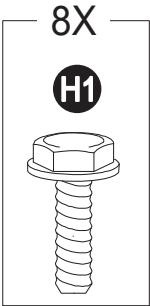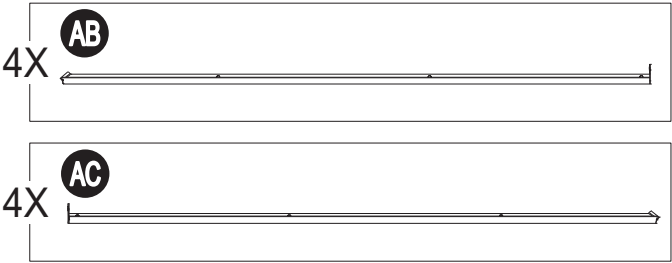





Step 20

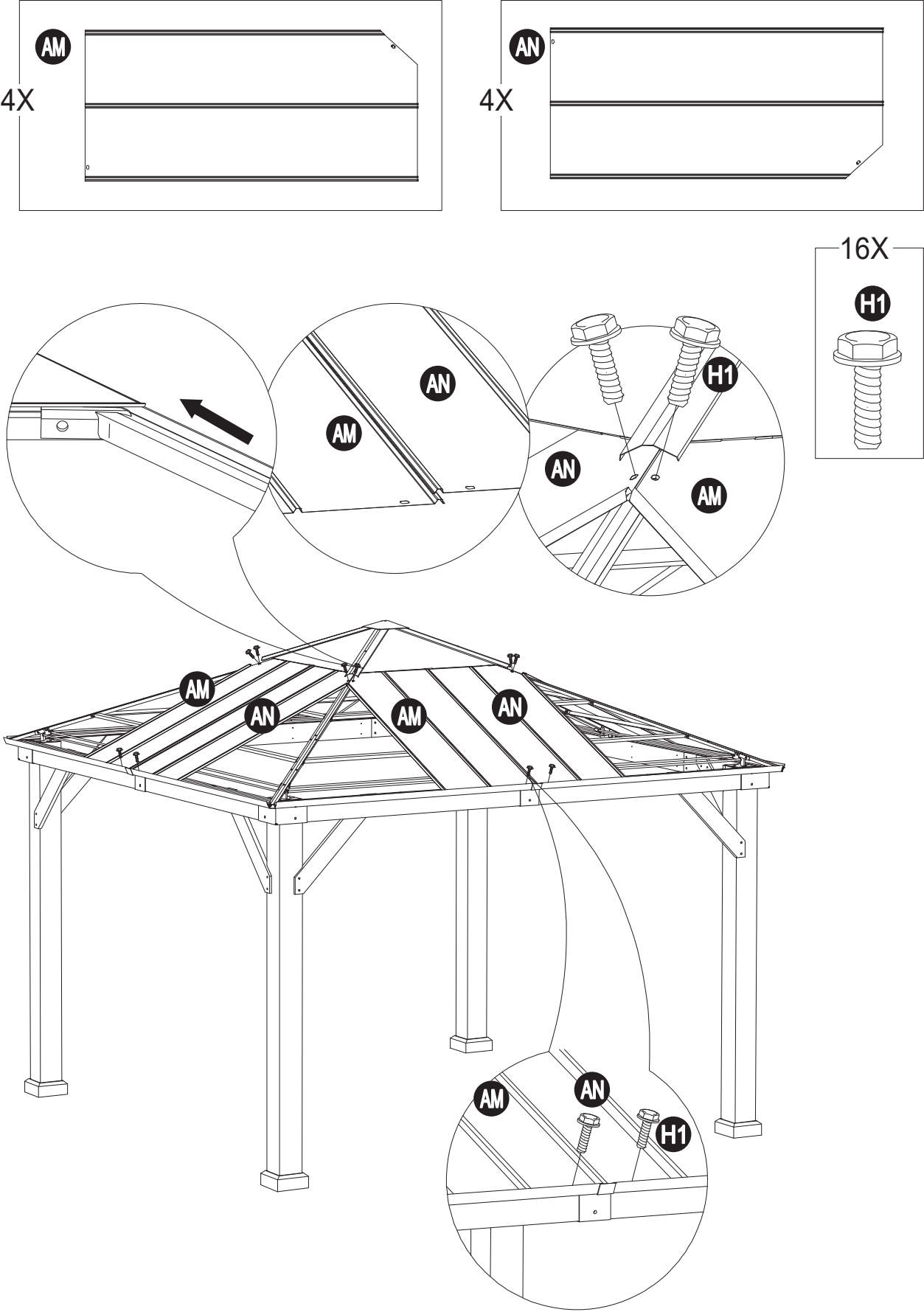




Step 21

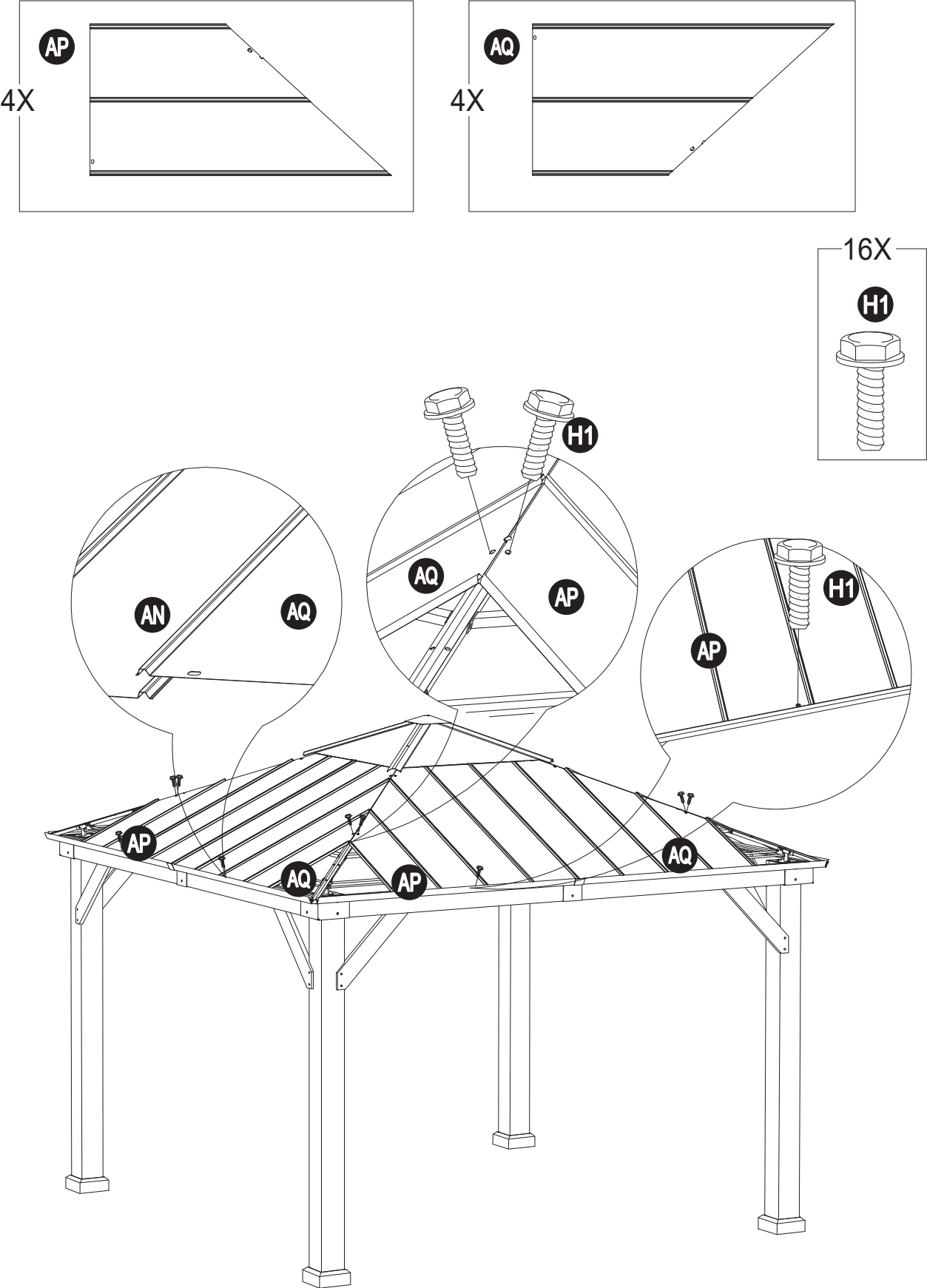

Step 22

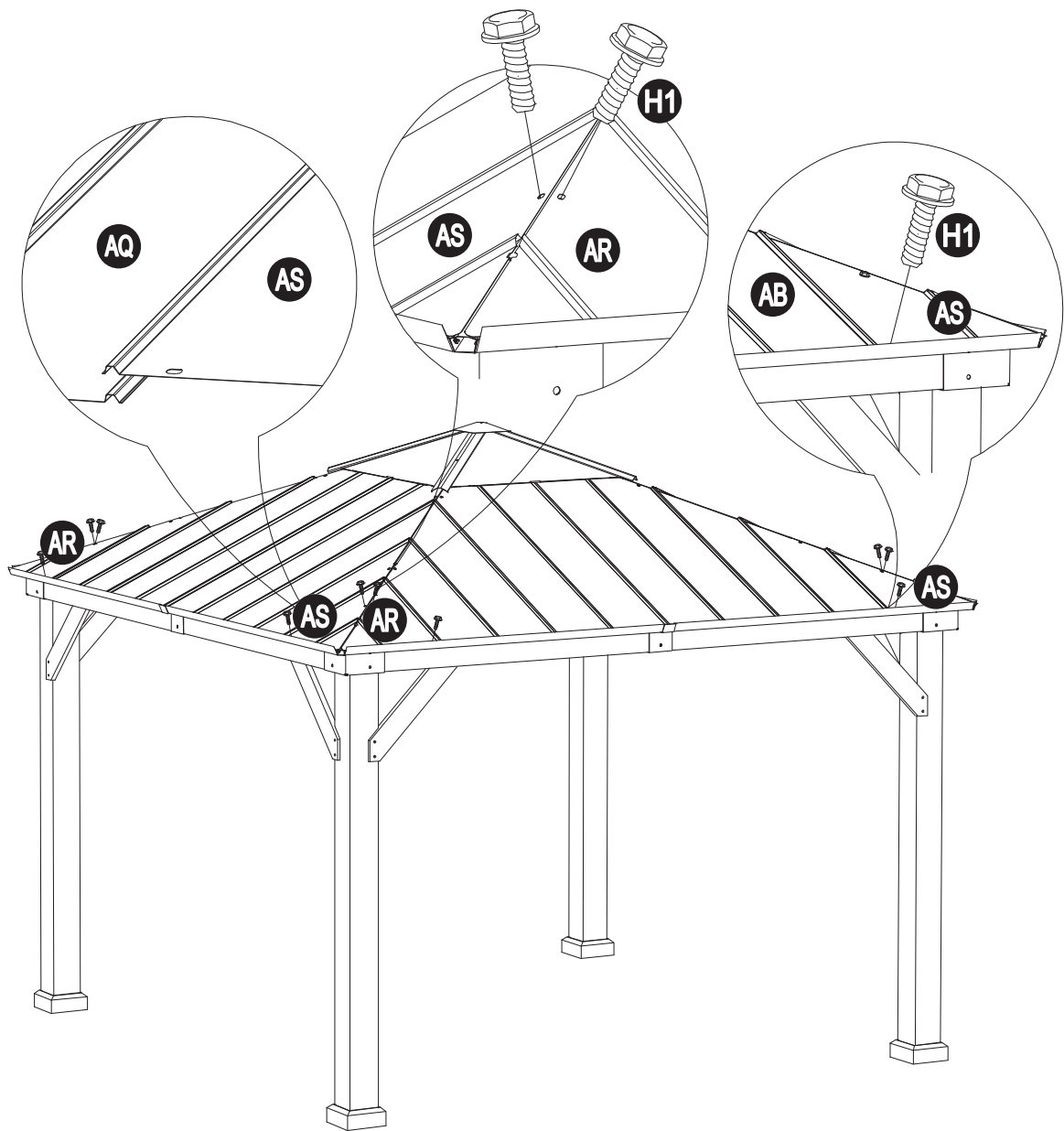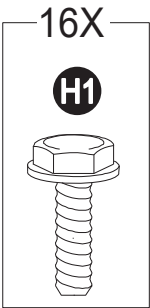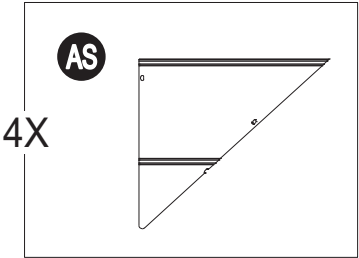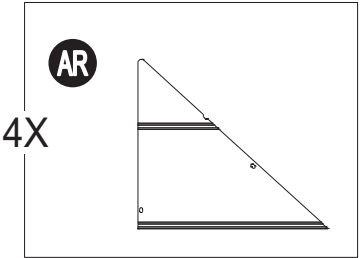

Step 23

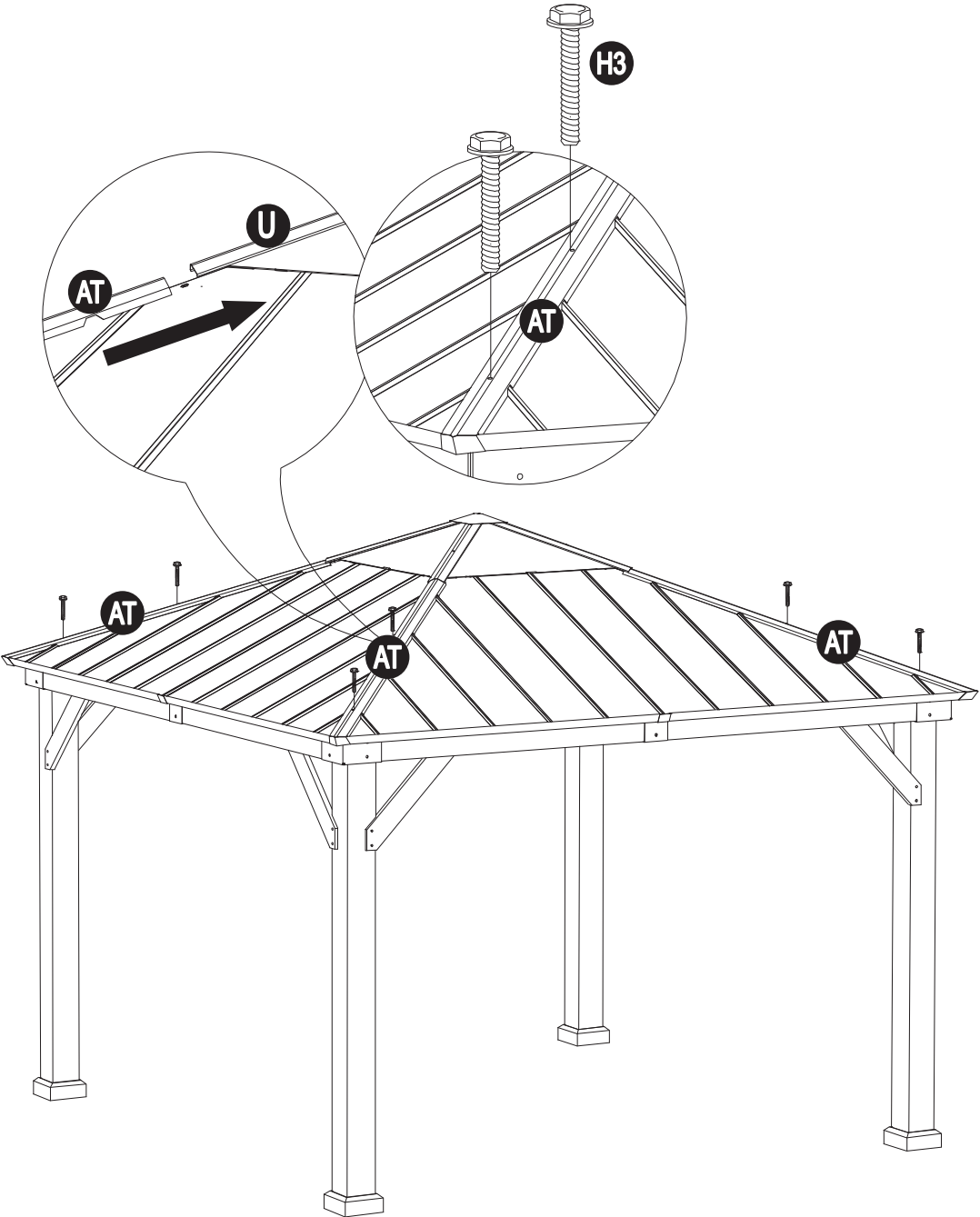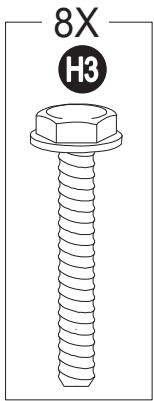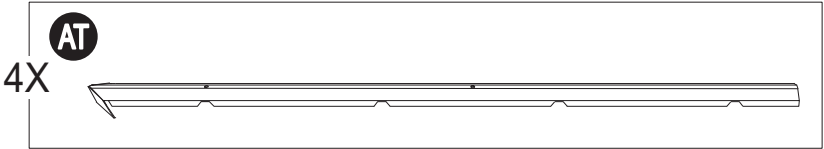

Step 24

