



**MCR
SAFETY**

6420

Memphis PVC

**Supported / Dipped gloves
Specification Sheet**

PRODUCT DESCRIPTION:

The best bang for your buck! PVC offers unmatched performance at an affordable cost. Double dipped PVC coated gloves provide excellent protection. Glove lengths from knit wrist to 18 inches to provide different levels of protection. The 6420 is an industry standard double dipped green PVC glove that features a sandy finish, jersey lining and a knit wrist. Looking for the best PVC coated gloves? Look no further than MCR Safety!



FEATURES:

- Double dipped PVC coated gloves
- Comfortable knit wrist
- Hunter green color
- Soft jersey liner
- Sandy texture improves grip

APPLICATIONS:

Agriculture, Carpentry, Construction, Farming, Fisheries, Janitorial, Landscaping, Sanitation

TECHNICAL DATA FOR: 6420

Series	Memphis PVC	Overall Length	10 in.
Material Group	Supported		
Product Type	Supported / Dipped gloves		
Glove Size	Large		
Material	PVC		
Grade	Industrial Grade		
Lining	Jersey		
Thumb Style	Wing		
Made In	China		

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2021 MCR Safety - All Rights Reserved




MCR
SAFETY

6420

Memphis PVC

Supported / Dipped gloves
Specification Sheet

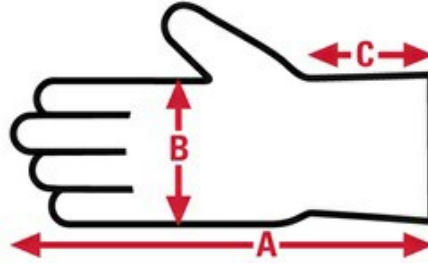

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
6420	Large	10.500	5.000	3	27.318 lb.	4.553

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2021 MCR Safety - All Rights Reserved