

SYROS

498-14-VB

FINISHES

VINTAGE BRASS

Coastal Suitable Finish (EPM): No

DIMENSIONS

Height: 18.5"

Width/Diameter: 13.75"

Minimum Height: 22"

Maximum Height: 92.25"

Canopy/Backplate: 5"

Hanging Type: 72" Chain

Product Weight: 12.57lb

Canopy/Backplate Shape: Round

Sloped Ceiling Compatible: Yes

Living Finish: Yes

Uplight Only: No

Shade

Shade 1: Glass

Shade 1 Finish: Remolino Blanco Etched Inside

Shade 1 Top Width: 13.75"

Shade 1 Height: 10.75"

Shade 2: Glass

Shade 2 Finish: Dark Bronze

Shade 2 Top Width: 10"

Shade 2 Height: 4"

ELECTRICAL



Bulb 1

Bulb Included: N/A

Socket: Integrated LED

Max Wattage: 21

Bulb Quantity: 1

Bulb Included: Yes

Wire Length: 144"

Cord Type: SPT-1 SILVER W/ TINNED GROUND
WIRE

Dimmer Type: TRIAC

Gem Box Required (2"x3"):

Dark Sky: No

CRI: 90

Color Temp.: 2700k

Lumens: 1000

Title 24: No

Field Serviceable: Yes


SHIPPING

Carton 1: 18" x 18" x 22"


Carton 1 Weight: 21lb

Shipping Method: Ground

Country of Origin: VN

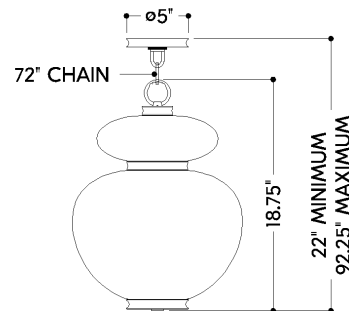

FRONT

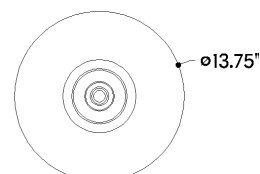

BOTTOM