



Installation Instruction

UFO HIGHBAY



PLEASE READ
BEFORE USE!

SAFETY INFORMATION:

1. Please read and understand this entire manual before attempting to assemble, operate, or install the product, modifications to the product void the warranty.
2. Suitable for wet locations.

WARNING:

1. Turn off power before installation or maintenance.
2. Suitable for operation in ambient not exceeding 45 °C (113°F)

CAUTION:

1. To prevent wiring damage or abrasion, do not expose wiring to edges of sheet metal or other sharp objects.
2. This product must be installed in accordance with the applicable installation code by a person familiar with the construction and operation of the product and the hazards involved.
3. Risk of fire.

PREPARATION:

Before beginning assembly, installation or operation of product, make sure all parts are present. Compare parts with package contents list and diagram. If any part is missing or damaged, do not attempt to assemble, install or operate the product. Contact customer service for replacement parts.

INSTALLATION GUIDE:

1. UNBOX AND FLIP THE MOUNTING RING (See Fig.1)

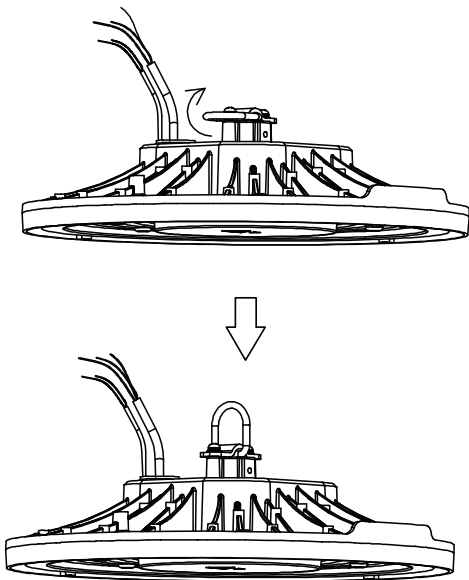


Fig.1

2. DISCONNECT POWER OF LUMINAIRE

Disconnect power to luminaire or circuit (if possible). Ensure all power is off by using a voltmeter or other method to confirm.

3. MOUNTING LUMINAIRE

Hang the Mounting ring to the ceiling Hook and Fasten ceiling Hook nut. (See Fig.2)

Attention: the ceiling should be able to support more than 60Kg.

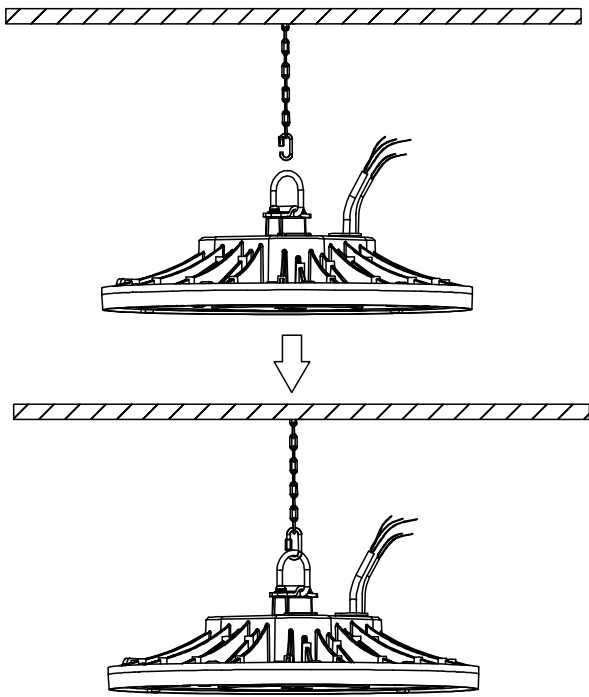


Fig2

4. THE WIRING SHOULD BE IN ACCORDANCE WITH THE NEC (See Fig.3)

- a. LUMINAIRE black wire wiring to the Mains line L with a wirenut (not provided).
- b. LUMINAIRE white wire wiring to the Mains line N with a wire nut(not provided).
- c. LUMINAIRE green wire wiring to the ground wire with a wire nut(not provided). in accordance to local electrical codes.
- d. Push all wires and all wire nuts(not provided) back inside outlet box, Relock the outlet box , making sure the ports are in the outlet box


Attention: It should be waterproof and insulated.

DIMMING METHOD:

This dimmable UFO light is compatible with all 0-10V/1-10V dimmers available on the market.

To enable the dimming function, please follow these wiring instructions:(See Fig.3)

- a. Connect the luminaire's purple wire to the 0-10V signal input wire (DIM+) using a wire nut (not included).
- b. Connect the luminaire's pink wire to the 0-10V signal input wire (DIM-) using a wire nut (not included).

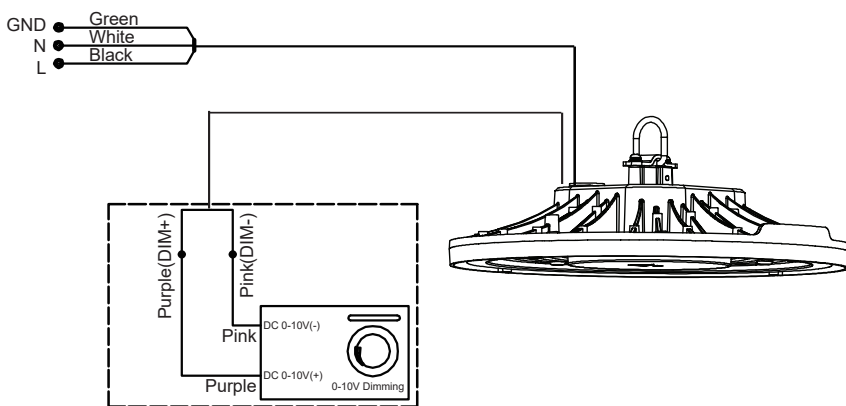

This is dimming only

Fig3

5. RESTORE THE POWER OF LUMINAIRE

Restore power to circuit/luminaire and test light.

WARNING of maintenance:

- Turn off power before Maintenance.