

DASHIELL

490-60-VPB

The modern mobile-inspired Dashiell chandelier is designed to spark conversations. While constructed of substantial materials, this chandelier maintains a light, balanced appearance with an innate sense of movement. Slender Vintage Polished Brass arms are capped with tapered cylindrical alabaster shades, adding a note of contrast to the upscale fixture. The distinctive fluted holders of the shades provide additional style. Illuminated by LED, Dashiell is available in two sizes.

*Due to the one-of-a-kind nature of the medium, exact colors and patterns may vary slightly from the image shown.

FINISHES

VINTAGE POLISHED BRASS

Coastal Suitable Finish (EPM): No

DIMENSIONS

Height: 13.75"

Width/Diameter: 60"

Minimum Height: 19.25"

Maximum Height: 87.75"

Canopy/Backplate: 6"

Hanging Type: 72" Chain

Product Weight: 32.29lb

Canopy/Backplate Shape: Round

Sloped Ceiling Compatible: No

Living Finish: No

Uplight Only: No

Shade

Shade 1: Natural Stone

Shade 1 Finish: Alabaster

Shade 1 Top Width: 1.75"

Shade 1 Bottom L/W: 0" / 2.5"

Shade 1 Height: 11.5"

ELECTRICAL



Bulb 1

Bulb Included: N/A

Socket: Integrated LED

Max Wattage: 39

Bulb Quantity: 6

Bulb Included: Yes

Wire Length: 120"

Cord Type: SPT-1 SILVER W/ TINNED GROUND
WIRE

Dimmer Type: ELV, TRIAC, 0-10 VOLT

Gem Box Required (2"x3"): No

Dark Sky: No

CRI: 90

Color Temp.: 2700k

Lumens: 2475

Title 24: No

Field Serviceable: No


SHIPPING

Carton 1: 38" x 24" x 7"

Carton 1 Weight: 38lb

Shipping Method: Ground

Country of Origin: VN

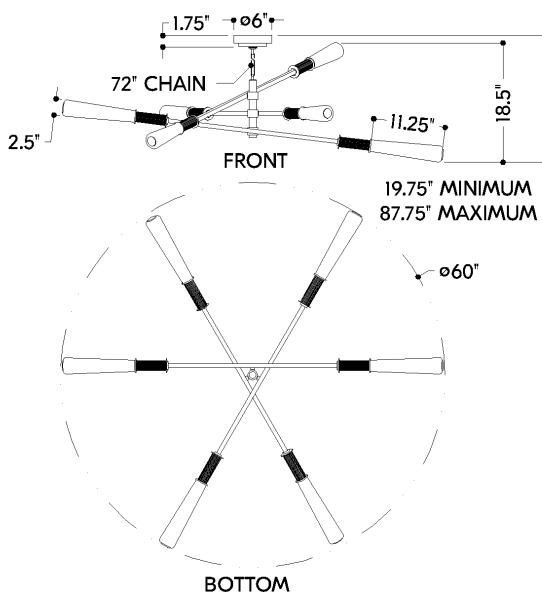

HUDSON VALLEY
LIGHTING GROUP

| hvlgroup.com | 1.800.814.3993

REVISED 3.11.2022