

Steel octagon boxes & ceiling pans


4" OCTAGON OUTLET BOXES – 21.5 CUBIC INCH CAPACITY

2 1/8" DEEP
FOR CONDUIT – NO CLAMPS

UL LISTED



TP288, TP290, TP294

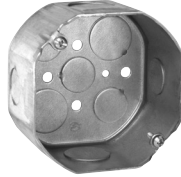

TP292, TP838



TP292RED



TP339

Cat. #	Description	Knockouts		Fan rated (weight lbs.)	Fixture rated (weight lbs.)	Unit qty.	Wt. lbs. per 100
		Sides	Bottom				
TP288	-	4 - 1/2"	3 - 1/2", 2 - 3/4"	No	50	25	64
TP288G	-	4 - 1/2"	3 - 1/2", 2 - 3/4"	No	50	25	64
TP288PF	-	4 - 1/2"	3 - 1/2", 2 - 3/4"	No	50	25	64
TP290	-	4 - 3/4"	3 - 1/2", 2 - 3/4"	No	50	25	64
TP290G	-	4 - 3/4"	3 - 1/2", 2 - 3/4"	No	50	25	64
TP290PF	-	4 - 3/4"	3 - 1/2", 2 - 3/4"	No	50	25	64
TP292	-	2 - 1/2", 2 - 3/4"	3 - 1/2", 2 - 3/4"	No	50	25	64
TP292G	-	2 - 1/2", 2 - 3/4"	3 - 1/2", 2 - 3/4"	No	50	25	64
TP292PF	-	2 - 1/2", 2 - 3/4"	3 - 1/2", 2 - 3/4"	No	50	25	64
TP292RED	-	2 - 1/2", 2 - 3/4"	3 - 1/2", 2 - 3/4"	No	50	25	64
TP294	-	4 - 1"	3 - 1/2", 2 - 3/4"	No	50	25	64
TP294G	-	4 - 1"	3 - 1/2", 2 - 3/4"	No	50	25	64
TP339	Blank bottom	4 - 1/2"	-	No		25	65
Air plenum							
TP838	For air plenum	2 - 1/2", 2 - 3/4"	3 - 1/2", 2 - 3/4"	No	50	25	62

^BFor air plenum (no mounting holes) - not UL Listed.

^ETP catalog numbers ending in PF include ground screw with pigtail lead.

^FCSA certified. G indicates ground screw installed.

^GNot UL Listed.

4" OCTAGON OUTLET BOXES – 21.5 CUBIC INCH CAPACITY

2 1/8" DEEP – WITH CABLE CLAMPS

UL LISTED




TP316



TP318



TP320

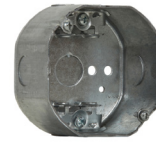

TP317



TP338

Cat. #	Description	Knockouts		Fan rated (weight lbs.)	Fixture rated (weight lbs.)	Unit qty.	Wt. lbs. per 100
		Sides	Bottom				
For non-metallic cable							
TP316	-	4 - cable, 2 - 1/2"	1 - 1/2"	No	50	25	68
TP318	"C" bracket	4 - cable, 2 - 1/2"	1 - 1/2"	No	50	25	88
TP318G	"C" bracket	4 - cable, 2 - 1/2"	1 - 1/2"	No	50	25	88
TP320	"S" bracket, set 1/2"	4 - cable, 1 - 1/2"	1 - 1/2"	No	50	25	81
For armored & metal-clad (MCI) cable – clamps in each end							
TP317 ^A	-	4 - cable, 2 - 1/2"	1 - 1/2"	No	50	25	69
TP338 ^A	"S" bracket, set 1/2"	4 - cable, 1 - 1/2"	1 - 1/2"	No	50	25	82
TP338PF ^E	"S" bracket, set 1/2"	4 - cable, 1 - 1/2"	1 - 1/2"	No	50	25	82

^AUL approved for use with aluminum interlocking grounding metal-clad cable, Type MCIA (Southwire MCAP™).

MCAP™ is a registered trademark of Southwire Company.

^ETP catalog numbers ending in PF include ground screw with pigtail lead.

^FCSA certified. G indicates ground screw installed.

Steel boxes