


ASSEMBLY AND INSTALLATION INSTRUCTIONS

P0474 / C0374

WARNING: TO AVOID RISK OF ELECTRICAL SHOCK, BE SURE TO SHUT OFF POWER WHILE INSTALLING OR SERVICING THIS FIXTURE.

NOTE: 1. Before installing, consult local electrical codes for wiring and grounding requirements.
2. Read and save these instructions.


Hardware Package (included):

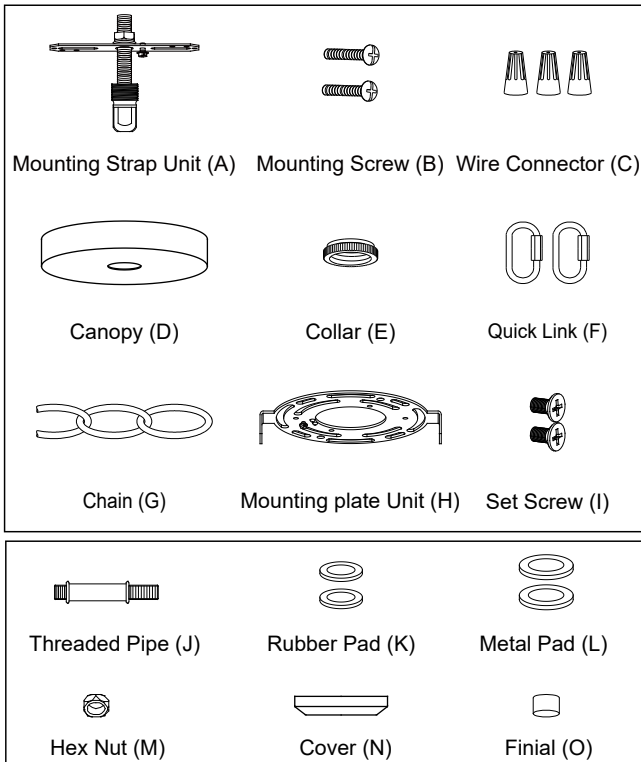

Installation Steps for Pendant:

Turn off the power at fuse or circuit box

1. Attach the mounting strap unit (A) to the outlet box using two mounting screws (B).
2. Attach the loop to the fixture with threaded pipe.
3. Choose the length of the chain (G) you needed, then weave the fixture wire and the fixture ground wire through the chain (G), collar (E) and canopy (D).
4. Connect the chain (G) to the loop and the top loop on mounting strap unit (A) with two quick links (F).
5. Thread the fixture wire and fixture ground wire through the top loop, threaded pipe of the mounting strap unit (A).

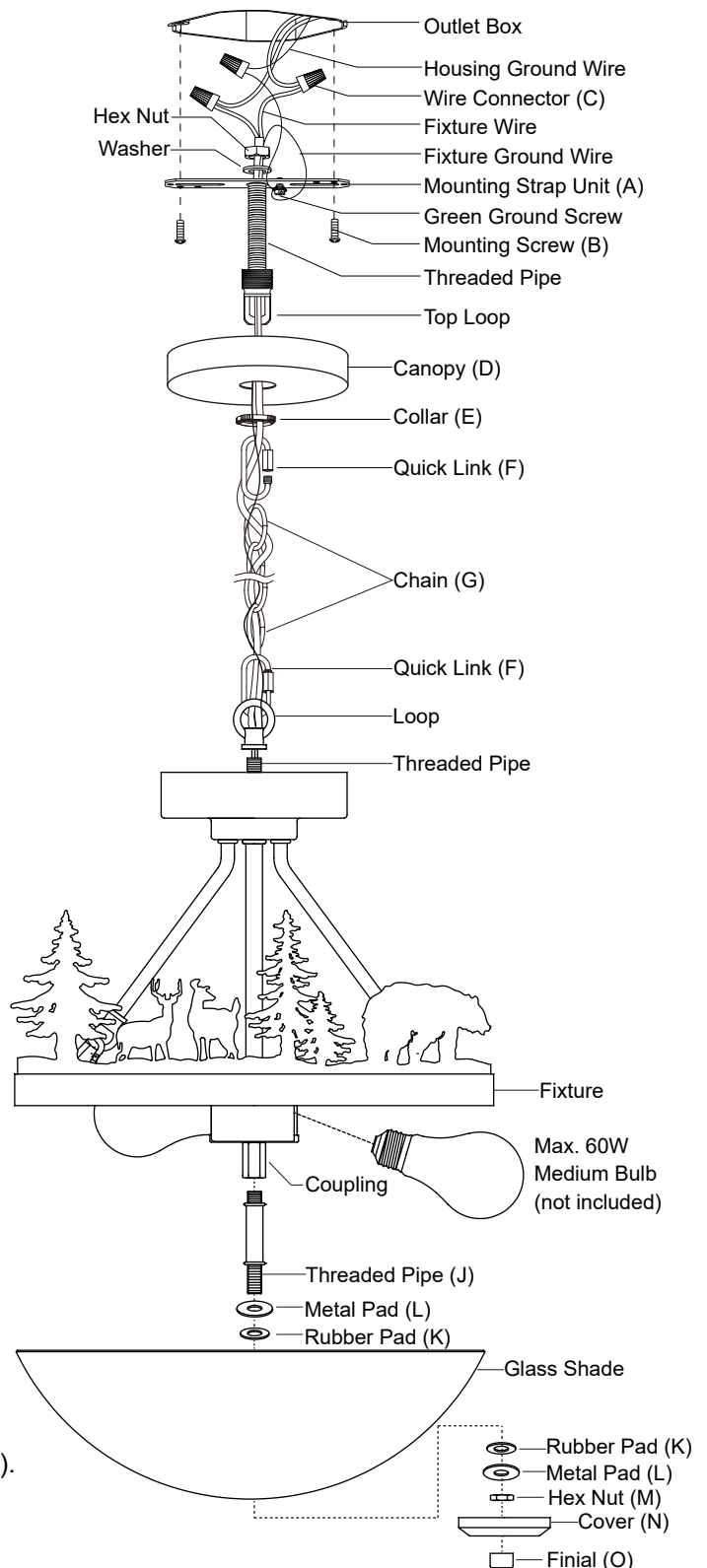

6. Pull out the outlet wires and house ground wire from the outlet box. Make wire connections using the wire connectors (C):
 - The smooth wire (marked) from the fixture to the black wire from the power source.
 - The ribbed wire (unmarked) from the fixture to the white wire from the power source.
 - Attach the fixture ground wire to the mounting strap unit (A) with the green ground screw, then connect it to the house ground wire with a wire connector (C).
 Carefully put the wires back into the outlet box.

7. Attach the canopy (D) to the mounting strap unit (A) by inserting the top loop, then tighten the collar (E) to secure it.

8. Install 2 x 60W Max. medium base bulbs (not included).


See relamping label at socket area or packaging for maximum wattage allowed.

9. Secure the threaded pipe (J) into the coupling of the fixture.

10. Attach metal pad (L), rubber pad (K) the glass shade to the fixture by inserting the threaded pipe (J) through glass shade, and then secure it with the rubber pad (K), metal pad (L), hex nut (M), cover (N) and finial (O).

11. Angled mounting recommended for a vaulted or angled ceiling (Fig.A).

Turn on the power at fuse or circuit box

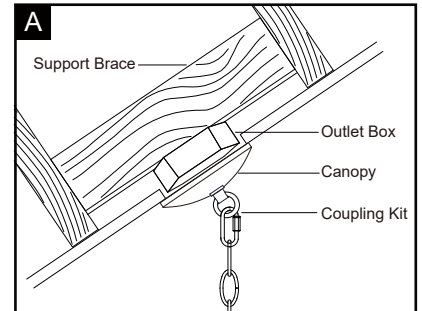


Installation Steps for Semi-Flush Mount:


Turn off the power at fuse or circuit box

1. Unscrew the two set screws (I) from the mounting plate unit (H).
2. Attach the mounting plate unit (H) to the outlet box by using two mounting screws (B).

3. Unscrew the two long set screws from the canopy, then discard the long set screws. (See Fig.1).

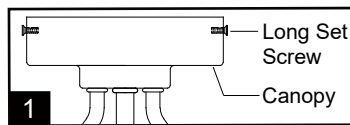

4. Cut excess fixture wires leaving only 8" (20cm) of wire from the top end of the threaded pipe. Next, strip off 3/4" (2cm) of the plastic wire coating. Remove the loop from the fixture (See Fig. 2).

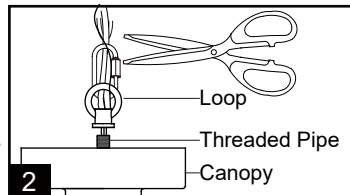


5. Pull out the source wires from the outlet box. Make wire connections using wire connectors (C) as follows:
 - Connect the smooth-coated wire (marked) from the fixture to the black wire from the power source.
 - Connect the ribbed-coated wire (unmarked) from the fixture to the white wire from the power source.
 - Attach the fixture ground wire to the mounting plate unit (H) with the green ground screw, then connect it to the house ground wire with a wire connector (C).
 Carefully put the wires back into the outlet box.

6. Attach the canopy to the mounting plate unit (H), and then secure it with two set screws (I).

7. Install 2 x 60W max. medium base bulbs (not included).

See relamping label at socket area or packaging for maximum wattage allowed.


8. Secure the threaded pipe (J) into the coupling of the fixture.

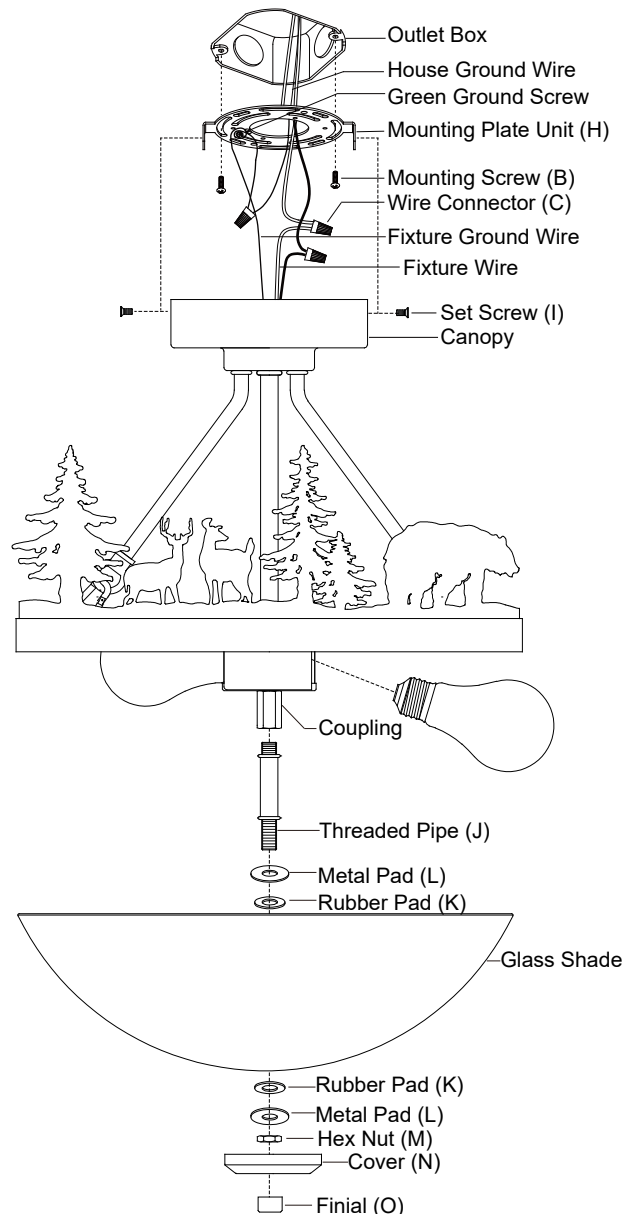

9. Attach metal pad (L), rubber pad (K) the glass shade to the fixture by inserting the threaded pipe (J) through glass shade, and then secure it with the rubber pad (K), metal pad (L), hex nut (M), cover (N) and finial (O).

Turn on the power at fuse or circuit box

Selecting Main Light or Night Light Mode

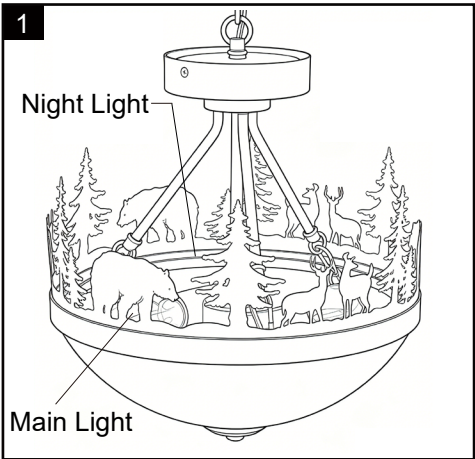

1. The fixture has three fixed sequential modes:
Mode 1 (light bulbs only), Mode 2 (LED night light only) and Mode 3 (both light bulbs and the LED night light turn on simultaneously)
- a. Flip the wall switch ON after installation to enter Mode 1 (light bulbs only).
- b. Flip the wall switch OFF and back ON in less than 3 seconds to enter the Mode 2 (LED night light only).
- c. Flip the wall switch OFF and back ON again in less than 3 seconds to enter Mode 3(both light bulbs and LED night light)

This fixture is dimmable with a forward phase electronic dimmer. Dimmers tested to be compatible with this Fixture are the Lutron: SCL-153P, LECL-153P.DVCL-153P.


If you are unfamiliar with electrical installation, it is recommended to use a qualified electrician for your installation(s).

NOTE: If the fixture is turned off for more than 6 seconds, the mode will automatically revert to the default Mode 1 (light bulbs only).

The following parts are available for reorder if damaged or missing.

Spare Parts List:

				→ Mounting Hardware 7282MM (1SET)
Mounting Strap Unit (A)	Mounting Screw (B)	Wire Connector (C)	Canopy (D)	
				→ Assembly Hardware 7283MM (1SET)
Collar (E)	Quick Link (F)	Chain (G)	Mounting plate Unit (H)	
Set Screw (I)				
				→ Glass Shade 10617FW
Threaded Pipe (J)	Rubber Pad (K)	Metal Pad (L)		
Hex Nut (M)	Cover (N)	Finial (O)		

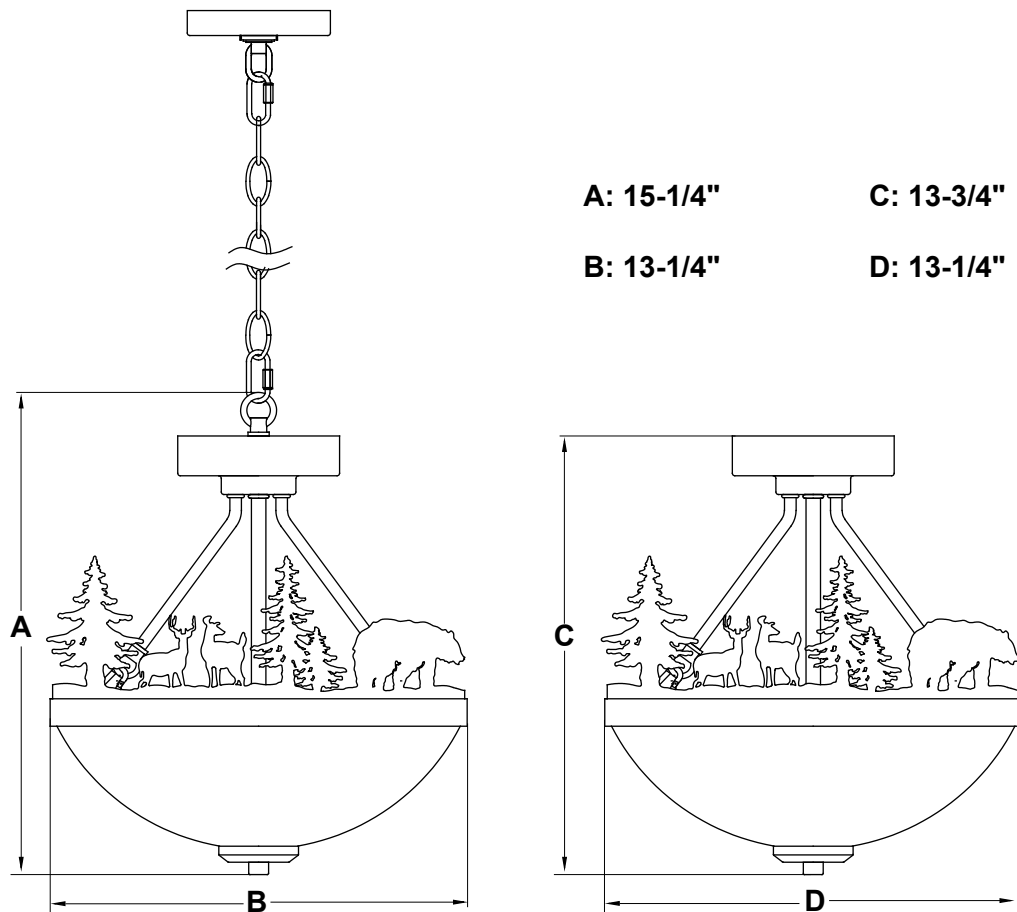

5 Year Limited Warranty

Vaxcel warrants all of our products against defects in workmanship and finishes for one year following the date of shipment.

In addition:

- Any product with an integrated motion sensor or dusk-to-dawn photocell is supported by a 5-year warranty for the functionality of the product.
- Any product with integrated LED modules is covered by a 5-year warranty on the LED functionality.

Exclusions: This warranty does not include the failure of products from extreme acts of nature; environmental conditions not suited for the products intended use; operation in temperatures outside of the range specified in the instruction manual; usage with improper power supply, power surges or dips. For coastal locations, some corrosion is considered normal for the environment.

Vaxcel reserves the right to repair, replace or issue a credit for any properly installed product, provided it is returned per RMA instruction. This warranty is limited to the cost of the product only and does not extend to transportation, installation or replacement costs.

How can warranty service be obtained?

info@vaxcel.com

1-800-482-9235