

1/4" Drive 90-Tooth Teardrop Ratchet

- 90-tooth gear delivers a 4° swing arc to turn a fastener in tight confines
- Teardrop, low-profile head and flush-mounted on/off switch allow better access in tight spaces
- Enclosed head design for extreme resistance to dirt infiltration
- Precision engineered high strength pawl for increased durability
- Highly visible on/off markings on the head
- Bright, full polish chrome finish easily wipes clean and resists corrosion
- Meets or exceeds ASME specifications



Cat. No.	Overall Length	Head Width	Head Thickness	Tooth Count	Repair Kit	Product Weight
81011T	5.13 in	0.98 in	0.35 in	90	81099T	0.290 lb

1/4" Drive 90-Tooth Dual Material Teardrop Ratchet

- 90-tooth gear delivers a 4° swing arc to turn a fastener in tight confines
- Teardrop, low-profile head and flush-mounted on/off switch allow better access in tight spaces
- Dual material comfort grip handle
- Enclosed head design for extreme resistance to dirt infiltration
- Precision engineered high strength pawl for increased durability
- Highly visible on/off markings on the head
- Bright, full polish chrome finish easily wipes clean and resists corrosion
- Meets or exceeds ASME specifications



Cat. No.	Overall Length	Head Width	Head Thickness	Tooth Count	Repair Kit	Product Weight
81007T	6.88 in	0.98 in	0.35 in	90	81099T	0.310 lb

1/4" Drive 90-Tooth Long Handle Teardrop Ratchet

- 90-tooth gear delivers a 4° swing arc to turn a fastener in tight confines
- Precision engineered high strength pawl for increased durability
- Long 6.8" full polish chrome handle for increased access
- Highly visible on/off markings on the head
- Teardrop, low-profile head and flush-mounted on/off switch allow better access in tight spaces
- Enclosed head design for extreme resistance to dirt infiltration
- Bright, full polish chrome finish easily wipes clean and resists corrosion
- Meets or exceeds ASME specifications



Cat. No.	Overall Length	Head Width	Head Thickness	Tooth Count	Repair Kit	Product Weight
81028T	6.87 in	0.98 in	0.35 in	90	81099T	0.330 lb

1/4" Drive 90-Tooth Long Handle Dual Material Teardrop Ratchet

- 90-tooth gear delivers a 4° swing arc to turn a fastener in tight confines
- Teardrop, low-profile head and flush-mounted on/off switch allow better access in tight spaces
- Long 8.1" handle for increased access
- Dual material comfort grip handle
- Enclosed head design for extreme resistance to dirt infiltration
- Precision engineered high strength pawl for increased durability
- Highly visible on/off markings on the head
- Bright, full polish chrome finish easily wipes clean and resists corrosion
- Meets or exceeds ASME specifications



Cat. No.	Overall Length	Head Width	Head Thickness	Tooth Count	Repair Kit	Product Weight
81029T	8.18 in	0.98 in	0.35 in	90	81099T	0.550 lb

1/4" Drive 90-Tooth Flex Head Teardrop Ratchet

- 90-tooth gear delivers a 4° swing arc to turn a fastener in tight confines
- Teardrop, low-profile head and flush-mounted on/off switch allow better access in tight spaces
- 6 Position flexible head provides access for hard to reach fasteners
- Enclosed head design for extreme resistance to dirt infiltration
- Precision engineered high strength pawl for increased durability
- Highly visible on/off markings on the head
- Bright, full polish chrome finish easily wipes clean and resists corrosion
- Meets or exceeds ASME specifications



Cat. No.	Overall Length	Head Width	Head Thickness	Tooth Count	No. of Positions	Repair Kit	Product Weight
81012T	6.97 in	0.98 in	0.35 in	90	6	81099T	0.410 lb

1/4" Drive 90-Tooth Dual Material Flex Head Teardrop Ratchet

- 90-tooth gear delivers a 4° swing arc to turn a fastener in tight confines
- Teardrop, low-profile head and flush-mounted on/off switch allow better access in tight spaces
- 6 Position flexible head provides access for hard to reach fasteners
- Dual material comfort grip handle
- Enclosed head design for extreme resistance to dirt infiltration
- Precision engineered high strength pawl for increased durability
- Highly visible on/off markings on the head
- Bright, full polish chrome finish easily wipes clean and resists corrosion
- Meets or exceeds ASME specifications



Cat. No.	Overall Length	Head Width	Head Thickness	Tooth Count	No. of Positions	Repair Kit	Product Weight
81009T	8.26 in	0.98 in	0.35 in	90	6	81099T	0.430 lb

90-Tooth 12 Point Combination Ratcheting Wrenches

- 90-tooth ratcheting box end delivers a 4° swing arc to turn a fastener in tight spaces
- Off-corner loading design on box end provides better grip and reduces fastener rounding
- Dual-direction off-corner loading on open-end reduces fastener rounding
- 12-point ratcheting box-end for use on 6 or 12-point fasteners
- Longer, wider beam for improved reach, leverage, and comfort
- Large color-coded markings for easy size ID
- Bright, full polish chrome finish easily wipes clean and resists corrosion
- Exceeds ASME torque performance requirements



Cat. No.	SAE/Metric	Fastener Size	End A Width	End A Thickness	End B Width	End B Thickness	Overall Length	Product Weight
86940	SAE	1/4 in	0.567 in	0.181 in	0.654 in	0.256 in	5.118 in	0.100 lb
86941	SAE	5/16 in	0.665 in	0.193 in	0.697 in	0.272 in	5.709 in	0.100 lb
86942	SAE	11/32 in	0.768 in	0.213 in	0.752 in	0.272 in	6.189 in	0.100 lb
86943	SAE	3/8 in	0.862 in	0.224 in	0.831 in	0.303 in	6.673 in	0.100 lb
86944	SAE	7/16 in	0.953 in	0.252 in	0.909 in	0.323 in	7.094 in	0.100 lb
86945	SAE	1/2 in	1.122 in	0.319 in	1.047 in	0.339 in	7.839 in	0.140 lb
86946	SAE	9/16 in	1.228 in	0.327 in	1.102 in	0.37 in	8.378 in	0.140 lb
86947	SAE	5/8 in	1.358 in	0.346 in	1.276 in	0.406 in	9.22 in	0.220 lb
86948	SAE	11/16 in	1.492 in	0.362 in	1.358 in	0.421 in	9.854 in	0.220 lb
86949	SAE	3/4 in	1.626 in	0.374 in	1.445 in	0.441 in	10.886 in	0.220 lb
86950	SAE	13/16 in	1.807 in	0.382 in	1.622 in	0.512 in	12 in	0.450 lb
86951	SAE	7/8 in	1.807 in	0.382 in	1.622 in	0.512 in	12 in	0.450 lb
86952	SAE	15/16 in	2.055 in	0.406 in	1.894 in	0.571 in	13.563 in	0.450 lb
86953	SAE	1 in	2.055 in	0.406 in	1.894 in	0.571 in	13.563 in	0.450 lb
86954	SAE	1-1/16 in	2.221 in	0.429 in	2.037 in	0.61 in	14.142 in	0.710 lb
86955	SAE	1-1/8 in	2.429 in	0.469 in	2.27 in	0.669 in	15.846 in	0.710 lb
86956	SAE	1-1/4 in	2.583 in	0.484 in	2.402 in	0.689 in	16.764 in	0.710 lb
86906	Metric	6 mm	0.567 in	0.181 in	0.654 in	0.256 in	5.118 in	0.100 lb
86907	Metric	7 mm	0.665 in	0.193 in	0.697 in	0.272 in	5.709 in	0.100 lb
86908	Metric	8 mm	0.665 in	0.193 in	0.697 in	0.272 in	5.709 in	0.100 lb
86909	Metric	9 mm	0.768 in	0.213 in	0.752 in	0.272 in	6.189 in	0.100 lb
86910	Metric	10 mm	0.862 in	0.224 in	0.831 in	0.303 in	6.673 in	0.100 lb
86911	Metric	11 mm	0.953 in	0.252 in	0.909 in	0.323 in	7.094 in	0.100 lb
86912	Metric	12 mm	1.047 in	0.291 in	0.969 in	0.339 in	7.453 in	0.140 lb
86913	Metric	13 mm	1.122 in	0.319 in	1.047 in	0.339 in	7.839 in	0.140 lb
86914	Metric	14 mm	1.228 in	0.327 in	1.102 in	0.37 in	8.378 in	0.140 lb
86915	Metric	15 mm	1.327 in	0.327 in	1.201 in	0.39 in	8.85 in	0.140 lb
86916	Metric	16 mm	1.358 in	0.346 in	1.276 in	0.406 in	9.22 in	0.220 lb
86917	Metric	17 mm	1.492 in	0.362 in	1.358 in	0.421 in	9.854 in	0.220 lb
86918	Metric	18 mm	1.583 in	0.37 in	1.394 in	0.441 in	10.366 in	0.220 lb
86919	Metric	19 mm	1.626 in	0.374 in	1.445 in	0.441 in	10.886 in	0.220 lb
86920	Metric	20 mm	1.807 in	0.382 in	1.622 in	0.512 in	12 in	0.450 lb
86921	Metric	21 mm	1.807 in	0.382 in	1.622 in	0.512 in	12 in	0.450 lb
86922	Metric	22 mm	1.807 in	0.382 in	1.622 in	0.512 in	12 in	0.450 lb
86924	Metric	24 mm	2.055 in	0.406 in	1.894 in	0.571 in	13.563 in	0.450 lb
86925	Metric	25 mm	2.055 in	0.406 in	1.894 in	0.571 in	13.563 in	0.450 lb

13 Pc. 72-Tooth 12 Point SAE XL Combination Ratcheting Wrench Sets

- 72-tooth ratcheting box end needs a minimal 5° to move fasteners vs. 30° for standard wrenches
- Off-corner loading design on box end provides better grip and reduces fastener rounding
- Thin head and beam provide greater access in confined work areas
- Size conveniently stamped on both ends of the beam for quick identification
- Manufactured from alloy steel for better strength and longer tool life
- Bright, full polish chrome finish easily wipes clean and resists corrosion
- Longer beam provides greater access to confined work areas
- Meets or exceeds ASME and ANSI specifications
- Included tool roll or rack for storage and organization



Cat. No.	Included Storage	Product Weight
----------	------------------	----------------

85199R	Tool Roll	3.65 lb
--------	-----------	---------

Cat. No.	Included Storage	Product Weight
----------	------------------	----------------

85199	Wrench Rack	7.62 lb
-------	-------------	---------

Cat. No.	Description	Cat. No.	Description
----------	-------------	----------	-------------

85108	1/4" 72-Tooth 12 Point XL Ratcheting Combination Wrench	85122D	11/16" 72-Tooth 12 Point XL Ratcheting Combination Wrench
85110	5/16" 72-Tooth 12 Point XL Ratcheting Combination Wrench	85124D	3/4" 72-Tooth 12 Point XL Ratcheting Combination Wrench
85112	3/8" 72-Tooth 12 Point XL Ratcheting Combination Wrench	85126	13/16" 72-Tooth 12 Point XL Ratcheting Combination Wrench
85114	7/16" 72-Tooth 12 Point XL Ratcheting Combination Wrench	85128	7/8" 72-Tooth 12 Point XL Ratcheting Combination Wrench
85116	1/2" 72-Tooth 12 Point XL Ratcheting Combination Wrench	85130	15/16" 72-Tooth 12 Point XL Ratcheting Combination Wrench
85118	9/16" 72-Tooth 12 Point XL Ratcheting Combination Wrench	85132	1" 72-Tooth 12 Point XL Ratcheting Combination Wrench
85120D	5/8" 72-Tooth 12 Point XL Ratcheting Combination Wrench		

8 Pc. 72-Tooth 12 Point SAE XL Combination Ratcheting Wrench Set with Wrench Rack

- 72-tooth ratcheting box end needs a minimal 5° to move fasteners vs. 30° for standard wrenches
- Off-corner loading design on box end provides better grip and reduces fastener rounding
- Thin head and beam provide greater access in confined work areas
- Size conveniently stamped on both ends of the beam for quick identification
- Manufactured from alloy steel for better strength and longer tool life
- Bright, full polish chrome finish easily wipes clean and resists corrosion
- Longer beam provides greater access to confined work areas vs. standard length wrenches
- Meets or exceeds ASME and ANSI specifications
- Included rack for storage and organization



Cat. No.	Included Storage	Product Weight
----------	------------------	----------------

85198	Wrench Rack	3.12 lb
-------	-------------	---------

Cat. No.	Description	Cat. No.	Description
----------	-------------	----------	-------------

85110	5/16" 72-Tooth 12 Point XL Ratcheting Combination Wrench	85118	9/16" 72-Tooth 12 Point XL Ratcheting Combination Wrench
85112	3/8" 72-Tooth 12 Point XL Ratcheting Combination Wrench	85120D	5/8" 72-Tooth 12 Point XL Ratcheting Combination Wrench
85114	7/16" 72-Tooth 12 Point XL Ratcheting Combination Wrench	85122D	11/16" 72-Tooth 12 Point XL Ratcheting Combination Wrench
85116	1/2" 72-Tooth 12 Point XL Ratcheting Combination Wrench	85124D	3/4" 72-Tooth 12 Point XL Ratcheting Combination Wrench

7 Pc. 72-Tooth 12 Point SAE XL Combination Ratcheting Wrench Set with Wrench Roll

- 72-tooth ratcheting box end needs a minimal 5° to move fasteners vs. 30° for standard wrenches
- Off-corner loading design on box end provides better grip and reduces fastener rounding
- Thin head and beam provide greater access in confined work areas
- Size conveniently stamped on both ends of the beam for quick identification
- Manufactured from alloy steel for better strength and longer tool life
- Bright, full polish chrome finish easily wipes clean and resists corrosion
- Longer beam provides greater access to confined work areas vs. standard length wrenches
- Meets or exceeds ASME and ANSI specifications
- Included tool roll for storage and organization



Cat. No.	Included Storage	Product Weight
85197R	Tool Roll	3.25 lb

Cat. No.	Description	Cat. No.	Description
85112	3/8" 72-Tooth 12 Point XL Ratcheting Combination Wrench	85120D	5/8" 72-Tooth 12 Point XL Ratcheting Combination Wrench
85114	7/16" 72-Tooth 12 Point XL Ratcheting Combination Wrench	85122D	11/16" 72-Tooth 12 Point XL Ratcheting Combination Wrench
85116	1/2" 72-Tooth 12 Point XL Ratcheting Combination Wrench	85124D	3/4" 72-Tooth 12 Point XL Ratcheting Combination Wrench
85118	9/16" 72-Tooth 12 Point XL Ratcheting Combination Wrench		

16 Pc. 72-Tooth 12 Point Metric XL Combination Ratcheting Wrench Sets

- 72-tooth ratcheting box end needs a minimal 5° to move fasteners vs. 30° for standard wrenches
- Off-corner loading design on box end provides better grip and reduces fastener rounding
- Thin head and beam provide greater access in confined work areas
- Size conveniently stamped on both ends of the beam for quick identification
- Manufactured from alloy steel for better strength and longer tool life
- Bright, full polish chrome finish easily wipes clean and resists corrosion
- Longer beam provides greater access to confined work areas
- Meets or exceeds ASME and ANSI specifications
- Included tool roll or rack for storage and organization



Cat. No.	Included Storage	Product Weight
85099R	Tool Roll	8.64 lb

Cat. No.	Included Storage	Product Weight
85099	Wrench Rack	8.26 lb

Cat. No.	Description	Cat. No.	Description
85008D	8mm 72-Tooth 12 Point XL Ratcheting Combination Wrench	85016	16mm 72-Tooth 12 Point XL Ratcheting Combination Wrench
85009	9mm 72-Tooth 12 Point XL Ratcheting Combination Wrench	85017	17mm 72-Tooth 12 Point XL Ratcheting Combination Wrench
85010	10mm 72-Tooth 12 Point XL Ratcheting Combination Wrench	85018	18mm 72-Tooth 12 Point XL Ratcheting Combination Wrench
85011	11mm 72-Tooth 12 Point XL Ratcheting Combination Wrench	85019	19mm 72-Tooth 12 Point XL Ratcheting Combination Wrench
85012	12mm 72-Tooth 12 Point XL Ratcheting Combination Wrench	85020	20mm 72-Tooth 12 Point XL Ratcheting Combination Wrench

Cat. No.	Description	Cat. No.	Description
85013D	13mm 72-Tooth 12 Point XL Ratcheting Combination Wrench	85021	21mm 72-Tooth 12 Point XL Ratcheting Combination Wrench
85014	14mm 72-Tooth 12 Point XL Ratcheting Combination Wrench	85022	22mm 72-Tooth 12 Point XL Ratcheting Combination Wrench
85015	15mm 72-Tooth 12 Point XL Ratcheting Combination Wrench	85024D	24mm 72-Tooth 12 Point XL Ratcheting Combination Wrench

12 Pc. 72-Tooth 12 Point Metric XL Combination Ratcheting Wrench Set with Wrench Rack

- 72-tooth ratcheting box end needs a minimal 5° to move fasteners vs. 30° for standard wrenches
- Off-corner loading design on box end provides better grip and reduces fastener rounding
- Thin head and beam provide greater access in confined work areas
- Size conveniently stamped on both ends of the beam for quick identification
- Manufactured from alloy steel for better strength and longer tool life
- Bright, full polish chrome finish easily wipes clean and resists corrosion
- Longer beam provides greater access to confined work areas vs. standard length wrenches
- Meets or exceeds ASME and ANSI specifications
- Included rack for storage and organization




Cat. No.	Included Storage	Product Weight
85098	Wrench Rack	4.12 lb

Cat. No.	Description	Cat. No.	Description
85008D	8mm 72-Tooth 12 Point XL Ratcheting Combination Wrench	85014	14mm 72-Tooth 12 Point XL Ratcheting Combination Wrench
85009	9mm 72-Tooth 12 Point XL Ratcheting Combination Wrench	85015	15mm 72-Tooth 12 Point XL Ratcheting Combination Wrench
85010	10mm 72-Tooth 12 Point XL Ratcheting Combination Wrench	85016	16mm 72-Tooth 12 Point XL Ratcheting Combination Wrench
85011	11mm 72-Tooth 12 Point XL Ratcheting Combination Wrench	85017	17mm 72-Tooth 12 Point XL Ratcheting Combination Wrench
85012	12mm 72-Tooth 12 Point XL Ratcheting Combination Wrench	85018	18mm 72-Tooth 12 Point XL Ratcheting Combination Wrench
85013D	13mm 72-Tooth 12 Point XL Ratcheting Combination Wrench	85019	19mm 72-Tooth 12 Point XL Ratcheting Combination Wrench

72-Tooth 12 Point XL Combination Ratcheting Wrenches

- 72-tooth ratcheting box end needs a minimal 5° to move fasteners vs. 30° for standard wrenches
- Off-corner loading design on box end provides better grip and reduces fastener rounding
- Thin head and beam provide greater access in confined work areas
- Size conveniently stamped on both ends of the beam for quick identification
- Manufactured from alloy steel for better strength and longer tool life
- Bright, full polish chrome finish easily wipes clean and resists corrosion
- Longer beam provides greater access to confined work areas vs. standard length wrenches
- Meets or exceeds ASME and ANSI specifications

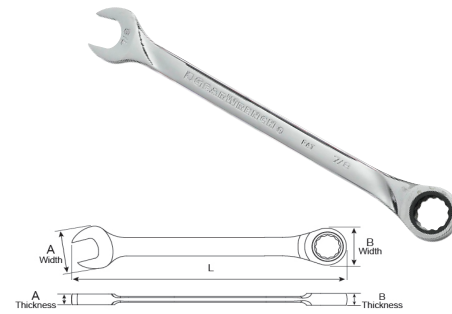

Cat. No.	SAE/Metric	Fastener Size	End A Width	End A Thickness	End B Width	End B Thickness	Overall Length	Product Weight
85108	SAE	1/4 in	0.57 in	0.18 in	0.61 in	0.26 in	5.31 in	0.09 lb
85110	SAE	5/16 in	0.77 in	0.2 in	0.67 in	0.27 in	5.91 in	0.12 lb
85112	SAE	3/8 in	0.86 in	0.22 in	0.78 in	0.3 in	7.09 in	0.17 lb
85114	SAE	7/16 in	0.95 in	0.25 in	0.85 in	0.32 in	7.68 in	0.20 lb
85116	SAE	1/2 in	1.15 in	0.32 in	0.98 in	0.34 in	8.66 in	0.30 lb
85118	SAE	9/16 in	1.23 in	0.33 in	1.04 in	0.37 in	9.25 in	0.38 lb
85120D	SAE	5/8 in	1.36 in	0.35 in	1.2 in	0.41 in	10.24 in	0.43 lb
85122D	SAE	11/16 in	1.49 in	0.36 in	1.27 in	0.42 in	10.83 in	0.49 lb
85124D	SAE	3/4 in	1.63 in	0.37 in	1.34 in	0.44 in	12.01 in	0.76 lb
85126	SAE	13/16 in	1.77 in	0.4 in	1.54 in	0.51 in	12.51 in	0.95 lb
85128	SAE	7/8 in	1.87 in	0.42 in	1.54 in	0.51 in	13 in	1.01 lb
85130	SAE	15/16 in	2.01 in	0.44 in	1.75 in	0.57 in	14 in	1.25 lb
85132	SAE	1 in	2.09 in	0.46 in	1.75 in	0.57 in	14.5 in	1.39 lb
85007	Metric	7 mm	0.64 in	0.19 in	0.62 in	0.26 in	5.61 in	0.09 lb
85008D	Metric	8 mm	0.77 in	0.2 in	0.67 in	0.27 in	5.91 in	0.12 lb
85009	Metric	9 mm	0.77 in	0.21 in	0.7 in	0.27 in	6.5 in	0.14 lb
85010	Metric	10 mm	0.86 in	0.22 in	0.78 in	0.3 in	7.09 in	0.16 lb
85011	Metric	11 mm	0.95 in	0.25 in	0.85 in	0.32 in	7.68 in	0.20 lb
85012	Metric	12 mm	1.05 in	0.29 in	0.91 in	0.34 in	8.15 in	0.23 lb
85013D	Metric	13 mm	1.15 in	0.32 in	0.98 in	0.34 in	8.66 in	0.31 lb
85014	Metric	14 mm	1.23 in	0.33 in	1.04 in	0.37 in	9.25 in	0.36 lb
85015	Metric	15 mm	1.33 in	0.33 in	1.13 in	0.39 in	9.84 in	0.41 lb
85016	Metric	16 mm	1.36 in	0.35 in	1.2 in	0.41 in	10.24 in	0.50 lb
85017	Metric	17 mm	1.49 in	0.36 in	1.27 in	0.42 in	10.83 in	0.55 lb
85018	Metric	18 mm	1.58 in	0.37 in	1.31 in	0.44 in	11.42 in	0.65 lb
85019	Metric	19 mm	1.63 in	0.37 in	1.34 in	0.44 in	12.01 in	0.72 lb
85020	Metric	20 mm	1.77 in	0.4 in	1.54 in	0.51 in	12.51 in	0.99 lb
85021	Metric	21 mm	1.77 in	0.4 in	1.54 in	0.51 in	12.51 in	1.08 lb
85022	Metric	22 mm	1.87 in	0.42 in	1.54 in	0.51 in	13 in	1.14 lb
85024D	Metric	24 mm	2.01 in	0.44 in	1.75 in	0.57 in	14 in	1.24 lb

34 Pc. 72-Tooth 12 Point SAE/Metric Standard/Stubby Combination Ratching Wrench Set

- 72-tooth ratcheting box end needs a minimal 5° to move fasteners vs. 30° for standard wrenches
- Off-corner loading design on box end provides better grip and reduces fastener rounding
- Thin head and beam provide greater access in confined work areas
- Manufactured from alloy steel for better strength and longer tool life
- Bright, full polish chrome finish easily wipes clean and resists corrosion
- Meets or exceeds ASME and ANSI specifications



Cat. No.	Included Storage	Product Weight
85034	None	8.705 lb

Cat. No.	Description	Cat. No.	Description
9010D	5/16" 72-Tooth 12 Point Ratcheting Combination Wrench	-	5/16" 12 Point Stubby Ratcheting Combination Wrench
9012D	3/8" 72-Tooth 12 Point Ratcheting Combination Wrench	9500DD	3/8" 72-Tooth 12 Point Stubby Ratcheting Combination Wrench
9014	7/16" 72-Tooth 12 Point Ratcheting Combination Wrench	9501DD	7/16" 72-Tooth 12 Point Stubby Ratcheting Combination Wrench
9016D	1/2" 72-Tooth 12 Point Ratcheting Combination Wrench	9502D	1/2" 72-Tooth 12 Point Stubby Ratcheting Combination Wrench
9018D	9/16" 72-Tooth 12 Point Ratcheting Combination Wrench	9503D	9/16" 72-Tooth 12 Point Stubby Ratcheting Combination Wrench
9020	5/8" 72-Tooth 12 Point Ratcheting Combination Wrench	9504D	5/8" 72-Tooth 12 Point Stubby Ratcheting Combination Wrench
9022	11/16" 72-Tooth 12 Point Ratcheting Combination Wrench	9505D	11/16" 72-Tooth 12 Point Stubby Ratcheting Combination Wrench
9024	3/4" 72-Tooth 12 Point Ratcheting Combination Wrench	9506D	3/4" 72-Tooth 12 Point Stubby Ratcheting Combination Wrench
9110D	10mm 72-Tooth 12 Point Ratcheting Combination Wrench	9510DD	10mm 72-Tooth 12 Point Stubby Ratcheting Combination Wrench
9111	11mm 72-Tooth 12 Point Ratcheting Combination Wrench	9511D	11mm 72-Tooth 12 Point Stubby Ratcheting Combination Wrench
9112	12mm 72-Tooth 12 Point Ratcheting Combination Wrench	9512D	12mm 72-Tooth 12 Point Stubby Ratcheting Combination Wrench
9113D	13mm 72-Tooth 12 Point Ratcheting Combination Wrench	9513D	13mm 72-Tooth 12 Point Stubby Ratcheting Combination Wrench
9114D	14mm 72-Tooth 12 Point Ratcheting Combination Wrench	9514D	14mm 72-Tooth 12 Point Stubby Ratcheting Combination Wrench
9115D	15mm 72-Tooth 12 Point Ratcheting Combination Wrench	9515D	15mm 72-Tooth 12 Point Stubby Ratcheting Combination Wrench
9116D	16mm 72-Tooth 12 Point Ratcheting Combination Wrench	9516D	16mm 72-Tooth 12 Point Stubby Ratcheting Combination Wrench
9117D	17mm 72-Tooth 12 Point Ratcheting Combination Wrench	9517D	17mm 72-Tooth 12 Point Stubby Ratcheting Combination Wrench
9118D	18mm 72-Tooth 12 Point Ratcheting Combination Wrench	9518D	18mm 72-Tooth 12 Point Stubby Ratcheting Combination Wrench